
 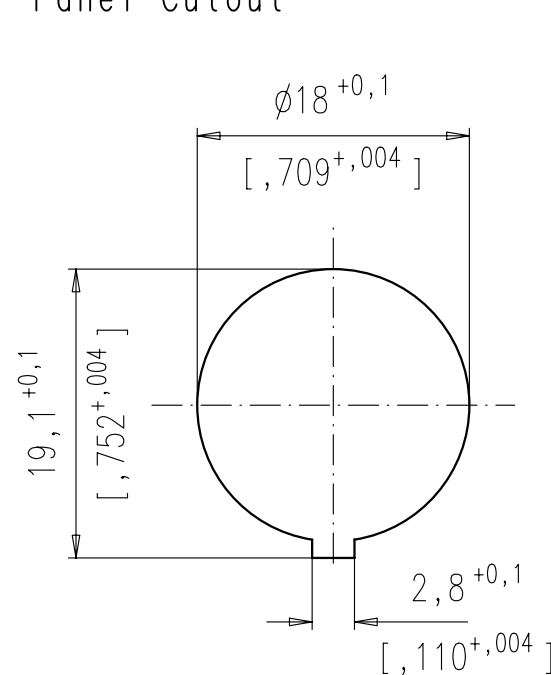
 
 
 
 
 
 
 




Gewicht (errechnet)/ Calc WT:				Zul. Abw./Tolerances:		Maßstab/ Scale 2:1		A3			
Prüfmaß/Testdimension				 DIN/ISO 13715		CUSTOMER DRAWING					
Teileindex Partindexnumber											
				04	Datum/Date	Name		Gerätedose Female receptacle			
				Gez.	29.09.	Meuser					
				Drawn							
				Gepr.							
				Checked							
02	200700144	25.06.08	Cl	Amphenol-Tuchel Electronics GmbH		M	GA T 3XXX 150				Blatt/Sheet
01	200400530	29.09.04	Me								1
Index	Änderung/Description	Datum/Date	Name			Ers. f./Similar to:				1 Bl.	

2		1
	8 IEC	T 3507 150
	7 IEC	T 3487 150
	7	T 3478 150
	6	T 3403 150
	5	T 3363 150
	5 IEC	T 3359 150
	4	T 3303 150
	3	T 3263 150
SYMBOL symbol	POLZAHL number of contacts	TYP-NUMMER-CRIMP type-number-crimp

Diese Steckverbinder dürfen betriebsmäßig nicht unter Spannung betätigt werden. Metallene Gehäuseteile sind sicher mit dem Schutzleitersystem zu verbinden.
Do not connect or disconnect under load. Metal housing parts shall be securely incorporated to protected ground.

Crimpkontakte bitte separat bestellen, Details siehe M-N 02 015 00XX (X)
oder Katalog C091 A/B/D Seite 44
please order crimp contacts separately, details see M-N 02 015 00XX (X)
or catalog C091 A/B/D page 44

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[T3363-150](#)