

Amphenol® LTW®



Head Office (Taiwan):
Amphenol LTW Technology Co., Ltd.
 9F, No.657-12, Jungjeng Road, Shinjuang City,
 Taipei County 242, Taiwan
 Tel : +886-2-2908-5626
 Fax: +886-2-2902-9787~88
 e-mail: sales@ltw-tech.com

Branch Office (China):
Amphenol Zhengri Electronic (Kunshan) Co., Ltd.
 No. 62 Da Tung Road, Peng Lang Street, Kunshan City,
 Jiangsu Province 215333, China
 Tel : +86-512-5761-0501~2
 Fax: +86-512-5761-0515
 Sales Contact: (East China) +86-512-5761-0512
 (South China) +86-755-2823-2407
 137-1383-4316

Distributed by :



Amphenol® LTW®

Waterproof Connector Solutions

Amphenol® LTW® Innovation in Waterproof Solution

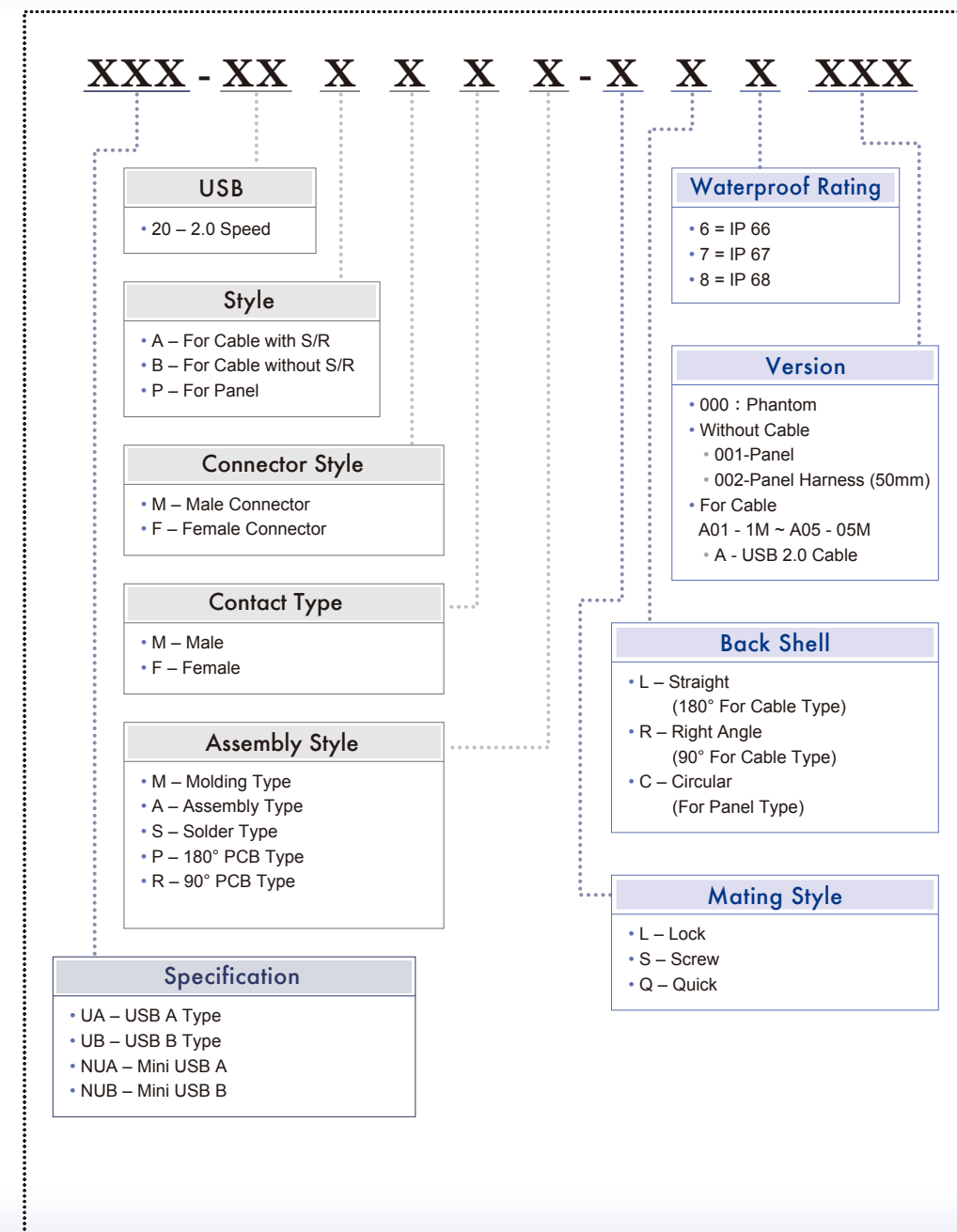
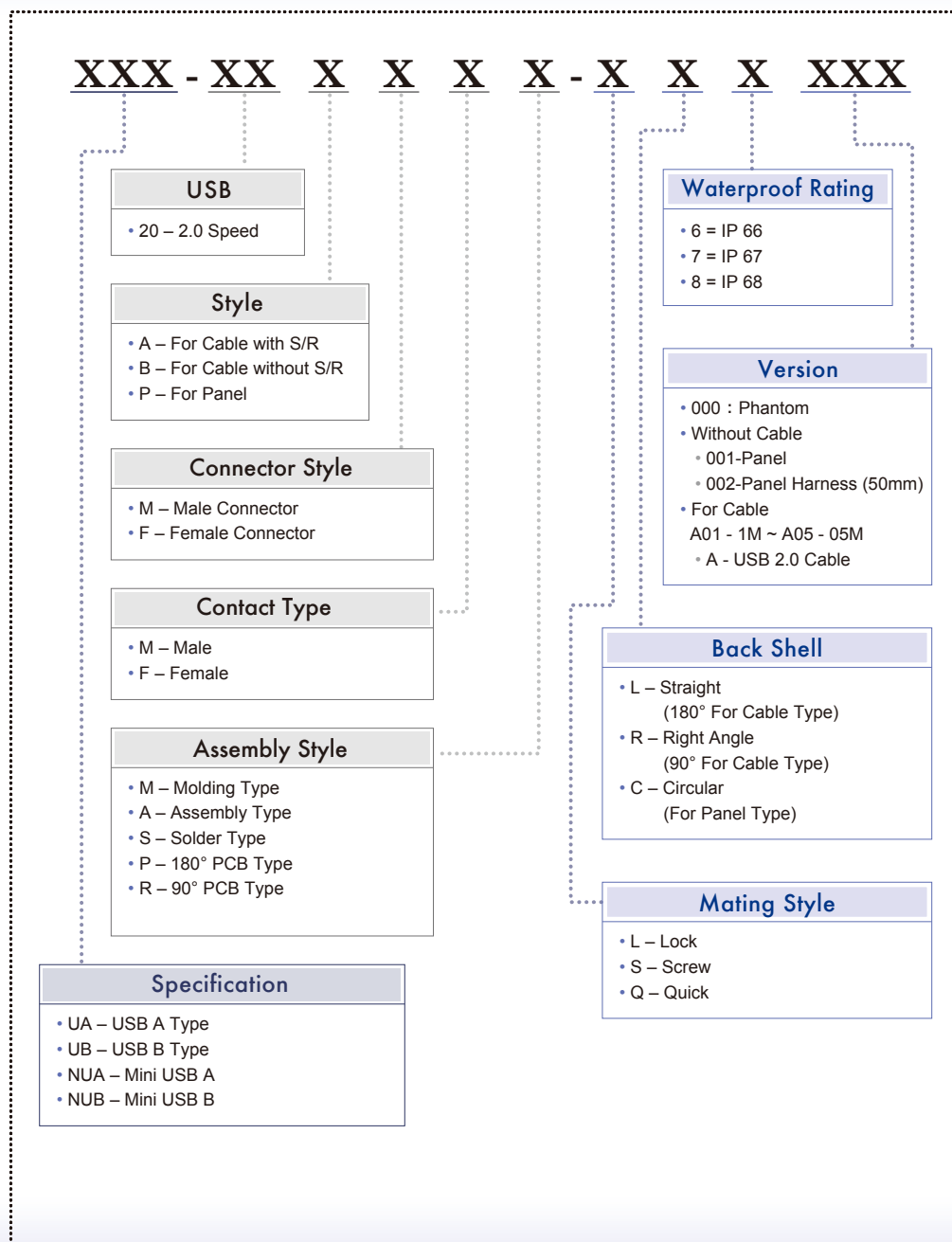


Complete Range of Waterproof Connectors & Cable Assembly

www.amphenolltw.com

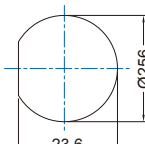
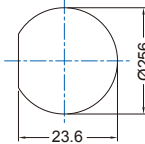
Amphenol LTW reserves the right to improve, enhance and modify the design specifications and construction of Amphenol LTW products without prior notification. For additional product and technical information, please contact us.

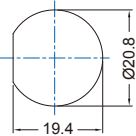
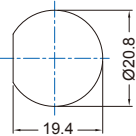
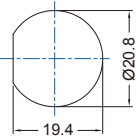
Copyright by Amphenol LTW in Taiwan 05/2010

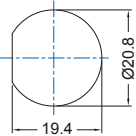
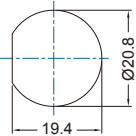
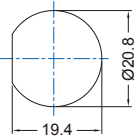


SPECIFICATIONS

No.	Specifications	Standard Value
01. Identifications	USB A Type USB B Type	
02. Description	Panel Mount, Molded with Cable and Field Installable	
03. Current Rating	USB: 1.5A Mini USB: 1A	
04. Speed	480Mbps	
05. Material	Contacts: Copper Alloy, Gold Plated Connector Body: PBT UL94V-0	
06. Temperature Range	-20°C to +80°C	
07. Waterproof Rating	IP67, IP68	
08. Contact Resistance	≤30mΩ Max	
09. Insulation Resistance	≥1000mΩ Min	
10. Breakdown Voltage	≥AC 500V / 1 Minute	
11. Standard Cable Length (for Molded Cable)	1–5M (Standard Cable: USB2.0)	

Male Connector		Mating Parts		Accessories
CONNECTOR	P/N	CONNECTOR	P/N	
 1 LTWUA-20PMFP-LC7△ FEATURES: • USB A Type • Male Connector • PCB 180° • With or without Flying Lead • IP 67 • △ Means Different Versions PANEL CUT-OUT 		 LTWUA-20AFMM-L△7AXX FEATURES: • USB A Type • Female Connector • Cable Length 1 to 5 Meters • IP 67 • △ 180° or 90° In-line Molded Type • With SR		 Waterproof Cover with Chain
 2 LTWUB-20PMFP-LC7△ FEATURES: • USB B Type • Male Connector • PCB 180° • With or without Flying Lead • IP 67 • △ Means Different Versions PANEL CUT-OUT 		 LTWUB-20AFMM-L△7AXX FEATURES: • USB B Type • Female Connector • Cable Length 1 to 5 Meters • IP 67 • △ 180° or 90° In-line Molded Type • With SR		 Waterproof Cover with Rubber Lead

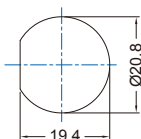
Male Connector		Mating Parts 1~3		Accessories
CONNECTOR	P/N	CONNECTOR	P/N	
 1 LTWUA-20PMFP-SC8△XX FEATURES: • USB A Type • Male Connector • PCB 180° • IP 68 • △ With or without Flying Lead PANEL CUT-OUT 				 Waterproof Cover with Chain
 2 LTWUA-20AMFM-SL7AXX FEATURES: • USB A Type • Male Connector • In-line Molded Type • With SR • Cable Length 1 to 5 Meters • IP 67 PANEL CUT-OUT 		 LTWUA-20BFMM-SL7AXX FEATURES: • USB A Type • Female Connector • In-line Molded Type • Without SR • Cable Length 1 to 5 Meters • IP 67		 Waterproof Cover with Rubber Lead
 3 LTWUA-20BMFA-SL8001 FEATURES: • USB A Type • Male Connector • Field Installable • Without Cable • IP 68 PANEL CUT-OUT 				 Waterproof Cover with Fish Line
				 Waterproof Box

Male Connector		Mating Parts 4~6		Accessories
CONNECTOR	P/N	CONNECTOR	P/N	
 4 LTWUB-20PMFP-SC8△XX FEATURES: • USB B Type • Male Connector • PCB 180° • IP 68 • △ With or without Flying Lead PANEL CUT-OUT 				 Waterproof Cover with Chain
 5 LTWUB-20AMFM-SL7AXX FEATURES: • USB B Type • Male Connector • In-line Molded Type • With SR • Cable Length 1 to 5 Meters • IP 67 PANEL CUT-OUT 		 LTWUB-20BFMM-SL7AXX FEATURES: • USB B Type • Female Connector • In-line Molded Type • Without SR • Cable Length 1 to 5 Meters • IP 67		 Waterproof Cover with Rubber Lead
 6 LTWUB-20BMFA-SL8001 FEATURES: • USB B Type • Male Connector • Field Installable • Without Cable • IP 68 PANEL CUT-OUT 				 Waterproof Cover with Fish Line
				 Waterproof Box

145 USB Screw Style: Mini USB

Male Connector		Mating Parts 1 ~ 4		Accessories
CONNECTOR	P/N	CONNECTOR	P/N	
	1 LTWNUB-20PMFP-SC7001 FEATURES: • Male Connector • PCB 180° • IP 67		LTWNUB-20AFMM-SL7AXX FEATURES: • Female Connector • In-line Molded Type (Cable to Cable) with SR • Cable Length 5 Meters Max • IP 67	 Waterproof Cover with Chain  Waterproof Cover with Rubber Lead  Waterproof Cover
	2 LTWNUB-20PMFR-SC7001 FEATURES: • Male Connector • PCB 90° • IP 67			
	3 TWNUB-20BMFA-SL7001 FEATURES: • Male Connector • Field Installable • Without SR • IP 67			
	4 LTWNUB-20AMFM-SL7AXX FEATURES: • Male Connector • In-line Molded Type (Cable to Cable) with SR • Cable Length 5 Meters Max • IP 67			

PANEL CUT-OUT



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

[LTWUA-20AFMM-LL7A01](#) [LTWUB-20AFMM-LL7A01](#) [LTWNUB-20AFMM-SL7A01](#) [LTWNUB-20AFMM-SL7A02](#)
[LTWNUB-20PMFR-SC7001](#) [LTWNUB-20AFMM-SL7A05](#) [LTWNUB-20PMFP-SC7001](#) [LTWUA-20PMFP-LC7001](#)
[LTWUA-20PMFP-LC7002](#) [LTWUB-20PMFP-LC7001](#) [LTWUB-20PMFP-LC7002](#) [LTWUA-20PMFP-SC8002](#) [LTWUB-](#)
[20PMFP-SC8001](#) [LTWUB-20PMFP-SC8002](#) [LTWUB-20BFMM-SL7A01](#) [UA-20BFM-SA7A01](#) [UA-20PMFP-LC7002](#)
[UA-20AFMM-LR7A02](#) [UA-20AMFM-SL7A03](#) [UA-20AMF-SA7A05](#) [UA-20BFMM-SL7A04](#) [UA-20AFMM-LR7A03](#) [UA-](#)
[20BFMM-NL7A03](#) [UA-20AMFM-SL7A01](#) [UA-20BFM-SA7A02](#) [UA-20BFMM-NL7A02](#) [UA-20AMFM-SL7A05](#) [UA-](#)
[20BFM-SB7A01](#) [UA-20AFMM-LL7A02](#) [UA-20PMFP-LC7003](#) [UA-20AMF-SB7A02](#) [UA-20BFMM-NL7A05](#) [UA-](#)
[20AFMM-LL7A01](#) [UA-20AMF-SA7A01](#) [UA-20AFMM-LL7A05](#) [UA-20AMFM-SL7A02](#) [UA-20BFM-SA7A03](#) [UA-20BFM-](#)
[SA7A05](#) [UA-20AMF-SA7A03](#) [UA-20AMF-SB7A05](#) [UA-20BFM-SB7A05](#) [UA-20PMFJ-NC7001](#) [UA-20AFMM-LR7A01](#)
[UA-20PMFP-LC7001](#) [UA-20AFMM-LR7A05](#) [UA-20AFMM-LL7A03](#) [UA-20BFMM-SL7A03](#) [UA-20BFMM-SL7A01](#) [UA-](#)
[20BFM-SB7A02](#) [UA-20BFMM-SL7A05](#) [UA-20AMF-SB7A01](#) [UA-20BFMM-SL7A02](#) [UA-20BFMM-NL7A04](#) [UA-](#)
[20BFMM-NL7A01](#) [UA-20PMFP-SC8002](#) [UA-20AMF-SA7A02](#) [UA20FL-NAML-SA001](#) [UA20FL-NAML-SA002](#)
[UA20FL-NAML-SA003](#) [UA20FL-NAML-SA005](#) [UA20FL-NBML-SA001](#) [UA20ML-NBML-SA001](#) [UA20ML-NBML-SA002](#)
[UA20ML-NBML-SA005](#) [UA20FL-NBML-SA002](#) [UA20FL-NBML-SA005](#) [UA20ML-NAML-SA001](#) [UA20ML-NAML-](#)
[SA002](#) [UA20ML-NAML-SA003](#) [UA20ML-NAML-SA005](#) [UA-20AFMM-LL7A04](#) [UA-20AFMM-LR7A04](#) [UA-20AMFM-](#)
[SL7A04](#)