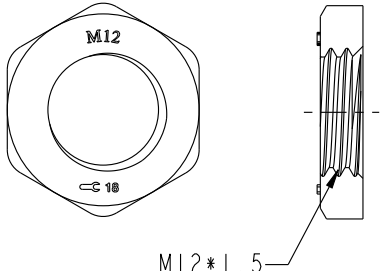
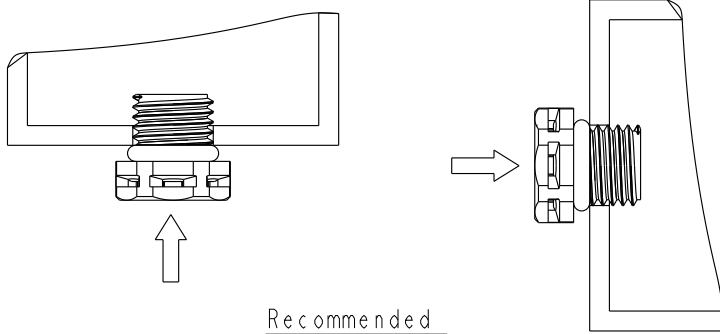
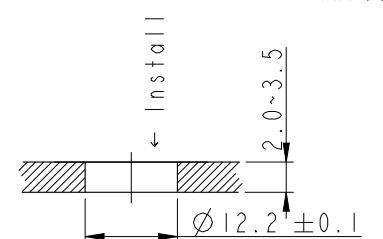
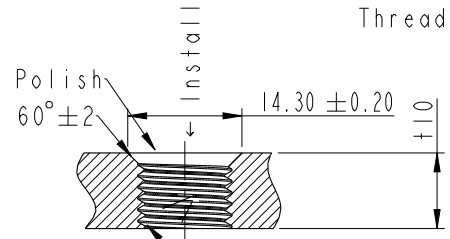
 


		2		3		4		5		6		7		8																																																																																																											
Cap Membrane Housing O-Ring ALTW DCC. DEPT. CONFIDENTIAL 2017.12.21 ISSUED ALTW CONFIDENTIAL 2017-12-15 R&D DEPT. 16 (HEX.) Ø 17.0 Amphenol LTW Ø 15.8 10.0 M12*1.5 O-Ring 10*2 Ø 17.0 Amphenol LTW						REV.	ECN NO.	DATE	SIGN	DESCRIPTION																																																																																																															
						A	Initial Release	2017/03/28	Jinhai	Chnage Rev.05 To Rev.A																																																																																																															
						B	LEN1750155~166	2017/05/12	Jinhai	Add Recommended thickness of plank																																																																																																															
						C	LEN1790339~350	2017/09/25	Ethan	Add透氣量>3000ml/min@70mbar Vent																																																																																																															
						D	LEN17C0606~621	2017/12/15	Ethan	Add O-Ring Dimensions And Modify Dimensions																																																																																																															
Without Nut <table><tr><td>成品料號(Product no.)</td><td>透氣量ml/min@70mbar</td><td>主體顏色(Body Colour)</td><td>O-Ring Color</td><td>疏油性(Oleophobic)</td><td>Waterproof Rate</td></tr><tr><td>VENT-PSINGY-N8001</td><td>>1000</td><td>Gray</td><td>Blue</td><td>N</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSINBK-N8001</td><td>>1000</td><td>Black</td><td>Blue</td><td>N</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSINGY-O8001</td><td>>550</td><td>Gray</td><td>Black</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSINBK-O8001</td><td>>550</td><td>Black</td><td>Black</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSINGY-O8002</td><td>>1000</td><td>Gray</td><td>Green</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSINBK-O8002</td><td>>1000</td><td>Black</td><td>Green</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSINGY-N8002</td><td>>3000</td><td>Gray</td><td>Red</td><td>N</td><td>IP68</td></tr><tr><td>VENT-PSINBK-N8002</td><td>>3000</td><td>Black</td><td>Red</td><td>N</td><td>IP68</td></tr></table> With Nut <table><tr><td>成品料號(Product no.)</td><td>透氣量ml/min@70mbar</td><td>主體顏色(Body Colour)</td><td>O-Ring Color</td><td>疏油性(Oleophobic)</td><td>Waterproof Rate</td></tr><tr><td>VENT-PSIYGY-N8001</td><td>>1000</td><td>Gray</td><td>Blue</td><td>N</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSIYBK-N8001</td><td>>1000</td><td>Black</td><td>Blue</td><td>N</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSIYGY-O8001</td><td>>550</td><td>Gray</td><td>Black</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSIYBK-O8001</td><td>>550</td><td>Black</td><td>Black</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSIYGY-O8002</td><td>>1000</td><td>Gray</td><td>Green</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSIYBK-O8002</td><td>>1000</td><td>Black</td><td>Green</td><td>Y</td><td>IP68/IP69K</td></tr><tr><td>VENT-PSIYGY-N8002</td><td>>3000</td><td>Gray</td><td>Red</td><td>N</td><td>IP68</td></tr><tr><td>VENT-PSIYBK-N8002</td><td>>3000</td><td>Black</td><td>Red</td><td>N</td><td>IP68</td></tr></table>						成品料號(Product no.)	透氣量ml/min@70mbar	主體顏色(Body Colour)	O-Ring Color	疏油性(Oleophobic)	Waterproof Rate	VENT-PSINGY-N8001	>1000	Gray	Blue	N	IP68/IP69K	VENT-PSINBK-N8001	>1000	Black	Blue	N	IP68/IP69K	VENT-PSINGY-O8001	>550	Gray	Black	Y	IP68/IP69K	VENT-PSINBK-O8001	>550	Black	Black	Y	IP68/IP69K	VENT-PSINGY-O8002	>1000	Gray	Green	Y	IP68/IP69K	VENT-PSINBK-O8002	>1000	Black	Green	Y	IP68/IP69K	VENT-PSINGY-N8002	>3000	Gray	Red	N	IP68	VENT-PSINBK-N8002	>3000	Black	Red	N	IP68	成品料號(Product no.)	透氣量ml/min@70mbar	主體顏色(Body Colour)	O-Ring Color	疏油性(Oleophobic)	Waterproof Rate	VENT-PSIYGY-N8001	>1000	Gray	Blue	N	IP68/IP69K	VENT-PSIYBK-N8001	>1000	Black	Blue	N	IP68/IP69K	VENT-PSIYGY-O8001	>550	Gray	Black	Y	IP68/IP69K	VENT-PSIYBK-O8001	>550	Black	Black	Y	IP68/IP69K	VENT-PSIYGY-O8002	>1000	Gray	Green	Y	IP68/IP69K	VENT-PSIYBK-O8002	>1000	Black	Green	Y	IP68/IP69K	VENT-PSIYGY-N8002	>3000	Gray	Red	N	IP68	VENT-PSIYBK-N8002	>3000	Black	Red	N	IP68	Amphenol LTW		ITEM NO		DRAWN BY		DATE	
成品料號(Product no.)	透氣量ml/min@70mbar	主體顏色(Body Colour)	O-Ring Color	疏油性(Oleophobic)	Waterproof Rate																																																																																																																				
VENT-PSINGY-N8001	>1000	Gray	Blue	N	IP68/IP69K																																																																																																																				
VENT-PSINBK-N8001	>1000	Black	Blue	N	IP68/IP69K																																																																																																																				
VENT-PSINGY-O8001	>550	Gray	Black	Y	IP68/IP69K																																																																																																																				
VENT-PSINBK-O8001	>550	Black	Black	Y	IP68/IP69K																																																																																																																				
VENT-PSINGY-O8002	>1000	Gray	Green	Y	IP68/IP69K																																																																																																																				
VENT-PSINBK-O8002	>1000	Black	Green	Y	IP68/IP69K																																																																																																																				
VENT-PSINGY-N8002	>3000	Gray	Red	N	IP68																																																																																																																				
VENT-PSINBK-N8002	>3000	Black	Red	N	IP68																																																																																																																				
成品料號(Product no.)	透氣量ml/min@70mbar	主體顏色(Body Colour)	O-Ring Color	疏油性(Oleophobic)	Waterproof Rate																																																																																																																				
VENT-PSIYGY-N8001	>1000	Gray	Blue	N	IP68/IP69K																																																																																																																				
VENT-PSIYBK-N8001	>1000	Black	Blue	N	IP68/IP69K																																																																																																																				
VENT-PSIYGY-O8001	>550	Gray	Black	Y	IP68/IP69K																																																																																																																				
VENT-PSIYBK-O8001	>550	Black	Black	Y	IP68/IP69K																																																																																																																				
VENT-PSIYGY-O8002	>1000	Gray	Green	Y	IP68/IP69K																																																																																																																				
VENT-PSIYBK-O8002	>1000	Black	Green	Y	IP68/IP69K																																																																																																																				
VENT-PSIYGY-N8002	>3000	Gray	Red	N	IP68																																																																																																																				
VENT-PSIYBK-N8002	>3000	Black	Red	N	IP68																																																																																																																				
UNIT : mm		M12*1.5 VENT		DWG NO		CHECKED BY		DATE																																																																																																																	
TOLERANCE .X ±0.25 .XX ±0.1 .XXX ±0.05 ANGLES ±1°		SCALE 2:1		VENT-PSIXXX-XXXXX		Feng-li		2017-12-15																																																																																																																	
		REV. D		CUSTOMER ALTW		APPROVED BY Jerry		2017-12-15																																																																																																																	
		SIZE A4																																																																																																																							
		SHEET 1 OF 2																																																																																																																							
		WC-REV. A.7																																																																																																																							
		QC: Inspection item																																																																																																																							

THIS DOCUMENT IS SUBJECT TO CHANGE WITHOUT NOTICE. IT IS CONFIDENTIAL AND A PROPERTY OF Amphenol LTW. DISCLOSURE TO THIRD PARTY HAS TO BE AUTHORIZED BY Amphenol LTW.

	1	2	3	4	5	6	7	8				
F	Screw Nut: Optional part No.: APTP-ABKPA012-001 螺母作為選配件				REV.	ECN NO.	DATE	SIGN	DESCRIPTION			
E					 Recommended installation orientation 建議安裝朝向							
D	Through-hole  Recommended Panel Cut-Out 建議開孔尺寸											
C	Threaded-hole  Recommended Panel Cut-Out 建議開孔尺寸											
B					Note: *  Important Dimension. * Cap: Nylon+GF, 94V-0, UV Resistance * Membrane: ePTFE * Body: Nylon+GF, 94V-0, UV Resistance * O-Ring: Silicone, 94V-0 * Nut Torque Force: 6.0~8.0 Kgf.cm							
A	UNIT:mm  TOLERANCE <table><tr><td>.X</td><td>±0.25</td></tr><tr><td>.XX</td><td>±0.1</td></tr><tr><td>.XXX</td><td>±0.05</td></tr><tr><td>ANGLES</td><td>±1°</td></tr></table> TITLE M12*1.5 VENT SCALE 2:1 SIZE A4 SHEET 2 OF 2 REV. D WC-REV. A.7  Inspection item Amphenol LTW 安費諾亮泰企業股份有限公司 ITEM NO DWG NO CUSTOMER ALTW DRAWN BY Ethan CHECKED BY Feng-li APPROVED BY Jerry DATE 2017-12-15 DATE 2017-12-15 DATE 2017-12-15									.X	±0.25	.XX
.X	±0.25											
.XX	±0.1											
.XXX	±0.05											
ANGLES	±1°											
	1	2	3	4	5	6	7	8				

THIS DOCUMENT IS SUBJECT TO CHANGE WITHOUT NOTICE. IT IS CONFIDENTIAL AND A PROPERTY OF Amphenol LTW. DISCLOSURE TO THIRD PARTY HAS TO BE AUTHORIZED BY Amphenol LTW.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[VENT-PS1YBK-N8002](#)