


SIGN	DATE	DESCRIPTION	APPROVER
△			
THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!			

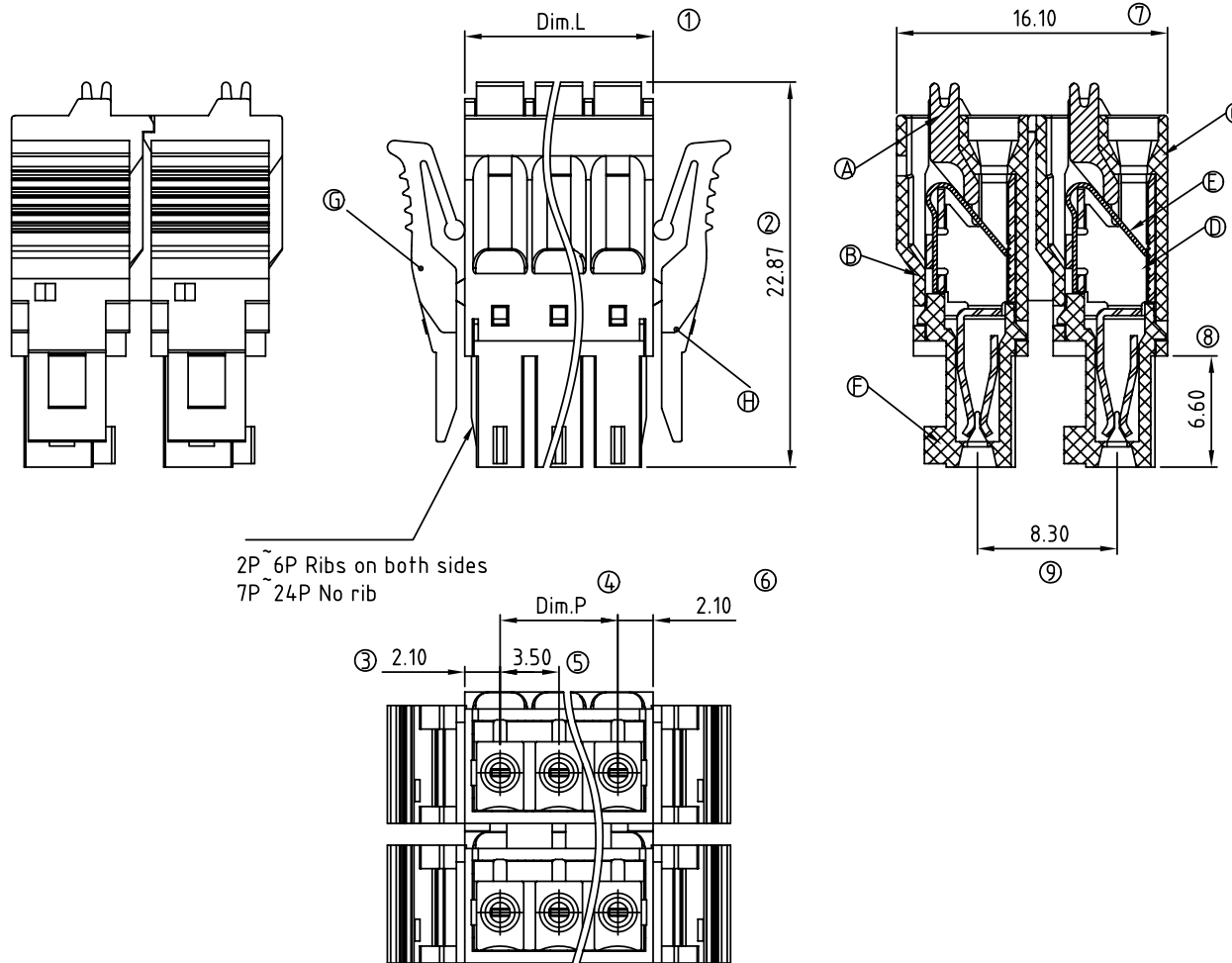

- Material:
- Item ① Terminal lever: Thermoplastic (UL94V-0)
 - Item ② Terminal top housing: Thermoplastic (UL94V-0)
 - Item ③ Terminal back housing: Thermoplastic (UL94V-0)
 - Item ④ Female contact : PhBz Tin Plated.
 - Item ⑤ Spring clamp : Stainless steel
 - Item ⑥ Terminal down housing: Thermoplastic (UL94V-0)
 - Item ⑦ Terminal Left Latch: Thermoplastic (UL94V-0)
 - Item ⑧ Terminal Right Latch: Thermoplastic (UL94V-0)

- Electrical:
- Voltage rating: 160 V
 - Current rating: 5.5 A
 - Wire range:
 - Solid wire(AWG): 16-24
 - Stranded wire(AWG): 16-24
 - Wire strip length: 9-10 mm
 - Withstanding Voltage: 1.32 KV
 - Operating temperature: -40°C to +115°C
 - APPROVAL: US

KD xx 1 0 x 2 Axxx G

No. OF POLES

- 04: 2x2 POLES
- 06: 2x3 POLES
- 48: 2x24 POLES

COLOR

- 0: BLACK
- 5: GREEN (RAL 6018/T)
- 6: BLUE
- 8: GREY (RAL 7035/D)

G: Pb<40000ppm

A000: "@" Logo (Standard)

A00A: "ANYTEK" Mark

Any special item by customer request. please contact sales department.

POLE		2	3	4	5	6	7	8	9	10	11	12
Dim.L		7.70	11.20	14.70	18.20	21.70	25.20	28.70	32.20	35.70	39.20	42.70
Dim.P		3.50	7.00	10.50	14.00	17.50	21.00	24.50	28.00	31.50	35.00	38.50
Tol.		±0.15					±0.25					
POLE	13	14	15	16	17	18	19	20	21	22	23	24
Dim.L	46.20	49.70	53.20	56.70	60.20	63.70	67.20	70.70	74.20	77.70	81.20	84.70
Dim.P	42.00	45.50	49.00	52.50	56.00	59.50	63.00	66.50	70.00	73.50	77.00	80.50
Tol.		±0.30					±0.40					

ANYTEK				CUSTOMER COPY			
ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD							
TITLE	KD 3.5mm W/ Latch Body (Double level) Series						
PART NO.	KDxx10x2AxxxG			DWG NO.	8KD0403		
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.		Tolerance	
		Runner 2010.05.17	Runner 2010.05.17			UNIT: mm	X. ±0.50
						SCALE: NONE	X.X ±0.30
				SHEET: 01/01		REV: B	X.XX ±0.10
							X° ±1°

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

<u>KD041052A000G</u>	<u>KD061052A000G</u>	<u>KD081052A000G</u>	<u>KD101052A000G</u>	<u>KD121052A000G</u>	<u>KD141052A000G</u>
<u>KD161052A000G</u>	<u>KD181052A000G</u>	<u>KD201052A000G</u>	<u>KD221052A000G</u>	<u>KD241052A000G</u>	<u>KD261052A000G</u>
<u>KD281052A000G</u>	<u>KD301052A000G</u>	<u>KD321052A000G</u>	<u>KD341052A000G</u>	<u>KD361052A000G</u>	<u>KD381052A000G</u>
<u>KD401052A000G</u>	<u>KD421052A000G</u>	<u>KD441052A000G</u>	<u>KD461052A000G</u>	<u>KD481052A000G</u>	