 


SIGN	DATE	DESCRIPTION	APPROVER
△	8/07'06	Added VDE standard	梁仁松
△	2010.11.26	The tolerance is changed	Jacke
THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!			

Material

- Item a Clamp: Brass(CuZn) Ni plated
- Item b Terminal screw: Steel Zinc plating "-" slot type
- Item c Female contact: PhBz Tin plated
- Item d With flange screw: Steel Zinc plating M2.5 "+/-" slot type
- Item e Terminal(housing): Thermoplastic (UL94V-0)
- Item f Terminal(cover): Thermoplastic (UL94V-0)

△ Electrical cULus/VDE


- Voltage rating: 300VAC/300VAC
- Current rating: 8A/10A
- Wire range: 1.5mm²
- Solid wire(AWG): 16-28
- Stranded wire(AWG): 16-28
- Torque: 1.7Lb-In./0.2Nm
- Screw: M2
- Wire strip length: 6-7mm
- Withstanding Voltage: 1.6KV/2.5KV
- Operating temperature: -40°C to +115°C
- Safety approval: 

TS xx 3 1 x C xxxx G

No. OF POLES → 02: 2 POLES
: :
24: 24 POLES

Color → 0 Black (RAL9005)
2 Red (RAL3001/D)
3 Orange(RAL2011/P)
4 Yellow(RAL1018/A)
5 Green(RAL6018/T)
6 Blue (RAL5015/A)
8 Grey(RAL 7035/D)

RoHS pb<40 , 000ppm
0000 Standard @ Logo
000A Standard ANY Logo
Any special item by customer request, please contact sales department.

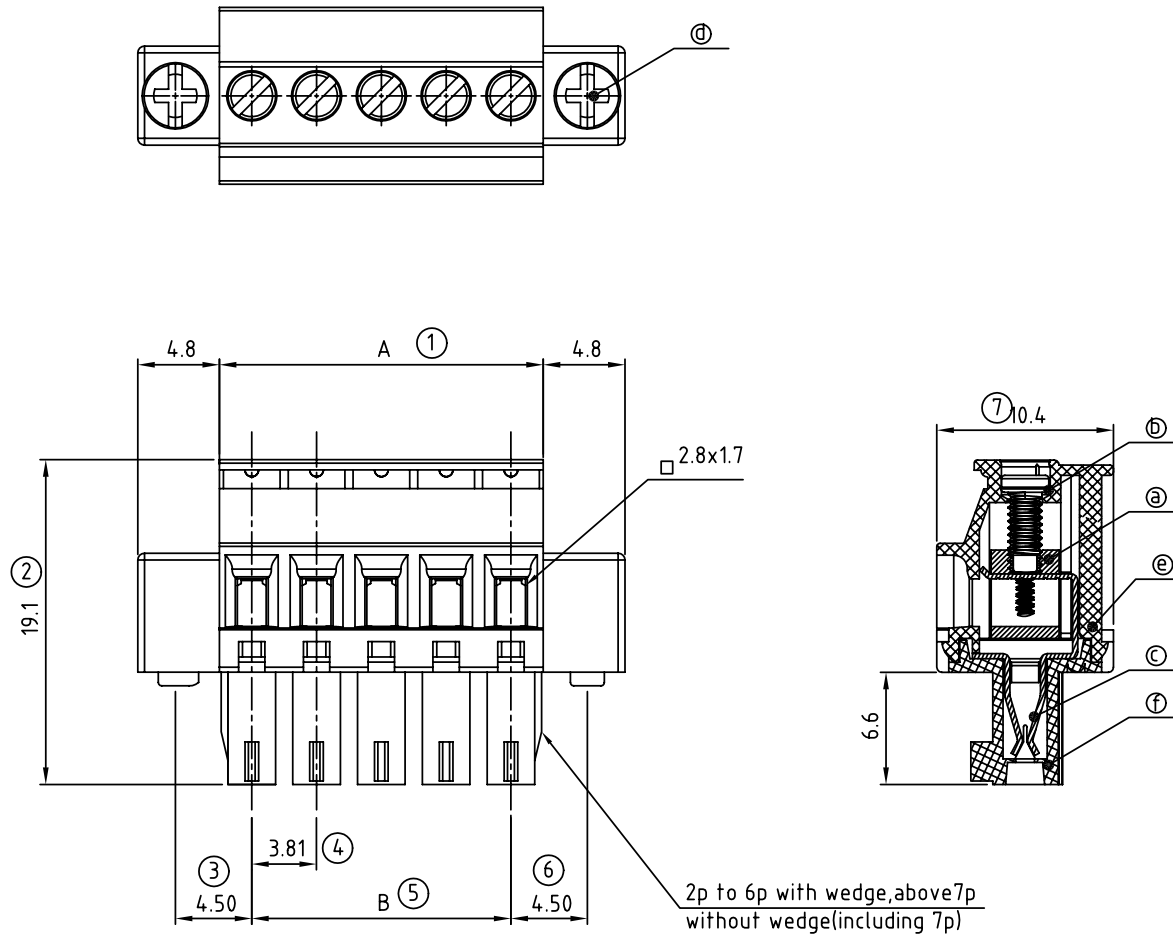

DIMENSION
N = Number of contacts

 
A	NX3.81
B	(N-1)X3.81

Poles	Tolerance
2p-6p	±0.15
7p-12p	±0.20
13p-16p	±0.25
17p-24p	±0.30

ANYTEK

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATSOEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE	TS-3.81mm Series With flange (W/latching hooks on the wire entry side)						
PART NO.	TSxx31xCxxxxG			DWG NO.	8TS0303		
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.			
		Jacke 2010.11.29	Jacke 2009.12.23		UNIT: mm	Tolerance	
					SCALE: NONE	X. ±0.50	
						X.X ±0.30	
						X.XX ±0.10	
						X° ±1°	
				SHEET: 01/01	REV.: G		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

TS02315C0000G	TS03315C0000G	TS04315C0000G	TS05315C0000G	TS06315C0000G	TS07315C0000G
TS08315C0000G	TS09315C0000G	TS10315C0000G	TS11315C0000G	TS12315C0000G	TS13315C0000G
TS14315C0000G	TS15315C0000G	TS16315C0000G	TS17315C0000G	TS18315C0000G	TS19315C0000G
TS20315C0000G	TS21315C0000G	TS22315C0000G	TS23315C0000G	TS24315C0000G	TS07318C0000G
TS03310C0000G	TS04310C0000G	TS02318C0000G	TS05318C0000G	TS08318C0000G	TS12318C0000G
TS02310C0000G	TS09310C0000G	TS10310C0000G	TS03318C0000G	TS04318C0000G	TS08310C0000G
TS05310C0000G	TS06318C0000G	TS07310C0000G	TS11318C0000G	TS13310C0000G	TS15310C0000G
TS19310C0000G	TS10318C0000G	TS11310C0000G	TS13318C0000G	TS16310C0000G	TS14310C0000G
TS17310C0000G	TS21318C0000G	TS16318C0000G	TS17318C0000G	TS18310C0000G	TS22310C0000G
TS23318C0000G	TS14318C0000G	TS15318C0000G	TS19318C0000G	TS24310C0000G	TS20318C0000G
TS21310C0000G	TS18318C0000G	TS24318C0000G	TS20310C0000G	TS22318C0000G	TS06310C0000G
TS09318C0000G	TS12310C0000G	TS23310C0000G			