


CONTACT MALE TAILLE 20

PIN CONTACT SIZE 20

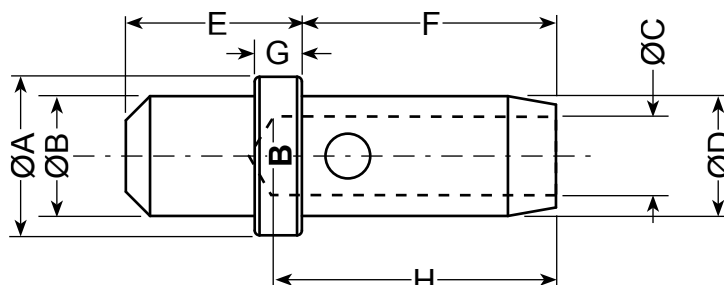

B = code fabricant contact

B = Contact constructor identification

DIMENSIONS CONTACT (mm) CONTACT DIMENSIONS (inch)							
ØA	ØB	ØC	ØD	E	F	G	H
2,62 - 2,54 .103 - .010	1,98 - 1,93 .078 - .076	1,27 - 1,22 .05 - .048	1,98 - 1,93 .078 - .076	3,03 - 2,79 .119 - .110	4,34 - 4,06 .171 - .160	0,83 - 0,73 .033 - .029	4,70 - 4,00 .185 - .157

CABLE		
AWG	Section (mm²)	Ø ext maxi mm (inch)
24 22 20	0,60 à / to 0,25	2,10 .083

OUTILS / TOOLS			
Pince à sertir Crimping tool	Positionneur Locator	INSERTION / EXTRACTION	
		Plastique / Plastic	Métallique / Metallic
M22520 / 1-01 M22520 / 2-01 M22520 / 7-01	M22520 / 1-02 M22520 / 2-02 M22520 / 7-02	M 81969/14-11 001112 200 25	-----

Normes de référence
- EN3155-016 M 2020
- NAS 1748-1749

Standards
- EN3155-016 M 2020
- NAS 1748/1749

CARACTERISTIQUES TECHNIQUES

Matière : Alliage cuivreux
Protection : Or sur nickel
Intensité max du contact : 7,5 A

TECHNICAL DATA

Material : Copper alloy
Plating : Gold on nickel
Max contact current rating : 7,5 A

Masse : 0,1402 g

Weight : 0,1402 g

Amphenol Air LB

29, Voie d'Yvois - 08110 BLAGNY
Tél : (33) 03.24.22.78.49
Fax : (33) 03.24.22.78.75

Réf. / P/N : 001104 203 02

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[00110420302](#)