



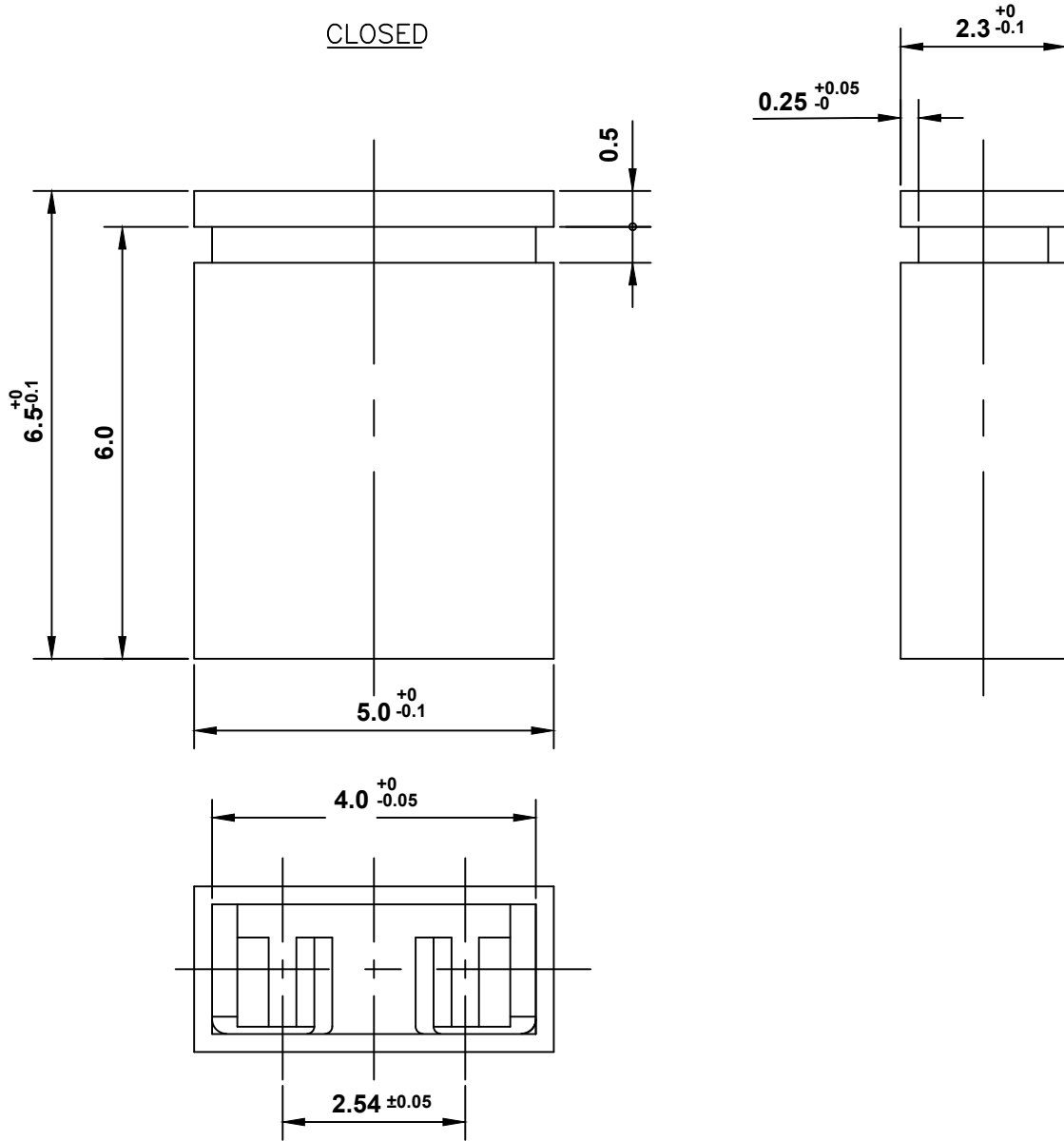

ORDERING INFORMATION

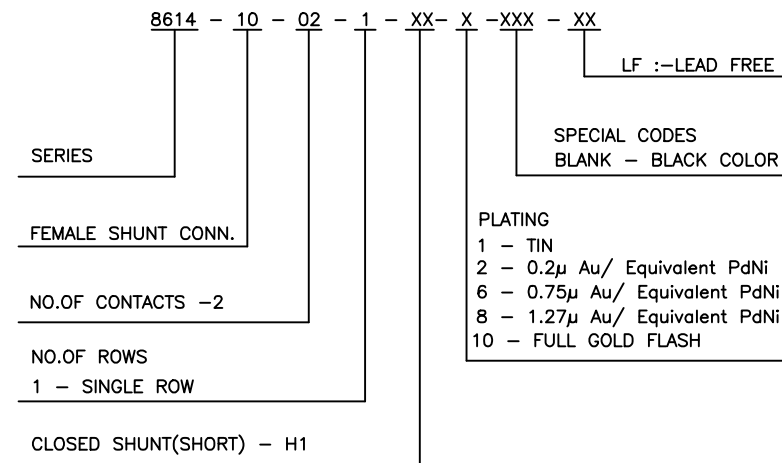

TECHNICAL SPECIFICATION

INSULATOR MATERIAL : SELF EXTINGUISHING THERMOPLASTIC (UL94 VO)

CONTACT MATERIAL : COPPER ALLOY

MAXIMUM VOLTAGE : 500 V rms.

NOMINAL CURRENT : 3A AT 20°C

 
INSULATION RESISTANCE : > 1000 MΩ

CLIMATIC CATAGORY : -55°C TO +125°C / 21 DAYS EXPOSURE TO- INDUSTRIAL ENVIRONMENT HUMIDITY TEST AS HE-14.

CONTACT RESISTANCE : < 20mΩ

NOTES :

1. THE PRODUCT (LF) MEETS EUROPEAN UNION DIRECTIVES AND OTHER COUNTRY REGULATIONS AS DESCRIBED IN GS-47-004

mat'l. code REF TECH SPEC				surface ISO 1302 ✓				tolerance ISO 406 ISO 1101				projection 				product family 8614																										
ltr	ecn no		dr	date		tolerances unless otherwise specified								title FEMALE SHORTING PLUG (CLOSED)																												
C	I06-0124		MKV	2002-07-12		angles linear		.0±0.1																																		
D	I06-0126		MKV	2003-06-07																																						
E	I06-0127		MKV	2004-09-29				0°±1°																																		
F	I06-0116		AB	2006-07-20		dr	MINI K VANDANATH				1998-12-06																dwg no				sheet 1 of 1				size							
G	ELX-I-19435		GMA	2014-11-15		engr	JAI.K.A				1998-12-06																C-8614-0085								A3							
H	ELX-I-24519		GMA	2016-07-15		chr	GREGAR.M				2016-07-15																															
						appd	BIJU K P				2016-07-15																															
sheet index		revision sheet		C	D	E	F	G	H																																	
				1	1	1	1	1	1																																	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[861410021H11LF](#)