

# D-SUB HIGH DENSITY

## Interface adapter – Connector Saver




RoHS compliant – CSA listed, File No.: LR 115000-1 – UL listed, File No.: E202784

### DESCRIPTION

- Variation plug to socket
- Precision machined contacts
- Threaded lock, 4-40 UNC or M3, on the plug side
- Threaded lock on the socket side available on request
- Quality class 3 (also available in quality class 1)
- Shell: Steel tin plated

### PRODUCT DRAWING

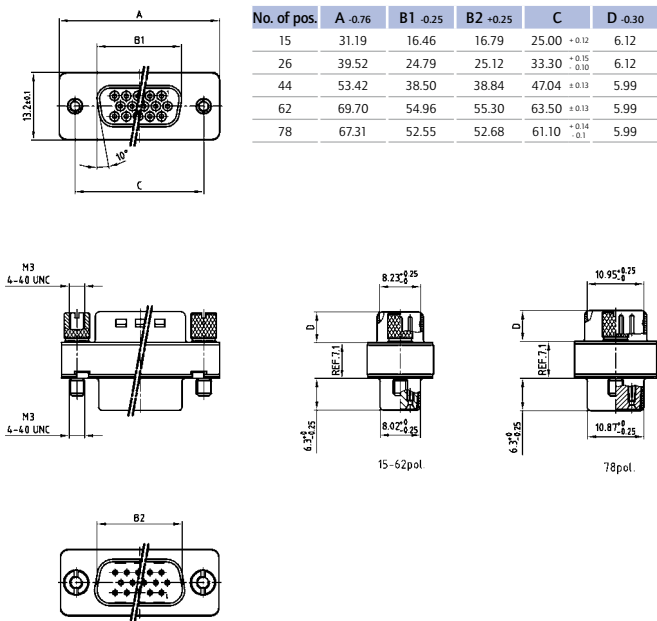

### ORDER DATA

PLUG CONNECTOR – SOCKET CONNECTOR		
No. of pos.	Mounting style	Part Number
15	4-40 UNC Threaded lock	164 A 03399 X
26	4-40 UNC Threaded lock	164 A 03919 X
44	4-40 UNC Threaded lock	164 A 03929 X
62	4-40 UNC Threaded lock	164 A 03939 X
78	4-40 UNC Threaded lock	DAH 5XAAAR04X
15	M3 Threaded lock	164 A 03949 X
26	M3 Threaded lock	164 A 03959 X
44	M3 Threaded lock	164 A 03969 X
62	M3 Threaded lock	164 A 03979 X
78	M3 Threaded lock	DAH 5XAAAR03X

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[164A03929X](#) [164A03399X](#)