


# D-SUB METAL HOOD

Straight cable entry – 9-37 pos. – Jack screws

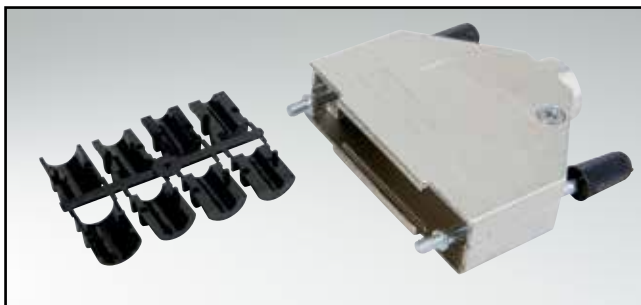


RoHS compliant – CSA listed, File No.: LR 115000-1 – UL listed, File No.: E202784

## DESCRIPTION

- Zinc die-cast hood, EMI/RFI shielding
- Plastic strain relief
- Fastening:  
jack screws 4-40 UNC or M3 thread
- Housing nickel plated
- Attenuation factor: > 40dB between 30 Mhz and 1 GHz
- Packaging: in bulk or in pack units as a single package

## PRODUCT DRAWING

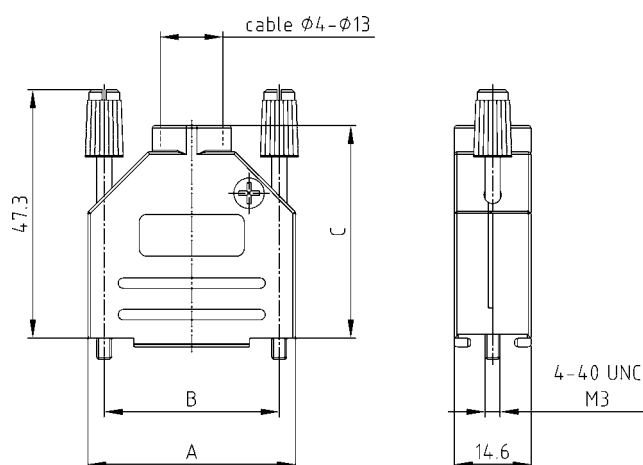

| No. of pos. | A     | B     | C     |
|-------------|-------|-------|-------|
| 09          | 31.20 | 25.00 | 38.30 |
| 15          | 39.30 | 33.30 | 40.50 |
| 25          | 53.40 | 47.00 | 47.80 |
| 37          | 69.90 | 63.50 | 52.20 |

## ORDER DATA

### D-SUB METAL HOOD – STRAIGHT CABLE ENTRY

| No. of pos. | Design 4-40 UNC | Part Number |
|-------------|-----------------|-------------|
| 09          | Jack screw      | 165X02609X  |
| 15          | Jack screw      | 165X02619X  |
| 25          | Jack screw      | 165X02629X  |
| 37          | Jack screw      | 165X02639X  |

For single packaged add the letter „E“ at the end of the part number.

### D-SUB METAL HOOD – STRAIGHT CABLE ENTRY

| No. of pos. | Design M3  | Part Number |
|-------------|------------|-------------|
| 09          | Jack screw | 165X02649X  |
| 15          | Jack screw | 165X02659X  |
| 25          | Jack screw | 165X02669X  |
| 37          | Jack screw | 165X02679X  |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[165X02679X](#) [165X02659X](#) [165X02639X](#) [165X02669X](#)