


SIGN	DATE	DESCRIPTION	APPROVER
△			
THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!			



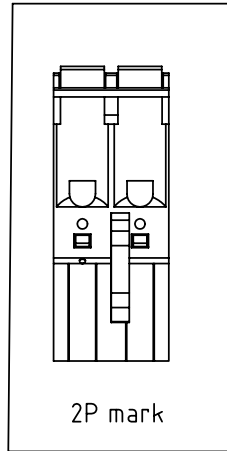


Dimension

DIM A	N×5.08
DIM B	(N-1)×5.08

N=Number of poles

POLES	TOL
2p-6p	±0.15
7p-12p	±0.20
13p-16p	±0.30
17p-24p	±0.40

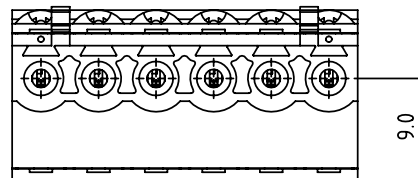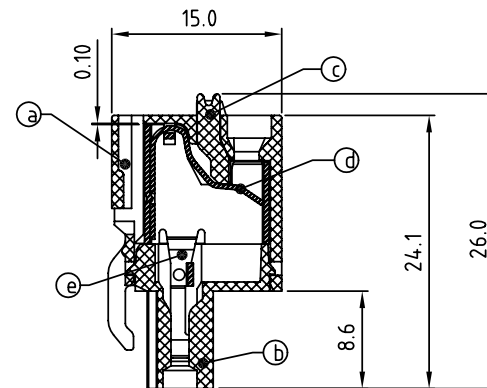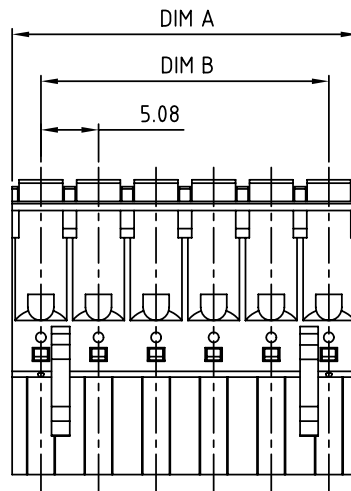

Material

- Item a Terminal body:Thermoplastic (UL94V-0)
- Item b Terminal body:Thermoplastic (UL94V-0)
- Item c Terminal lever:Thermoplastic (UL94V-0)
- Item d Wire guard:Stainless Steel
- Item e Female contact:PhBz (CuSn) Tin plated

Electrical cULus

- Voltage rating:300V
- Current rating:10A
- Solid wire(AWG):12-26
- Stranded wire(AWG):12-26
- Wire strip length: 9-10mm
- Withstanding Voltage:1.6KV
- Operating temperature:-40°C to +115°C

HW xx 50 x 1 xxxx G

02 2 CONTACTS	0 Black	0000 Standard @ Logo	RoHS
03 3 CONTACTS	5 Green	000A Standard ANY Logo	Pb<40,000ppm
... ..	6 Blue	Any special item by	
24 24 CONTACTS	8 Grey	customer request,	
		please contact sales	
		department.	

ANYTEK

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE	HW 5.08 Series Contact on up side							
PART NO.	HWxx50x1xxxxG			DWG NO.	8HW0201			
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.			Tolerance	
		Runner 2010.04.06	Runner 2010.04.06		UNIT: mm	X.	±0.50	
						SCALE: NONE	X.X	±0.30
							X.XX	±0.10
					SHEET: 01/01	REV.: B	X°	±1°

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

HW0250510000G	HW0450510000G	HW0550510000G	HW0650510000G	HW0850510000G	HW0950510000G
HW1050510000G	HW1150510000G	HW1250510000G	HW1350510000G	HW1450510000G	HW1550510000G
HW1650510000G	HW1750510000G	HW1850510000G	HW1950510000G	HW2050510000G	HW2150510000G
HW2250510000G	HW2350510000G	HW2450510000G	HW0350510000G	HW0750510000G	HW0250010000G
HW0250810000G	HW0350010000G	HW0350810000G	HW0450010000G	HW0450810000G	HW0550010000G
HW0550810000G	HW0650010000G	HW0650810000G	HW0750010000G	HW0750810000G	HW0850010000G
HW0850810000G	HW0950010000G	HW0950810000G	HW1050010000G	HW1050810000G	HW1150010000G
HW1150810000G	HW1250010000G	HW1250810000G	HW1350010000G	HW1350810000G	HW1450010000G
HW1450810000G	HW1550010000G	HW1550810000G	HW1650010000G	HW1650810000G	HW1750010000G
HW1750810000G	HW1850010000G	HW1850810000G	HW1950010000G	HW1950810000G	HW2050010000G
HW2050810000G	HW2150010000G	HW2150810000G	HW2250010000G	HW2350010000G	HW2350810000G
HW2450010000G	HW2450810000G	HW2250810000G			