
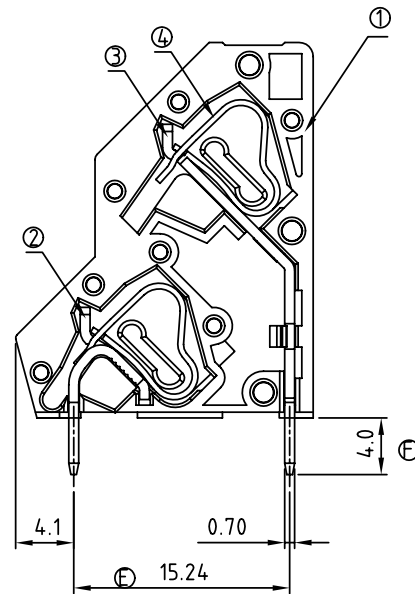


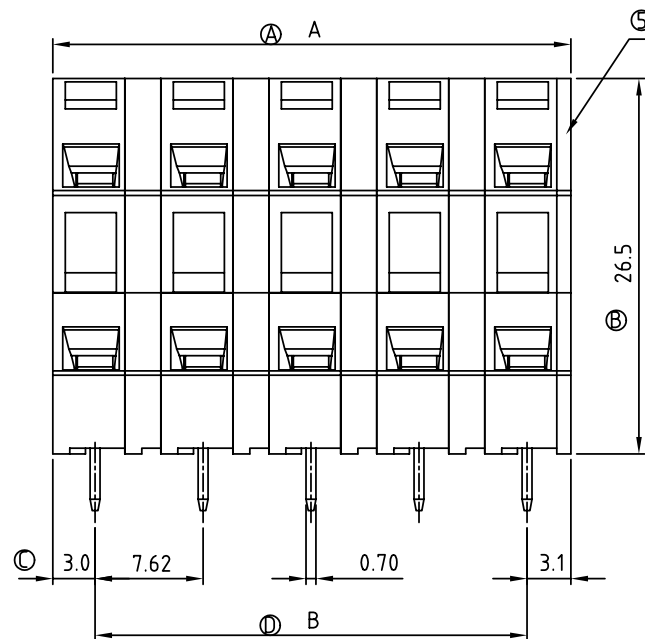

## PCB Layout

|      |       |       |       |       |       |        |        |        |
|------|-------|-------|-------|-------|-------|--------|--------|--------|
| POLE |       | 2x2   | 2x3   | 2x4   | 2x5   | 2x6    | 2x7    | 2x8    |
| A    |       | 13.70 | 21.32 | 28.94 | 36.56 | 44.18  | 51.80  | 59.42  |
| B    |       | 7.62  | 15.24 | 22.86 | 30.48 | 38.10  | 45.72  | 53.34  |
| Tol. | ±0.10 |       |       |       | ±0.15 |        |        |        |
| POLE | 2x9   | 2x10  | 2x11  | 2x12  | 2x13  | 2x14   | 2x15   | 2x16   |
| A    | 67.04 | 74.66 | 82.28 | 89.90 | 97.52 | 105.14 | 112.76 | 120.38 |
| B    | 60.96 | 68.58 | 76.20 | 83.82 | 91.44 | 99.06  | 106.68 | 114.30 |
| Tol. | ±0.20 |       |       |       | ±0.30 |        |        |        |

|                                                |      |             |          |
|------------------------------------------------|------|-------------|----------|
| SIGN                                           | DATE | DESCRIPTION | APPROVER |
| △                                              |      |             |          |
| THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!! |      |             |          |

Electrical:

⚠ ● Safety Approval:  US

No. OF POLES —  
02: 2x1 POLES  
04: 2x2 POLES  
⋮  
32: 2x16 POLES

COLOR —————  
0: BLACK  
5: GREEN (RAL 6018/T)  
6: BLUE  
8: GREY (RAL 7004/P)

- G: Pb<40000ppm
- 0000: “@” Logo (Standard)
- 000A: “ANYTEK” Mark

Any special item by  
customer request.  
please contact sales  
department.

**CUSTOMER COPY**

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

# ANYTEK

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Amphenol:

[HQ0450800000G](#) [HQ0650800000G](#) [HQ0850800000G](#) [HQ1050800000G](#) [HQ1250800000G](#) [HQ1450800000G](#)  
[HQ1650800000G](#) [HQ1850800000G](#) [HQ2050800000G](#) [HQ2250800000G](#) [HQ2450800000G](#) [HQ2650800000G](#)  
[HQ2850800000G](#) [HQ3050800000G](#) [HQ3250800000G](#)