

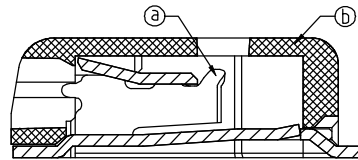
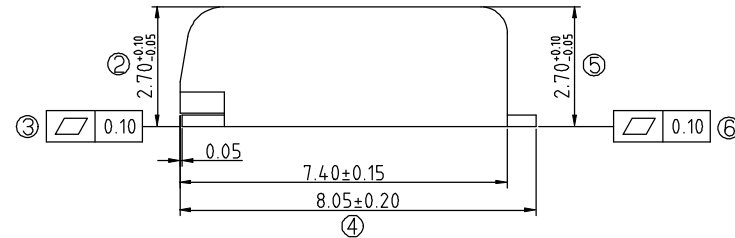


SIGN	DATE	DESCRIPTION	APPROVER
△	2015/11/26	修改白色料號編碼	Chenhao
THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!			

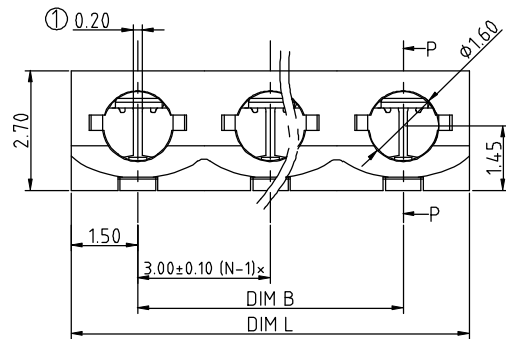

SECTION P-P △

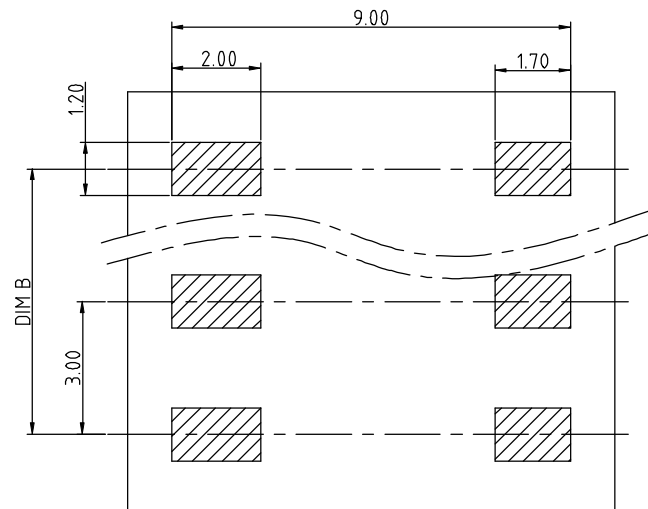

P.C.B. LAYOUT

N=Number of poles

Dim.L	$(N-1) \times 3.0 + 3.0$
Dim.B	$(N-1) \times 3.0$

POLES	DIM B	DIM L
1P	/	+/-0.10
2P	+/-0.10	+/-0.15
3P	+/-0.20	+/-0.20

TOLERANCE

Material

- Item③: Spring: PHBZ, Matte Tin plated over Nickel plated
- Item④: Body: LCP (UL94V-0)
- Electrical UL(1977)
- Voltage rating: 150V
- Current rating: 3A
- Wire range:
- Solid wire(AWG): 22-26
- Wire strip length: 5-6mm
- Withstanding Voltage: 1.3KV
- Operating temperature: -40°C to +130°C
- Reflow Soldering temperature: 260°C/10 Sec max
- Safety Approval: 

NQ xx 4 1 x 0 xxxx G

Poles
01: 1 Pole
02: 2 Poles
03: 3 Poles

Color
0 Black (RAL9005)
1 Natural color
8 Grey (RAL7044)
B White (RAL 9010)

000 0 Standard
Any special item by
customer request,
please contact sales
department.
G RoHS compliant
(lead<4%)
In copper Alloy

ANYTEK

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE		NQ 3.0 LOW PROFILE SERIES (1-3P)			
PART NO.	NQxx41x0xxxxG			DWG NO.	8NQ0201
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.	
		Chenhao 2015/11/26	Chenhao 2015/11/26		Tolerance
					X. ±0.50
					X.X ±0.30
					X.XX ±0.10
					X° ±1°
				SHEET: 01/01	REV.: C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

<u>NQ03411000J0G</u>	<u>NQ02411000J0G</u>	<u>NQ02011000J0G</u>	<u>NQ02410000J0G</u>	<u>NQ03410000J0G</u>	<u>NQ01410000J0G</u>
<u>NQ03011000J0G</u>	<u>NQ01411000J0G</u>	<u>NQ01211000J0G</u>	<u>NQ02211000J0G</u>	<u>NQ0141000000G</u>	<u>NQ0141100000G</u>
<u>NQ0241000000G</u>	<u>NQ0241100000G</u>	<u>NQ0341000000G</u>	<u>NQ0341100000G</u>	<u>NQ0141B00000G</u>	<u>NQ0341800000G</u>
<u>NQ0241800000G</u>	<u>NQ0241B00000G</u>	<u>NQ0141800000G</u>	<u>NQ0341B00000G</u>		