


Part number description :

10134337-XXXLF

LF: Lead Free, RoHs compliant, see note

XXX : Color ref or/and version

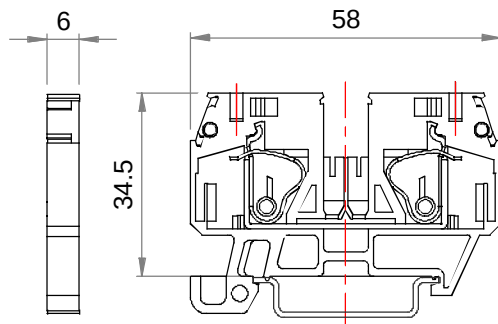

Note : THIS PRODUCT MEETS EUROPEAN UNION DIRECTIVES
AND OTHER COUNTRY REGULATIONS AS PER GS-47-0004

PN	Colour	Version
10134337-001LF	grey	
10134337-002LF	blue	

TECHNICAL DATA / DIMENSIONS

Dimensions	
Width mm	6.0
Length mm	58.0
Height mm	34.5
Mounting type (EN 60715)	Omega TH35
Technical data	
Maximum load current	41A
Insulating material	PA
Self-extinguishing degree acc. to UL94	V0
Rated surge voltage	6kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Nominal Voltage	630V
Nominal Current	32A
Connection data	
Conductor cross-section solid min/max	1.5 / 6 mm ²
Conductor cross-section stranded min/max	1.5 / 6 mm ²
AWG min/max	24-10AWG
Max conductor cross-section stranded with ferrule with plastic sleeve	4 mm ² / L=12 mm
Max conductor cross-section stranded with ferrule without plastic sleeve	6 mm ² / L=12 mm
Stripping length	max 15 mm

ACCESSORIES

Item	Description
Marking	
10134397-001LF	Blank large marking tags for screwless terminals
10134419-001LF	Vertical marking tags

DIN RAIL system - Mounting and Installation material

10134392-001LF	Steel Omega Rail TH35x7,5mm -2mt length
10134393-001LF	Slotted Steel Omega Rail TH35x7,5mm -2mt length
10134394-001LF	Steel Omega Rail TH35x15mm -2mt length
10134395-001LF	Slotted Steel Omega Rail TH35x15mm -2mt length
10134387-001LF	Angled support bracket
10134389-001LF	End Bracket for TH35 Omega rail -Width 9mm
10134390-001LF	End Bracket for TH35 Omega rail -Width 6mm
10134391-001LF	Fast-snap End Bracket for TH35 Omega rail

Additional items

 
10134343-001LF	End Plate for Screwless Terminal Block Q - QE 4
10134272-001LF	Jumper bar 2 poles,pitch 6,1mm -EURO J4
10134272-002LF	Jumper bar 3 poles,pitch 6,1mm -EURO J4
10134272-003LF	Jumper bar 24 poles,pitch 6,1mm -EURO J4
10134271-002LF	Ratchet Cutting Tool for jumper bar J4 -yellow
10134276-001LF	Red test plug adapter
10134276-002LF	Black test plug adapter

APPROVALS



AWG 24-10- 600V - 30A

EN60947-7-1 4mm² - 630V - 32A

spec ref				dir	Aymeric Soudy	30-06-2015	projection			size	A3	scale	1:1
tolerance std ISO 406 ISO 1101	TOLERANCES UNLESS OTHERWISE SPECIFIED			eng	Aymeric Soudy	30-06-2015				ecn no			
				chr									
				appr	Aymeric Soudy	30-06-2015	product family			DIN Terminal Block	rel level		
surface  ISO 1302	linear	0.X	± 0.3		title	Screwless Terminal Block Q4				no dwg no	10134337	rev A	
		0.XX	± 0.1										
	0.XXX	± 0.05											
	angular	0°	± 2°	www.fcj.com	cat. no.	-	Product customer drawing				sheet 1 of 1		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[10134337-002LF](#) [10134337-001LF](#)