

FOR REFERENCE ONLY

SPECIFICATIONS:

AC RATING: 10 AMPS @115VAC (RESISTIVE LOAD)
5 AMPS @115VAC (INDUCTIVE LOAD)
3 AMPS @115VAC (LAMP LOAD)

DC RATING: 10 AMPS @28VDC (RESISTIVE LOAD)
5 AMPS @28VDC (INDUCTIVE LOAD)
3 AMPS @28VDC (LAMP LOAD)

TYPE 7 CONTACT ARRANGEMENTS:

1/2 AMPERAGE LOADS SHOWN ABOVE

MECHANICAL LIFE: 500,000 CYCLES

ACTION: MOMENTARY SNAP OR PUSH PULL

OPERATING FORCE:

SERIES 20 & 30: 3 TO 5 POUNDS MOMENTARY

1/2 TO 2 POUNDS PUSH-PULL

SERIES 22 & 32: 2 TO 3 POUNDS MOMENTARY

WEIGHT: .050 POUNDS MAXIMUM


CASE: ALUMINUM ALLOY 2011-T3,
CLEAR ANODIZED IAW MIL-A-8625

PLUNGER: GLASS FILLED NYLON

BODY: DIALYL PHTHALATE IAW MIL-M-14

TERMINALS: THREADED #2-56 NC-2B

B NX301CB1R-XX

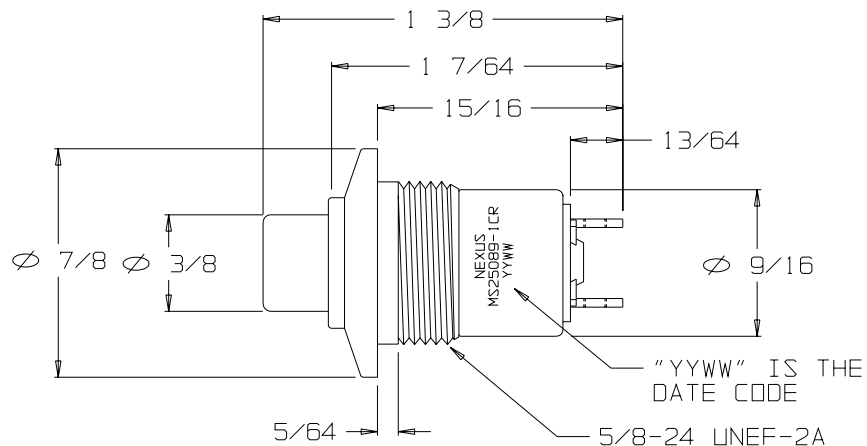

CONTACT
ARRANGEMENT
(SPNO)

DESCRIPTION

DUSTPROOF "SERIES 300" MOMENTARY SWITCH
CONTACTS SPNO - SINGLE POLE NORMALLY OPEN
ADAPTER TYPE "C", COLOR BLACK
BUTTON #1, COLOR RED

ORDERING INFORMATION:

NX301CB1R-00 SWITCH ONLY
NX301CB1R-60 SWITCH, MOUNTING HARDWARE
NX301CB1R-61 SWITCH, MOUNTING HARDWARE, TERNIMAL HARDWARE
NX301CB1R-00EU SWITCH (ROHS) ONLY
NX301CB1R-60EU SWITCH (ROHS), MOUNTING HARDWARE
NX301CB1R-61EU SWITCH (ROHS), MOUNTING HARDWARE, TERNIMAL HARDWARE

THIS DOCUMENT CONTAINS PROPRIETARY INFORMATION OF NEXUS, INCORPORATED AND SUCH INFORMATION MAY NOT BE DISCLOSED TO OTHERS FOR ANY PURPOSE OR USED FOR ANY PURPOSE WITHOUT THE WRITTEN CONSENT OF NEXUS.

DWN. BY EWT	DATE 11/14/06	MATERIAL N/A		
CHECKED BY	DATE	FINISH N/A		
APPR. BY	DATE	WEIGHT —	SCALE N/A	
UNLESS OTHERWISE SPECIFIED DIMENSIONS ARE IN INCHES TOLERANCES ON .XX .XXX ANGLES — ±.003 ±.5°		TITLE SWITCH SPNO MOMENTARY (MS25089-1CR)		
		DO NOT SCALE DWG.	SHEET 1 OF 1	
		SIZE B	DWG. NO. NX301CB1R-XX	

LET.	REVISION	CN #	DATE	CHK.
------	----------	------	------	------



SW-200-23
TERMINAL
(2)

 


SW-200-25
#2 LOCKWASHER
(2)




SW-200-72
#2-56 SCREW
(2)

TERMINAL
HARDWARE



SW-200-34
5/8-24 NUT
(1)

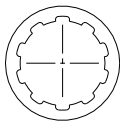

SW-200-35
5/8 LOCKWASHER
(1)

MOUNTING
HARDWARE

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[NX301CB1R](#) [NX301CB1R-61](#) [NXW301CB1R](#)