


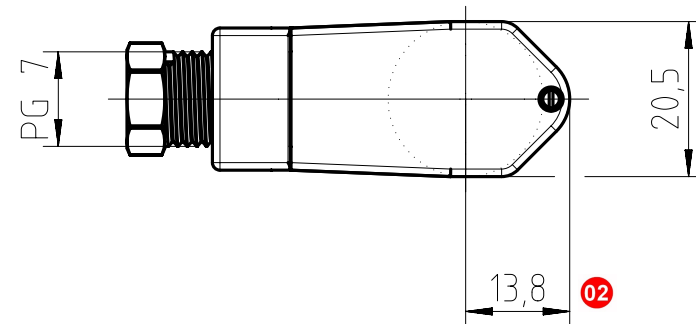

¹⁾ Edition 2000-05 ²⁾ values in brackets are according to DIN EN 61076-2-106 ³⁾ designed acc. pollution degree 2; can be used under pollution degree 3 when the rules of IEC 60644-1 are fulfilled ⁴⁾ under operating conditions >10⁸ Ohm	
Do not connect or disconnect under load. Metal housing parts shall be securely incorporated to protected ground. Remark for gold plated contacts: In order to avoid brittle inter-metallic connections, gold plated terminals have to be tin-plated in the solder area. All technical data have been measured in a laboratory environment and can be different during practical usage of the product. Any product information is for descriptive usage only and not legally binding; particularly the information does not constitute or provide any legal guaranties ("Beschaffungsgarantie" or "Haltbarkeitsgarantie").	

Gewicht (errechnet) / Calc WT :				Zul. Abw./Tolerances :		Maßstab / Scale : 1:1		A3			
 Prüfmaß / Testdimension				ISO 2768-c		 DIN / ISO 13715		CUSTOMER DRAWING			
Teileindex / Partindexnumber:						Female cable connector r/a for cable diameter 4-6mm					
Bagatelle change:											
				Gez.	20.08.2020						
				Drawn	MCARLE						
				Status	Released						
				Gepr.	02.03.2021						
				Checked	MBERTSCH						
02	202100006	01.03.2021	MCARL	Amphenol Tuchel Industrial GmbH		M	C091 31FXXX X00 2 U				Blatt / Sheet 1
01	202000083	26.10.2020	MCARL								1 Bl.
Index	Änderung / Description	Datum / Date	Name			Ers. f. / Replacement for :					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[C091 31F006 100 2](#)