


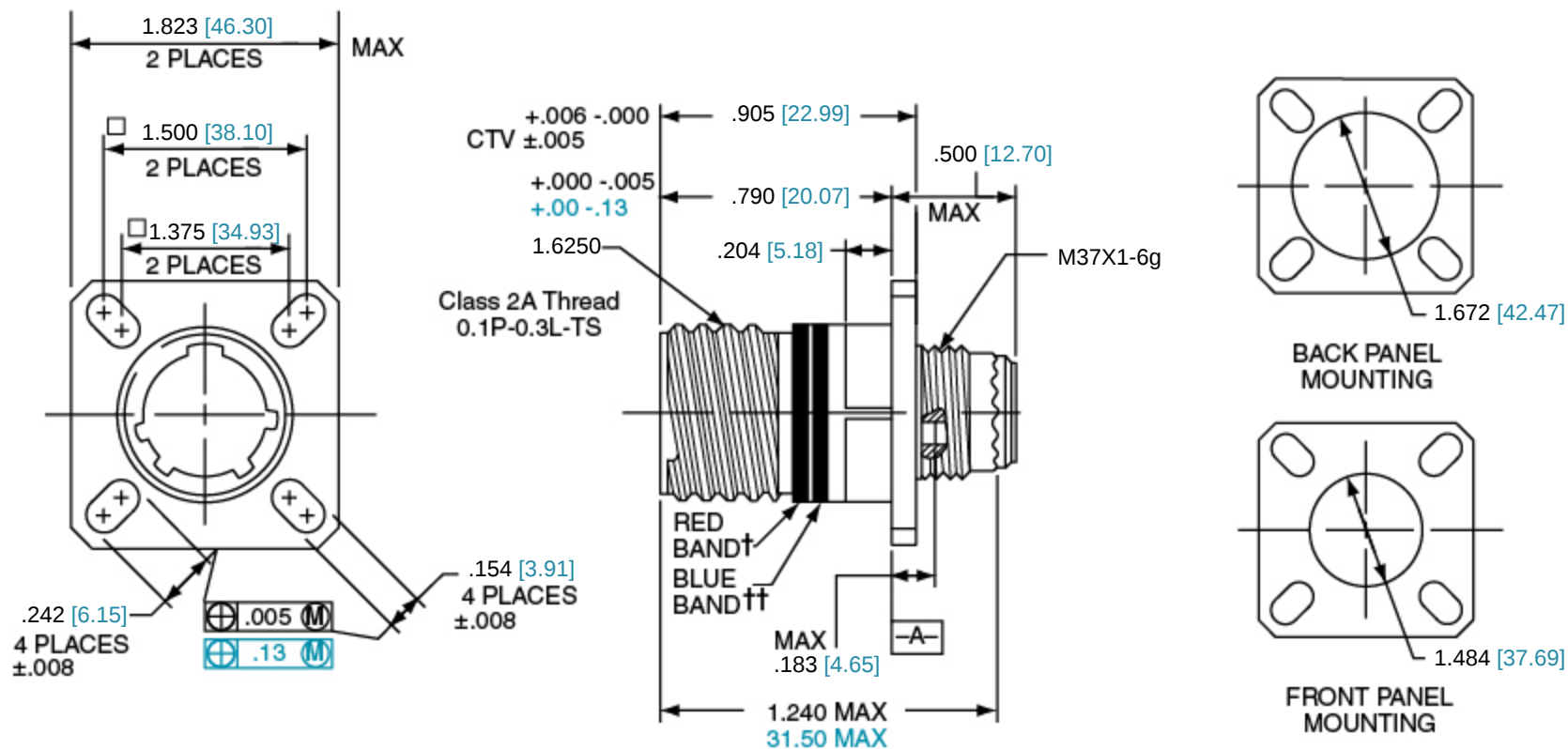

† Red band indicates fully mated
 †† Blue band indicates rear release contact retention system
 □ Designates true position dimensioning


Note: -Drawing not to Scale
 -Dimensions subject to change
 -Dimensions are in Inches, Millimeters (MM) & Blue color
 Property of Amphenol Aerospace.
 All rights reserved.

Part No.:
D38999/20TJ61PN

Amphenol[®] Aerospace
 40-60 Delaware Avenue
 Sidney, NY 13838-1395
 800-678-0141
 Cage Code: 77820
www.amphenol-aerospace.com

Matthew Mullins
Product Line Manager
Core Products
Phone: 607-563-5673
Email: mmullins@amphenol-aao.com

Connector Type	D38999/
Shell Style	Wall Mount Receptacle
Shell Material	Aluminum
Shell Finish	Durmalon (Nickel-PTFE) Plated
Insulation Resistance	5000 megohms min. @500 VDC25C
Operating Temperature [Min]	-65°C
Operating Temperature [Max]	+175°C
Shielding Effectiveness	50dB@10GHz
Durability	500 Hour Salt Spray
Contact Type	P
Contact Description	Pin Contacts

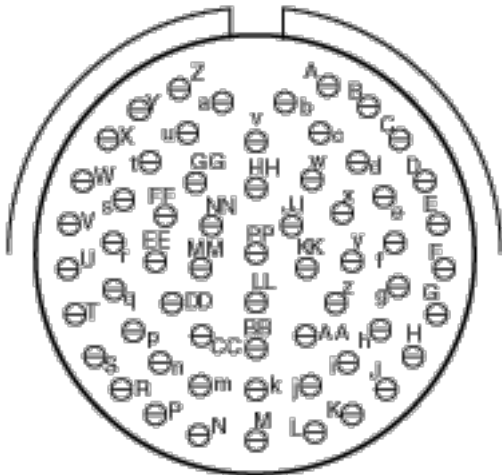Insert Arrangement	
Shell Size	J
Insert Arrg	61
Service Rating	I
Total # Contacts	61
Test Current	7.5 AMPS
Wire Size for 20	24, 22, 20
Contact Size 20	61
Number of Contacts	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[D38999/20TJ61PN](#)