


PT08 SE


SP08 SE

90 degree plug

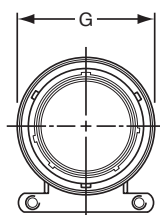


TERMINATION ASSEMBLIES

"SE" Open Wire Seal, "SE" (SR) Strain Relief

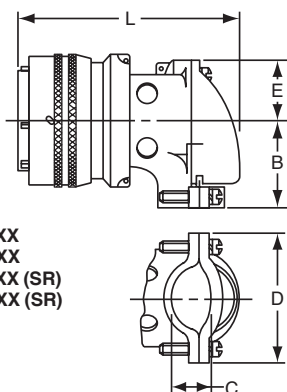

PT08SE-XX-XXX
SP08SE-XX-XXX
PT08SE-XX-XXX (SR)
SP08SE-XX-XXX (SR)

"SP" Potting Boot 75 degrees

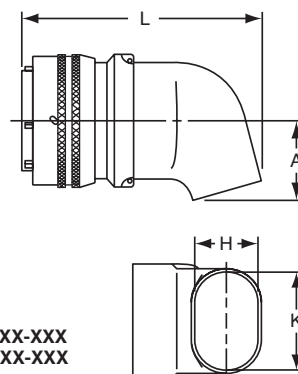

PT08SP-XX-XXX
SP08SP-XX-XXX

To complete part number see how to order on page 36.
All lockwire holes are .044 Dia. Min.

Shell Size	Plug Front View	Plug Side View								
	G Dia. Max.	Class "SE", "SE" (SR)					Class "SP"			
		B $\pm.031$	C $+.010$ $-.025$	D $\pm.062$	E $+.047$ $-.025$	L Max.	A $\pm.025$	H $\pm.015$	K $\pm.015$	L Max.
10	.921	.749	.170	1.191	.393	2.137	.547	.438	.562	2.031
12	1.046	.812	.264	1.191	.450	2.222	.625	.516	.688	2.093
14	1.171	.905	.310	1.254	.519	2.370	.734	.625	.781	2.203
16	1.297	1.030	.330	1.316	.583	2.572	.750	.656	.890	2.250
18	1.422	1.015	.444	1.562	.621	2.680	.781	.703	1.000	2.296
20	1.562	1.077	.510	1.625	.683	2.753	.859	.766	1.125	2.343
22	1.672	1.139	.515	1.719	.739	2.799	.906	.812	1.234	2.390
24	1.797	1.250	.656	1.750	.787	3.037	1.181	.918	1.374	2.624

All dimensions for reference only.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[PT08SE-12-10S\(470\)](#) [PT08SE-10-6P\(424\)](#) [PT08SE-12-10P\(470\)](#)