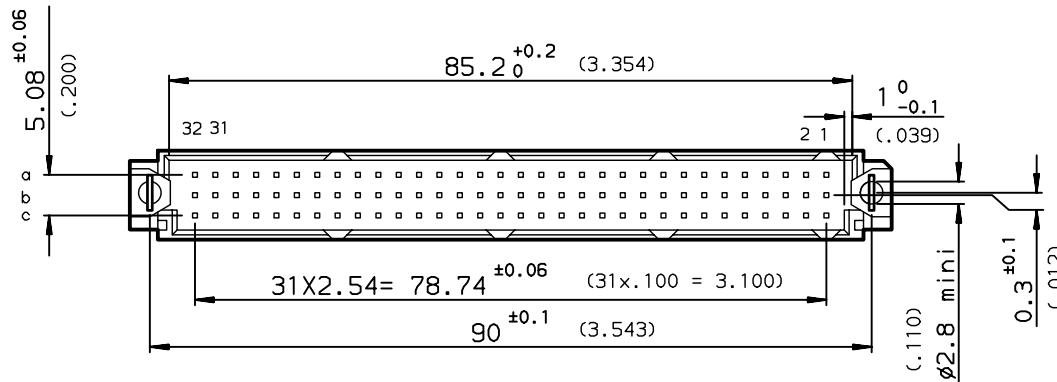
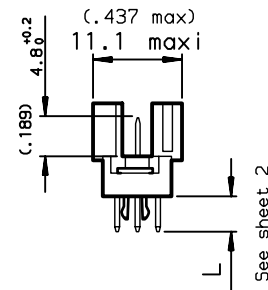
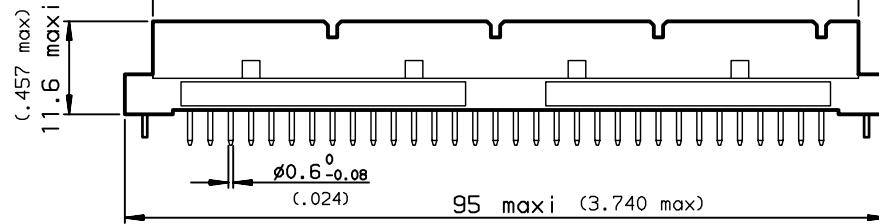


DIMENSIONS

mm (inches)

 $88^{+0}_{-0.2}$ (3.464)

TIN LEAD

LEAD FREE

8609 396 78 14 745 000 E1	8609 396 78 14 745 E1 LF	Style R header, 96 Position, solder to board, class 3
8609 396 78 14 755 000 E1	8609 396 78 14 755 E1 LF	Style R header, 96 Position, solder to board, class 2
8609 396 78 14 765 000 E1	8609 396 78 14 765 E1 LF	Style R header, 96 Position, solder to board, class 1
8609 464 78 14 745 000 E1	8609 464 78 14 745 E1 LF	Style R header, 64 Position, solder to board, class 3
8609 464 78 14 755 000 E1	8609 464 78 14 755 E1 LF	Style R header, 64 Position, solder to board, class 2
8609 464 78 14 765 000 E1	8609 464 78 14 765 E1 LF	Style R header, 64 Position, solder to board, class 1

Application specific part-numbers: See sheet 2

GENERAL CHARACTERISTICS AND ROHS INFORMATIONS:
SEE DRAWING C-8609-0000A


rev	ecn no	dr	date
C	-	ROU	2002/08/28
D	LS05-001	JTA	2005/03/01
E	LS06-0089	LGO	2006/06/01
-	-	-	-
-	-	-	-
-	-	-	-
-	-	-	-

www.fciconnect.com		surface ISO 1302	tolerance std ISO 406 ISO 1101	projection mm	size A3		Scale 1.5:1
TOLERANCES UNLESS OTHERWISE SPECIFIED		ANGULAR	LINEAR	0.X	±0.1	size	ECN
Dr ROUILLARD 23/06/92		0.XX	±0.1	0.XX	±0.1	ECN	LS06-0089
Eng LEGALLIC 23/06/92		0.XX	±2	0.XXX	±0.1	ECN	LS06-0089
Chr LEGARE 23/06/92		Product family		DIN		Spec ref -	
Appr LEGARE 23/06/92		Product family		DIN		Spec ref -	
FCI		STRAIGHT HEADER- STYLE R		C-8609-0265-1		Rev. E	
title SOLDER TO BOARD		catalog no		CUSTOMER		sheet 1 of 2	

B

C

 D



European Views

www.fciconnect.com			surface ISO 1302		tolerance std ISO 406 ISO 1101		projection 		mm 	
			TOLERANCES UNLESS		OTHERWISE SPECIFIED					
Dr	ROUILLARD	23/06/92	ANGULAR	LINEAR	0.X	±0.1	size A3	Scale .51:1		
Eng	LEGALLIC	23/06/92			0.XX	±0.1				
Chr	LEGARE	23/06/92			0.XX' ±2"	0.XXX		±0.1		
Appr	LEGARE	23/06/92	Product family				DIN	Spec ref -		
			title STRAIGHT HEADER - STYLE R SOLDER TO BOARD				dwg no C-8609-0265-2		Rev. E	
catalog no			-				CUSTOMER		sheet 2 of 2	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[FCI / Amphenol:](#)

[86093967814745E1LF](#) [86093967814755E1LF](#) [86093967814765E1LF](#) [86093967824755E1LF](#)
[86093967824765E1LF](#) [86093967824H55E1LF](#) [86093967824H65E1LF](#) [86094647814755E1LF](#) [86094647814765E1LF](#)
[86094647824755E1LF](#)