



## Heyco® North American Receptacle Outlets




### "V" Slotted Terminals

- Snap-in, NEMA 5-15R receptacle.
- Three wire grounding, all sizes rated at 15 Amps/125 Volts.
- Receptacle installs on computers or test equipment to allow for accessory connections.
- Connections are made via "V" slotted terminals.
- Molded of type 6/6 nylon. Flammability classification 94V-0; temperature index 65°C.
- For tab connector data see page 2-15.
- UL and CSA Approved.



PART NO. Black	DESCRIPTION	PART DIMENSIONS										MOUNTING HOLE DIMENSIONS
		A		B		C		D		E		
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	
0961	5-15R SNAP VST	1.06	27,0	.96	24,4	1.06	27,0	.14	3,5	.95	24,1	See Schematic Below

Standard Color: Black.

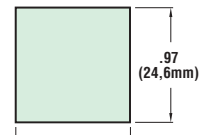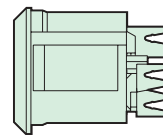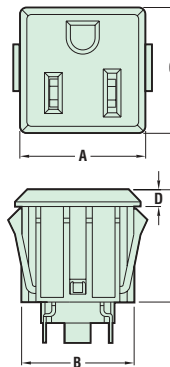




X = .97 FOR .032-.078 THK.  
(24,6mm FOR 0,8-2,0mm THK.)

### "QD" Tabs or Solid Wire




- Snap-in NEMA 5-15R receptacle.
- Three wire grounding. For 12 and 14 AWG rated at 15 Amps/125 Volts. For 16 AWG rated at 13 Amps/125 Volts.
- Receptacle installs on power supplies, computers, test equipment or wherever an accessory is desired or needed.
- Unique design allows for either solid or stranded wire termination (see diagram).
- Molded of type 6/6 nylon. Flammability classification 94V-0; temperature index 65°C.
- Use #0962 for #12 AWG thru #14 AWG.
- Use #0967 for #16 AWG thru #18 AWG.
- For tab connector data see page 2-15.
- UL and CSA Approved.

PART NO. Black	DESCRIPTION	PART DIMENSIONS										MOUNTING HOLE DIMENSIONS
		A		B		C		D		E		
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	
0962	5-15R SNAP QD/IDC 12-14	1.06	27,0	.95	24,1	1.06	27,0	.20	5,0	1.18	30,0	See Schematic Below
0967	5-15R SNAP QD/IDC 16-18											

Standard Color: Black.

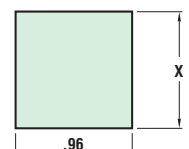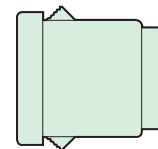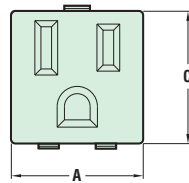

X = .96 FOR .032-.078 THK.  
(24,4mm FOR 0,8-2,0mm THK.)

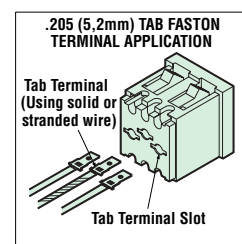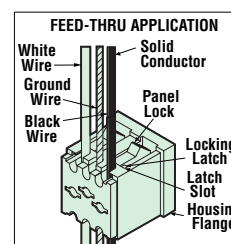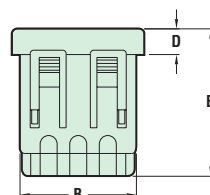

NOTE: THIS ILLUSTRATION PERTAINS TO SOLID WIRE APPLICATIONS ONLY.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[0962](#)