

HEYCO

HEYbrid™ Stainless Steel Liquid Tight Cordgrips

Straight-Thru, NPT Hubs

Don't get SKU'ed: More Cable Range, Fewer SKU's –
Genetically engineered to destroy your inventory monster!
The Ultimate in Liquid Tight Strain Relief Protection

**ALL NEW
PRODUCTS!**



CABLE DIA. RANGE				PART NO.	DESCRIPTION	 or 	PART DIMENSIONS					
Minimum		Maximum					A Clearance Hole Dia.	B Max. O.A. Length	C Thread Length	D Wrenching Thickness	E Nut Flat Size	
in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.

HEYCo-molded Finger/Gland




.065	1,7	.210	5,3	M6000	RSSCG 1/4	cULus	.540	13,7	1.29	32,8	.40	10,2	.20	5,1	.75	19,1
.115	2,9	.250	6,4	M6001	SSCG 1/4											
.065	1,7	.230	5,8	M6002	RSSCG 3/8	cULus	.680	17,3	1.39	35,3	.41	10,4	.20	5,1	.88	22,4
.105	2,7	.315	8,0	M6003	SSCG 3/8											
.095	2,4	.290	7,4	M6006	RSSCG 1/2	cULus	.875	22,2	1.69	42,9	.53	13,5	.20	5,1	1.06	26,9
.170	4,3	.450	11,4	M6007	SSCG 1/2											
.180	4,6	.400	10,1	M6008	RSSCG LL 1/2	cULus	.875	22,2	1.81	46,0	.53	13,5	.20	5,1	1.25	31,8
.260	6,6	.545	13,8	M6009	SSCG LL 1/2											
.250	6,4	.490	12,4	M6010	RSSCG 3/4	cULus	1.109	28,2	1.93	49,0	.55	14,0	.20	5,1	1.31	33,3
.435	11,0	.705	17,9	M6011	SSCG 3/4											
.490	12,4	.785	19,9	M6012	RSSCG 1	cULus	1.375	34,9	2.29	58,1	.69	17,5	.20	5,1	1.75	44,5
.590	15,0	1.000	25,4	M6013	SSCG 1											

Discrete Finger & Gland

.787	20,0	1.02	26,0	M6015	RSSCG 1-1/4	cULus	1.734	44,0	2.56	65,0	.71	18,0	.25	6,4	2.25	57,2
.865	22,0	1.26	32,0	M6016	SSCG 1-1/4											
1.00	25,4	1.24	31,5	M6017	RSSCG 1-1/2	cULus	1.984	50,4	2.69	67,1	.73	18,5	.25	6,4	2.50	63,5
1.23	31,2	1.56	39,6	M6018	SSCG 1-1/2											
1.16	29,5	1.35	34,3	M6019	RSSCG 2	cULus	2.469	62,7	2.92	74,2	.76	19,3	.25	6,4	2.75	69,9
1.45	36,8	1.73	44,0	M6020	SSCG 2											

- HEYCo-molded gripping finger/gland technology accommodates the **widest cable range** over the **fewest sku's**.
- Rolled grease-free threads **prevent galling** and allow for multiple assemblies and disassemblies. No messy, unsightly thread lubrication required.
- Approved for **NEMA 4, 4X, 6 and 6P**.
- Self-retaining sealing rings eliminate the need for an O-Ring groove, thus **reducing cost**.
- Sealing washer required for through hole applications only.
- Typical applications: Control cabinets, marine, car washes, hot tubs, instrumentation, carpet cleaning machines, food processing equipment, underground for direct burial or submersed up to 130 ft. (70 PSIG).
- Ideal for corrosive environments.
- Constructed from corrosion resistant 303 stainless steel.
- Resistant to salt water, acids and most chemicals.
- Locknuts not included. To order locknuts separately, contact Heyco.
- Patent pending.
- DFARS Compliant

The HEYCo-molded Finger, Gland & Seat

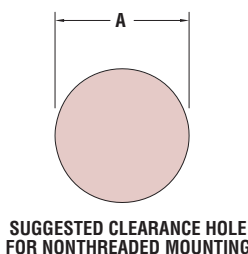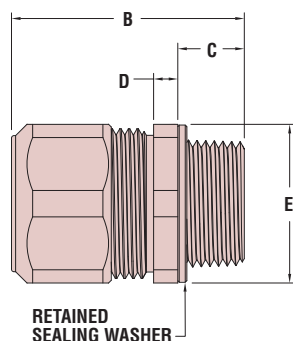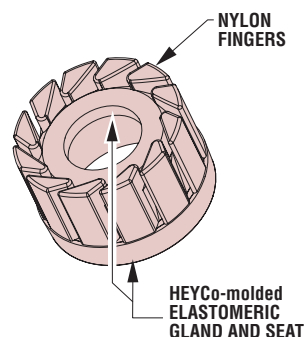

Material	303 Stainless Steel Body and sealing nut with nylon 6/6 and TPE co-molded finger/gland assembly SBR Sealing Washer	
Certifications	cULus	Listed under Underwriters' Laboratories File E51579
	cULus	Recognized under Underwriters' Laboratories File E51579
Flammability Rating	94V-2	
Temperature Range	-40°F (-40°C) to 221°F (105°C)	
IP Rating	IP68 (70 PSI, 5 BAR)	

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M6011](#) [M6009](#) [M6001](#) [M6013](#) [M6002](#) [M6010](#) [M6000](#) [M6007](#) [M6003](#) [M6012](#) [M6006](#) [M6008](#)