

HEYCO

HEYbrid™ Stainless Steel Liquid Tight Cordgrips

Straight-Thru, Metric Hubs


Don't get SKU'ed: More Cable Range, Fewer SKU's –
Genetically engineered to destroy your inventory monster!

The Ultimate in Liquid Tight Strain Relief Protection




ALL NEW
PRODUCTS!



CABLE DIA. RANGE				PART NO.	DESCRIPTION		PART DIMENSIONS									
Minimum		Maximum					A	B		C	D		E			
Clearance Hole Dia.		Max. O.A. Length					Thread Length	Wrenching Nut Thickness		Flat Size						
in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.	in.	mm.		
HEYco-molded Finger/Gland																
.065	1,7	.210	5,3	M6060	RSSCG M12		.473	12,0	1.23	31,2	.34	8,6	.20	5,1	.75	19,1
.115	2,9	.250	6,4	M6061	SSCG M12		.630	16,0	1.31	33,3	.34	8,6	.20	5,1	.88	22,4
.065	1,7	.230	5,8	M6062	RSSCG M16		.630	16,0	1.31	33,3	.34	8,6	.20	5,1	.88	22,4
.105	2,7	.315	8,0	M6063	SSCG M16		.787	20,0	1.58	42,9	.42	13,5	.20	5,1	1.06	26,9
.095	2,4	.290	7,4	M6066	RSSCG M20		.787	20,0	1.70	43,2	.42	10,7	.20	5,1	1.25	31,8
.170	4,3	.450	11,4	M6067	SSCG M20		.985	25,0	1.91	48,5	.53	13,5	.20	5,1	1.31	33,3
.180	4,6	.400	10,2	M6068	RSSCG LL M20		.787	20,0	2.19	55,6	.59	15,0	.20	5,1	1.75	44,5
.260	6,6	.545	13,8	M6069	SSCG LL M20		1.260	32,0	2.19	55,6	.59	15,0	.20	5,1	1.75	44,5
.250	6,4	.490	12,4	M6070	RSSCG M25		.985	25,0	2.19	55,6	.59	15,0	.20	5,1	1.75	44,5
.435	11,0	.705	17,9	M6071	SSCG M25		1.260	32,0	2.19	55,6	.59	15,0	.20	5,1	1.75	44,5
.490	12,4	.785	19,9	M6072	RSSCG M32		1.260	32,0	2.19	55,6	.59	15,0	.20	5,1	1.75	44,5
.590	15,0	1.000	25,4	M6073	SSCG M32											

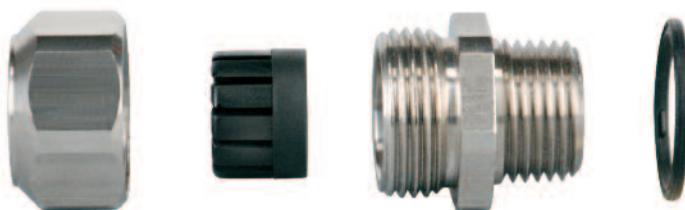

The HEYCo-molded Finger, Gland & Seat

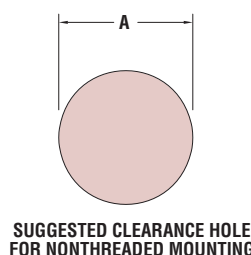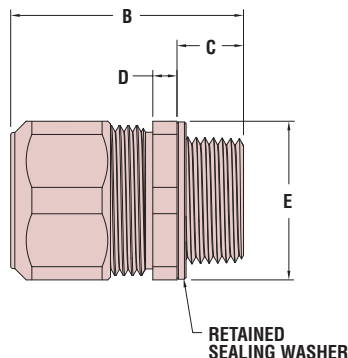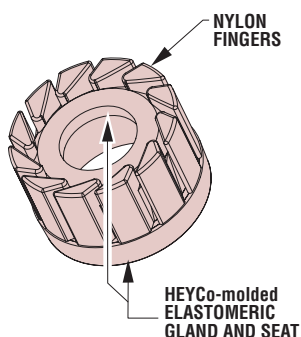

- HEYCo-molded gripping finger/gland technology accommodates the **widest cable range** over the **fewest sku's**.
- Rolled grease-free threads **prevent galling** and allow for multiple assemblies and disassemblies. No messy, unsightly thread lubrication required.
- Approved for **NEMA 4, 4X, 6 and 6P** applications.
- Self-retaining sealing rings eliminate the need for an O-Ring groove, thus **reducing cost**.
- Typical applications: Control cabinets, marine, car washes, hot tubs, instrumentation, carpet cleaning machines, food processing equipment, underground for direct burial or submersed up to 130 ft. (70 PSIG).
- Ideal for corrosive environments.
- Constructed from corrosion resistant 303 stainless steel.
- Resistant to salt water, acids and most chemicals.
- Locknuts not included. To order locknuts separately, see page 3-46.
- Patent pending.
- DFARS Compliant

Material	303 Stainless Steel Body and sealing nut with nylon 6/6 and TPE co-molded finger/gland assembly SBR Sealing Washer
Certifications	cULus Listed under Underwriters' Laboratories File E51579 cULus Recognized under Underwriters' Laboratories File E51579
Flammability Rating	94V-2
Temperature Range	-40°F (-40°C) to 221°F (105°C)
IP Rating	IP68 (70 PSI, 5 BAR)

Quick
Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M6072](#) [M6061](#) [M6067](#) [M6071](#) [M6068](#) [M6063](#) [M6066](#) [M6073](#) [M6060](#) [M6062](#) [M6069](#) [M6070](#)