

## HEYCO

### HEYbrid™ Plated Steel Liquid Tight Cordgrips

#### Straight-Thru, NPT Hubs

Don't get SKU'ed: More Cable Range, Fewer SKU's –

Genetically engineered to destroy your inventory monster!

*The Ultimate in Liquid Tight Strain Relief Protection*

**ALL NEW  
PRODUCTS!**






| CABLE DIA. RANGE |           | PART NO. | DESCRIPTION | UL or RA | PART DIMENSIONS             |                          |                       |                             |                       |           |           |           |           |           |
|------------------|-----------|----------|-------------|----------|-----------------------------|--------------------------|-----------------------|-----------------------------|-----------------------|-----------|-----------|-----------|-----------|-----------|
| Minimum          | Maximum   |          |             |          | A<br>Clearance<br>Hole Dia. | B<br>Max. O.A.<br>Length | C<br>Thread<br>Length | D<br>Wrenching<br>Thickness | E<br>Nut<br>Flat Size |           |           |           |           |           |
| in.   mm.        | in.   mm. |          |             |          | in.   mm.                   | in.   mm.                | in.   mm.             | in.   mm.                   | in.   mm.             | in.   mm. | in.   mm. | in.   mm. | in.   mm. | in.   mm. |

#### HEYco-molded Finger/Gland

|      |      |       |      |              |              |       |       |      |      |      |     |      |     |     |      |      |
|------|------|-------|------|--------------|--------------|-------|-------|------|------|------|-----|------|-----|-----|------|------|
| .065 | 1,7  | .210  | 5,3  | <b>M6200</b> | RPSCG 1/4    | cULus | .540  | 13,7 | 1.29 | 32,8 | .40 | 13,2 | .20 | 5,1 | .75  | 19,1 |
| .115 | 2,9  | .250  | 6,4  | <b>M6201</b> | PSCG 1/4     | cULus | .540  | 13,7 | 1.29 | 32,8 | .40 | 13,2 | .20 | 5,1 | .75  | 19,1 |
| .065 | 1,7  | .230  | 5,8  | <b>M6202</b> | RPSCG 3/8    | cULus | .680  | 17,3 | 1.39 | 35,3 | .41 | 10,4 | .20 | 5,1 | .88  | 22,4 |
| .105 | 2,7  | .315  | 8,0  | <b>M6203</b> | PSCG 3/8     | cULus | .680  | 17,3 | 1.39 | 35,3 | .41 | 10,4 | .20 | 5,1 | .88  | 22,4 |
| .095 | 2,4  | .290  | 7,4  | <b>M6206</b> | RPSCG 1/2    | cULus | .875  | 22,2 | 1.69 | 42,9 | .53 | 13,5 | .20 | 5,1 | 1.06 | 26,9 |
| .170 | 4,3  | .450  | 11,4 | <b>M6207</b> | PSCG 1/2     | cULus | .875  | 22,2 | 1.69 | 42,9 | .53 | 13,5 | .20 | 5,1 | 1.06 | 26,9 |
| .180 | 4,6  | .400  | 10,1 | <b>M6208</b> | RPSCG LL 1/2 | cULus | .875  | 22,2 | 1.81 | 46,0 | .53 | 13,5 | .20 | 5,1 | 1.25 | 31,8 |
| .260 | 6,6  | .545  | 13,8 | <b>M6209</b> | PSCG LL 1/2  | cULus | .875  | 22,2 | 1.81 | 46,0 | .53 | 13,5 | .20 | 5,1 | 1.25 | 31,8 |
| .250 | 6,4  | .490  | 12,4 | <b>M6210</b> | RPSCG 3/4    | cULus | 1.109 | 28,2 | 1.93 | 49,0 | .55 | 14,0 | .20 | 5,1 | 1.31 | 33,3 |
| .435 | 11,0 | .705  | 17,9 | <b>M6211</b> | PSCG 3/4     | cULus | 1.109 | 28,2 | 1.93 | 49,0 | .55 | 14,0 | .20 | 5,1 | 1.31 | 33,3 |
| .490 | 12,4 | .785  | 19,9 | <b>M6212</b> | RPSCG 1      | cULus | 1.375 | 34,9 | 2.29 | 58,1 | .69 | 17,5 | .20 | 5,1 | 1.75 | 44,5 |
| .590 | 15,0 | 1.000 | 25,4 | <b>M6213</b> | PSCG 1       | cULus | 1.375 | 34,9 | 2.29 | 58,1 | .69 | 17,5 | .20 | 5,1 | 1.75 | 44,5 |

- **HEYCo-molded gripping finger/gland technology** accommodates the **widest cable range** over the **fewest sku's**.
- Rolled grease-free threads **prevent galling** and allow for multiple assemblies and disassemblies. No messy, unsightly thread lubrication required.
- Approved for **NEMA 4, 4X, 6 and 6P** applications.
- Self-retaining sealing rings eliminate the need for an O-Ring groove, thus **reducing cost**.
- Sealing washer required for through hole applications only.
- Typical applications: Control cabinets, car washes, hot tubs, instrumentation, carpet cleaning machines, underground for direct burial or submersed up to 130 ft. (70 PSIG).
- Constructed from corrosion resistant Zinc Plated steel.
- Resistant to salt water, acids and most chemicals.
- Patent pending.
- DFARS Compliant

#### The HEYCo-molded Finger, Gland & Seat

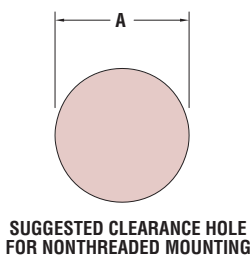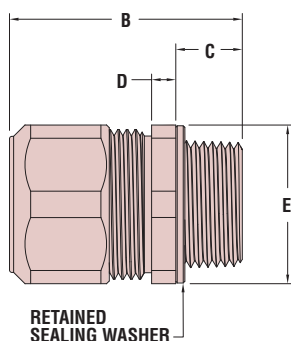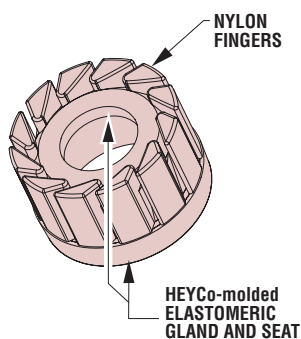

|                     |                                                                                                                            |
|---------------------|----------------------------------------------------------------------------------------------------------------------------|
| Material            | Zinc Plated Steel Body and sealing nut with nylon 6/6 and TPE co-molded finger/gland assembly<br>SBR Sealing Washer        |
| Certifications      | cULus Listed under Underwriters' Laboratories File E51579<br>cRAus Recognized under Underwriters' Laboratories File E51579 |
| Flammability Rating | 94V-2                                                                                                                      |
| Temperature Range   | -40°F (-40°C) to 221°F (105°C)                                                                                             |
| IP Rating           | IP68 (70 PSI, 5 BAR)                                                                                                       |

*Quick  
Specs*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M6209](#) [M6203](#) [M6206](#) [M6210](#) [M6200](#) [M6202](#) [M6211](#) [M6207](#) [M6212](#) [M6201](#) [M6208](#) [M6213](#)