

HEYCO

**NO O-RING
REQUIRED!**









Heyco® -Tite Liquid Tight Cordgrips

Pigtail™, Metric Hubs with Integral Sealing Ring

The Ultimate in Liquid Tight Strain Relief Protection



- Flexible Pigtail extender prevents sharp bends and extends cable life.
- Integral Sealing Ring ensures a superior seal at the clearance or threaded mounting hole location, every time.
- Widest range of approved cable diameters.
- IP 68 rated.
- Approved for **NEMA 4, 4X, 6 and 6P** applications.
- Ratchet design of sealing nut assembly provides superior anti-vibration protection and ensures a firm grip on the cable.
- Acme threads on body prevent skipping and speed installation.
- All nylon construction with Buna N or TPE sealing gland resists salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents. (This feature is not assessed by UL.)
- Multiple sizes for flexible cord diameters ranging from .065" (1,7 mm) to .705" (17,9 mm).
- We recommend using the fitting with the smallest maximum diameter that will fit your application.
- **Unassembled Nylon Locknuts INCLUDED.**
- For Heyco Liquid Tight Threaded Plugs, see page 3-49.
- Consult Heyco for cordgrips molded in other colors.

| CABLE DIA. RANGE | | | | PART NO. | | | DESCRIPTION |  | PART DIMENSIONS | | | | | | | |
|------------------|------|---------|------|---|-------|-----------------|------------------|---|--------------------------|-----------------------|------|--------------------|-----|--------------------------|------|------|
| Minimum | | Maximum | | Including Nylon Nut* Black Gray | | No Nut Black †† | | | A Clearance Hole Dia. | B Max. O.A. Length | | C Thread Length | | E Wrenching Nut Flats | | |
| in. | mm. | in. | mm. | | | | | | in. | mm. | in. | mm. | in. | mm. | in. | mm. |
| .065 | 1,7 | .210 | 5,3 | M4396 | M4397 | M4422 | Flex RLTCG M12 |  | .473 | 12,0 | 2.44 | 62,0 | .32 | 8,1 | .63 | 16,0 |
| .115 | 2,9 | .250 | 6,4 | M4398 | M4399 | M4424 | Flex LTCG M12 | | | | | | | | | |
| .065 | 1,7 | .230 | 5,8 | M4400 | M4401 | M4426 | Flex RLTCG M16 |  | .630 | 16,0 | 2.77 | 70,4 | .32 | 8,1 | .82 | 20,8 |
| .105 | 2,7 | .315 | 8,0 | M4402 | M4403 | M4428 | Flex LTCG M16 | | | | | | | | | |
| .095 | 2,4 | .290 | 7,4 | M4404 | M4405 | M4430 | Flex RLTCG M20 |  | .787 | 20,0 | 3.89 | 98,8 | .41 | 10,4 | .98 | 24,9 |
| .170 | 4,3 | .450 | 11,4 | M4406 | M4407 | M4432 | Flex LTCG M20 | | | | | | | | | |
| .260 | 6,6 | .545 | 13,8 | M3270 | M3271 | - | Flex LTCG LL M20 |  | .787 | 20,0 | 4.34 | 110,2 | .41 | 10,4 | 1.06 | 26,9 |
| .250 | 6,4 | .490 | 12,4 | M4408 | M4409 | M4434 | Flex RLTCG M25 | | | | | | | | | |
| .435 | 11,1 | .705 | 17,9 | M4410 | M4411 | M4436 | Flex LTCG M25 |  | .985 | 25,0 | 5.04 | 128,0 | .52 | 13,2 | 1.30 | 33,0 |
| | | | | | | | | | | | | | | | | |


Standard colors black and gray.

*Nylon locknuts shipped unassembled

††For No Nut Part Nos. in gray color please visit our Cordgrip product section at heyco.com

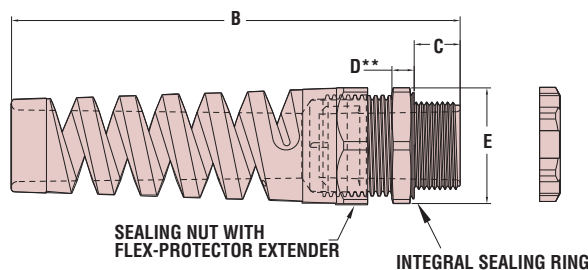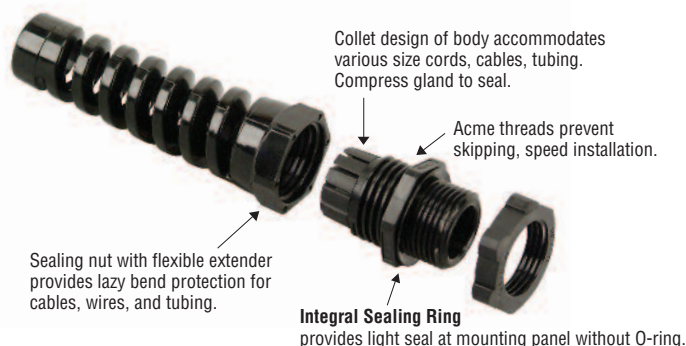

**Consult Heyco for Wrenching Nut Thickness "D"

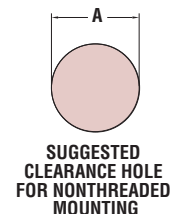

*Quick
Specs*

Material
Certifications

- Nylon 6/6 w/Buna N or TPE Sealing Gland
- Listed under Underwriters' Laboratories File E51579
- Recognized under Components Program of Underwriters' Laboratories File E51579
- Certified by Canadian Standards Association File 93876C
- Approved for NEMA 4, 4X, 6 and 6P Applications
- VDE Marks License #40010390
- Per CE Low Voltage Directive 73/23/EEC

Flammability Rating
Temperature Range

94V-2
Static -40°F (-40°C) to 239°F (115°C)
Dynamic -4°F (-20°C) to 212°F (100°C)

IP Rating

IP 68 (70 PSI, 5 BAR)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M4396](#) [M4398](#) [M4406](#) [M4424](#) [M4432](#) [M4410](#) [M4428](#) [M4434](#) [M4426](#) [M4402](#) [M4423](#) [M4436](#) [M3270](#) [M4430](#)
[M4397](#) [M4427](#) [M4403](#) [M4411](#) [M4422](#) [M4425](#) [M4433](#) [M4407](#) [M4400](#) [M4409](#) [M3271](#) [M4429](#) [M4431](#) [M4435](#)
[M4399](#) [M4408](#) [M4437](#) [M4405](#) [M4401](#) [M4404](#)