

HEYCO

**NO O-RING
REQUIRED!**



Heyco® -Tite Liquid Tight Cordgrips

Right Angle, PG Hubs with Integral Sealing Ring


The Ultimate in Liquid Tight Strain Relief Protection

Patented Fold Over Design

- Cordgrip is molded in the open position for ease of installation. After cable insertion, the cordgrip snaps closed, bending the cable without damage. This assembly method saves considerable time and money.
- Part design provides liquid tight integrity even in the open position.
- Integral Sealing Ring ensures a superior seal at the clearance or threaded mounting hole location, every time.
- Widest range of approved cable dimensions.
- IP 68 rated.
- Approved for **NEMA 4, 4X, 6 and 6P** applications.
- Acme threads on body prevent skipping and speed installation.
- All nylon construction with Buna N or TPE sealing gland resists salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents. (This feature is not assessed by UL.)
- We recommend using the fitting with the smallest maximum diameter that will fit your application.
- **Patented.**
- **Unassembled Nylon Locknuts INCLUDED.**
- For Heyco Liquid Tight Threaded Plugs, see page 3-49.
- Consult Heyco for cordgrips molded in other colors.

CABLE DIA. RANGE		PART NO.		DESCRIPTION	UL or ENEC	PART DIMENSIONS									
in.	mm.	Black	Gray			A Clearance Hole Dia.	B Right Angle Height	C Max O.A. Length (Closed)	D Thread Length	E Sealing Nut Length	F Wrenching Nut Flat Size				
						in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
.065 - .210	1,7 - 5,3	M8530	M8531	RLTCG 7 90											
.115 - .250	2,9 - 6,4	M8532	M8533	LTCG 7 90	UL	.492	12,5	.69	17,5	1,53	38,8	.32	8,1	.86	21,8
.065 - .230	1,7 - 5,8	M8534	M8535	RLTCG 9 90											
.105 - .315	2,7 - 8,0	M8536	M8537	LTCG 9 90	UL	.599	15,2	.88	22,3	1,77	44,9	.32	8,1	1,07	27,1
.069 - .260	1,8 - 6,6	M8538	M8539	RLTCG 11 90											
.230 - .400	5,8 - 10,2	M8540	M8541	LTCG 11 90	UL	.733	18,6	.99	25,1	2,01	51,0	.38	9,7	1,23	31,2
.095 - .290	2,4 - 7,4	M4542	M4543	RLTCG 13.5 90											
.170 - .450	4,3 - 11,4	M8542	M8543	LTCG 13.5 90	UL	.804	20,4	1,06	26,9	2,21	56,1	.41	10,4	1,38	35,1

Standard colors black and gray.

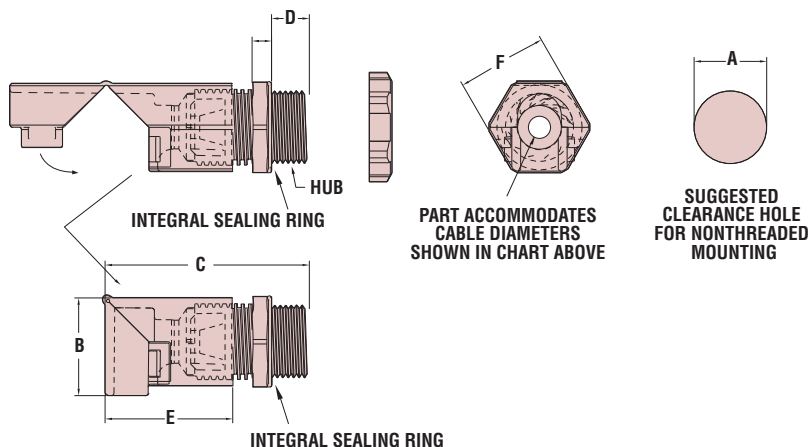

*Quick
Specs*

Material	Nylon 6/6 w/Buna N or TPE Sealing Gland
Certifications	<ul style="list-style-type: none"> UL Listed under Underwriters' Laboratories File E51579 Recognized under Components Program of Underwriters' Laboratories File E51579 CSA Certified by Canadian Standard Association File 93876C
Flammability Rating	94V-2
Temperature Range	Static -40°F (-40°C) to 239°F (115°C) Dynamic -4°F (-20°C) to 212°F (100°C)
IP Rating	IP 68 (70 PSI, 5 BAR)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M8540](#) [M8536](#) [M8532](#) [M8530](#) [M4542](#) [M8534](#) [M8543](#) [M8542](#) [M8541](#) [M8538](#) [M4543](#) [M8535](#) [M8533](#) [M8531](#)
[M8537](#) [M8539](#)