

HEYCO

**NO O-RING
REQUIRED!**



Heyco® -Tite Liquid Tight Cordgrips

Pigtail™, Metric Hubs with Integral Sealing Ring

The Ultimate in Liquid Tight Strain Relief Protection



- Flexible Pigtail extender prevents sharp bends and extends cable life.
- Integral Sealing Ring ensures a superior seal at the clearance or threaded mounting hole location, every time.
- Widest range of approved cable diameters.
- IP 68 rated.
- Approved for **NEMA 4, 4X, 6 and 6P** applications.
- Ratchet design of sealing nut assembly provides superior anti-vibration protection and ensures a firm grip on the cable.
- Acme threads on body prevent skipping and speed installation.
- All nylon construction with Buna N or TPE sealing gland resists salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents. (This feature is not assessed by UL.)
- Multiple sizes for flexible cord diameters ranging from .065" (1,7 mm) to .705" (17,9 mm).
- We recommend using the fitting with the smallest maximum diameter that will fit your application.
- **Unassembled Nylon Locknuts INCLUDED.**
- For Heyco Liquid Tight Threaded Plugs, see page 3-49.
- Consult Heyco for cordgrips molded in other colors.

CABLE DIA. RANGE				PART NO.			DESCRIPTION	UL or ENEC	PART DIMENSIONS							
Minimum	Maximum			Including Nylon Nut*	No Nut Black††	Gray			A	B	C	E				
in.	mm.	in.	mm.	Black					Clearance Hole Dia.	Max. O.A. Length	Thread Length	Wrenching Nut Flats				
									in.	mm.	in.	mm.	in.	mm.	in.	mm.
.065	1,7	.210	5,3	M4396	M4397	M4422	Flex RLTCG M12	UL	.473	12,0	2.44	62,0	.32	8,1	.63	16,0
.115	2,9	.250	6,4	M4398	M4399	M4424	Flex LTCG M12	UL	.630	16,0	2.77	70,4	.32	8,1	.82	20,8
.065	1,7	.230	5,8	M4400	M4401	M4426	Flex RLTCG M16	UL	.630	16,0	2.77	70,4	.32	8,1	.82	20,8
.105	2,7	.315	8,0	M4402	M4403	M4428	Flex LTCG M16	UL	.630	16,0	2.77	70,4	.32	8,1	.82	20,8
.095	2,4	.290	7,4	M4404	M4405	M4430	Flex RLTCG M20	UL	.787	20,0	3.89	98,8	.41	10,4	.98	24,9
.170	4,3	.450	11,4	M4406	M4407	M4432	Flex LTCG M20	UL	.787	20,0	3.89	98,8	.41	10,4	.98	24,9
.260	6,6	.545	13,8	M3270	M3271	-	Flex LTCG LL M20	UL	.787	20,0	4.34	110,2	.41	10,4	1.06	26,9
.250	6,4	.490	12,4	M4408	M4409	M4434	Flex RLTCG M25	UL	.985	25,0	5.04	128,0	.52	13,2	1.30	33,0
.435	11,1	.705	17,9	M4410	M4411	M4436	Flex LTCG M25	UL	.985	25,0	5.04	128,0	.52	13,2	1.30	33,0


Standard colors black and gray.

*Nylon locknuts shipped unassembled

††For No Nut Part Nos. in gray color please visit our Cordgrip product section at heyco.com

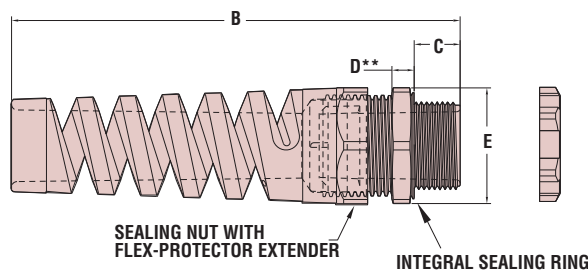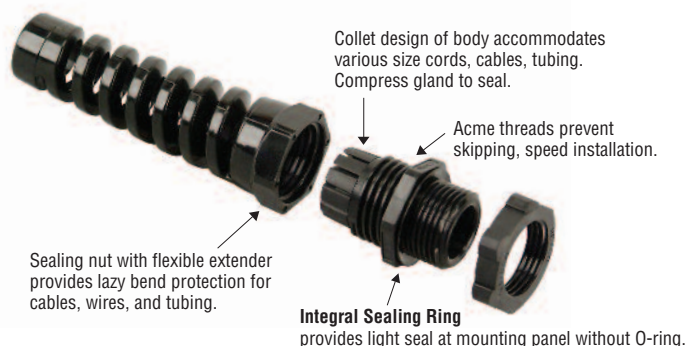

**Consult Heyco for Wrenching Nut Thickness "D"

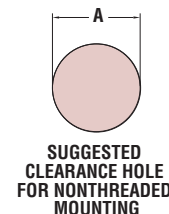

**SUGGESTED
CLEARANCE HOLE
FOR NONTHREADED
MOUNTING**

*Quick
Specs*

Material
Certifications

- Nylon 6/6 w/Buna N or TPE Sealing Gland
- Listed under Underwriters' Laboratories File E51579
- Recognized under Components Program of Underwriters' Laboratories File E51579
- Certified by Canadian Standards Association File 93876C
- Approved for NEMA 4, 4X, 6 and 6P Applications
- VDE Marks License #40010390
- Per CE Low Voltage Directive 73/23/EEC

Flammability Rating
Temperature Range

94V-2
Static -40°F (-40°C) to 239°F (115°C)
Dynamic -4°F (-20°C) to 212°F (100°C)

IP Rating

IP 68 (70 PSI, 5 BAR)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M4396](#) [M4398](#) [M4406](#) [M4424](#) [M4432](#) [M4410](#) [M4428](#) [M4434](#) [M4426](#) [M4402](#) [M4423](#) [M4436](#) [M4430](#) [M4397](#)
[M4427](#) [M4403](#) [M4411](#) [M4422](#) [M4425](#) [M4433](#) [M4407](#) [M4400](#) [M4409](#) [M4429](#) [M4431](#) [M4435](#) [M4399](#) [M4408](#)
[M4437](#) [M4405](#) [M4401](#) [M4404](#)