


Heyco® Nylon PCB Supports - Imperial Spacing

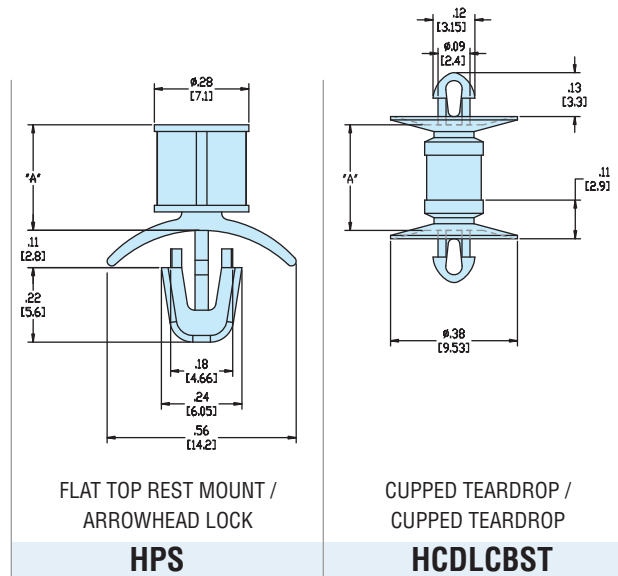

	Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	flat top rest mount				.062	1,6	.098	2,5
Chassis	.078	2,0	.187	4,8	.062	1,6	.098	2,5
A	PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in. mm.	Natural				Natural*			
.187 4,8	10233		HPS-03		10836		HCDLCBST-03	
.250 6,4	10234		HPS-04		10837		HCDLCBST-04	
.312 7,9	10235		HPS-05		10838		HCDLCBST-05	
.375 9,5	10236		HPS-06		10839		HCDLCBST-06	
.437 11,1	10237		HPS-07		10840		HCDLCBST-07	
.500 12,7	10238		HPS-08		10841		HCDLCBST-08	
.562 14,3					10842		HCDLCBST-09	
.625 15,9	10239		HPS-10		10843		HCDLCBST-10	
.750 19,1	10240		HPS-12					
.875 22,2	10241		HPS-14					

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Consult Heyco for HCDLCBST in V-0 material.

Material: Nylon 6/6
 Flammability Rating: 94V-2
 Temperature Range: .4°F (-18°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10234F](#) [10236F](#) [10235F](#) [10240F](#) [10233F](#) [10237F](#) [10239F](#) [10241F](#) [10238F](#)