




Heyco® Nylon PCB Supports - Imperial Spacing

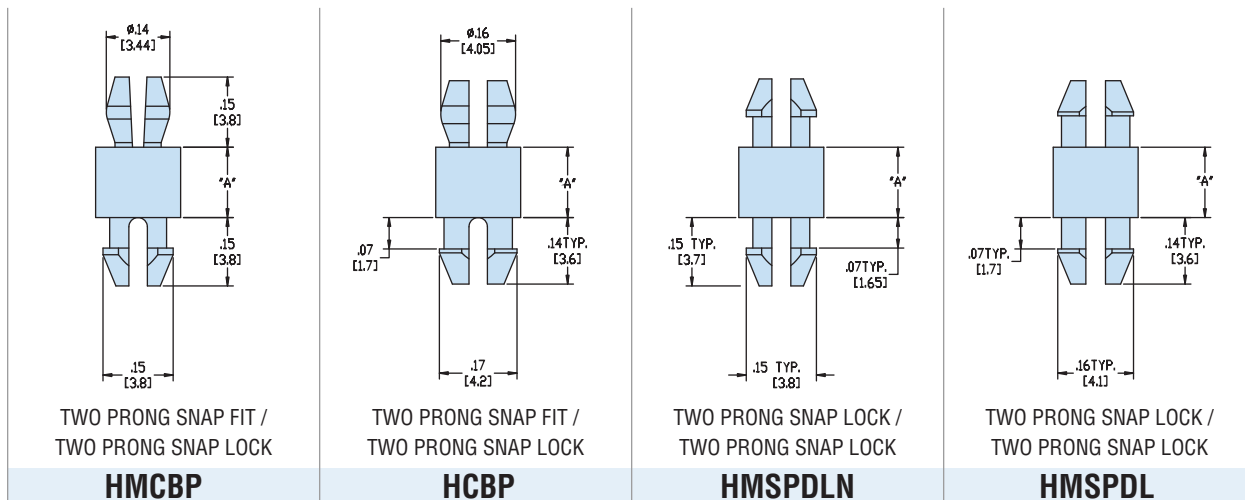

	Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	.062	1,6	.125	3,2	.062	1,6	.153	3,9	.062	1,6	.125	3,2	.062	1,6	.153	3,9
Chassis	.062	1,6	.125	3,2	.062	1,6	.153	3,9	.062	1,6	.125	3,2	.062	1,6	.153	3,9

A		PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION
in.	mm.								
.063	1,6	10243	HMCBP-01						
.125	3,2	10244	HMCBP-02	10263	HCBP-02	10282	HMSPDLN-02	10301	HMSPDL-02
.187	4,8	10245	HMCBP-03	10264	HCBP-03	10283	HMSPDLN-03	10302	HMSPDL-03
.250	6,4	10246	HMCBP-04	10265	HCBP-04	10284	HMSPDLN-04	10303	HMSPDL-04
.312	7,9	10247	HMCBP-05	10266	HCBP-05	10285	HMSPDLN-05	10304	HMSPDL-05
.375	9,5	10248	HMCBP-06	10267	HCBP-06	10286	HMSPDLN-06	10305	HMSPDL-06
.437	11,1	10249	HMCBP-07	10268	HCBP-07	10287	HMSPDLN-07	10306	HMSPDL-07
.500	12,7	10250	HMCBP-08	10269	HCBP-08	10288	HMSPDLN-08	10307	HMSPDL-08
.562	14,3	10251	HMCBP-09	10270	HCBP-09	10289	HMSPDLN-09	10308	HMSPDL-09
.625	15,9	10252	HMCBP-10	10271	HCBP-10	10290	HMSPDLN-10	10309	HMSPDL-10
.689	17,5	10253	HMCBP-11	10272	HCBP-11	10291	HMSPDLN-11	10310	HMSPDL-11
.750	19,1	10254	HMCBP-12	10273	HCBP-12	10292	HMSPDLN-12	10311	HMSPDL-12
.811	20,6	10255	HMCBP-13	10274	HCBP-13	10293	HMSPDLN-13	10312	HMSPDL-13
.875	22,2	10256	HMCBP-14	10275	HCBP-14	10294	HMSPDLN-14	10313	HMSPDL-14
1.000	25,4	10257	HMCBP-16	10276	HCBP-16	10295	HMSPDLN-16	10314	HMSPDL-16
1.125	28,6	10258	HMCBP-18	10277	HCBP-18	10296	HMSPDLN-18	10315	HMSPDL-18
1.250	31,8	10259	HMCBP-20	10278	HCBP-20	10297	HMSPDLN-20	10316	HMSPDL-20
1.375	34,9	10260	HMCBP-22	10279	HCBP-22	10298	HMSPDLN-22	10317	HMSPDL-22
1.500	38,1	10261	HMCBP-24	10280	HCBP-24	10299	HMSPDLN-24	10318	HMSPDL-24

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

Quick
Specs

Material Nylon 6/6
Flammability Rating 94V-2
Temperature Range .4°F (-18°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

<u>10280F</u>	<u>10259F</u>	<u>10256F</u>	<u>10302F</u>	<u>10286F</u>	<u>10301F</u>	<u>10282F</u>	<u>10285F</u>	<u>10284F</u>	<u>10308F</u>	<u>10267F</u>	<u>10244F</u>	<u>10304F</u>
<u>10243F</u>	<u>10283F</u>	<u>10287F</u>	<u>10250F</u>	<u>10248F</u>	<u>10289F</u>	<u>10310F</u>	<u>10246F</u>	<u>10303F</u>	<u>10305F</u>	<u>10265F</u>	<u>10263F</u>	<u>10288F</u>
<u>10290F</u>	<u>10271F</u>	<u>10296F</u>	<u>10245F</u>	<u>10249F</u>	<u>10266F</u>	<u>10311F</u>	<u>10313F</u>	<u>10306F</u>	<u>10258F</u>	<u>10270F</u>	<u>10315F</u>	<u>10278F</u>
<u>10312F</u>	<u>10316F</u>	<u>10295F</u>	<u>10294F</u>	<u>10293F</u>	<u>10291F</u>	<u>10254F</u>	<u>10264F</u>	<u>10299F</u>	<u>10314F</u>	<u>10268F</u>	<u>10309F</u>	<u>10269F</u>
<u>10252F</u>	<u>10307F</u>	<u>10247F</u>	<u>10253F</u>	<u>10317F</u>	<u>10251F</u>	<u>10272F</u>	<u>10297F</u>	<u>10292F</u>	<u>10260F</u>	<u>10255F</u>	<u>10318F</u>	<u>10279F</u>
<u>10277F</u>	<u>10273F</u>	<u>10257F</u>	<u>10275F</u>	<u>10276F</u>	<u>10261F</u>	<u>10298F</u>	<u>10274F</u>					