




Heyco® Nylon PCB Supports - Reverse Locking

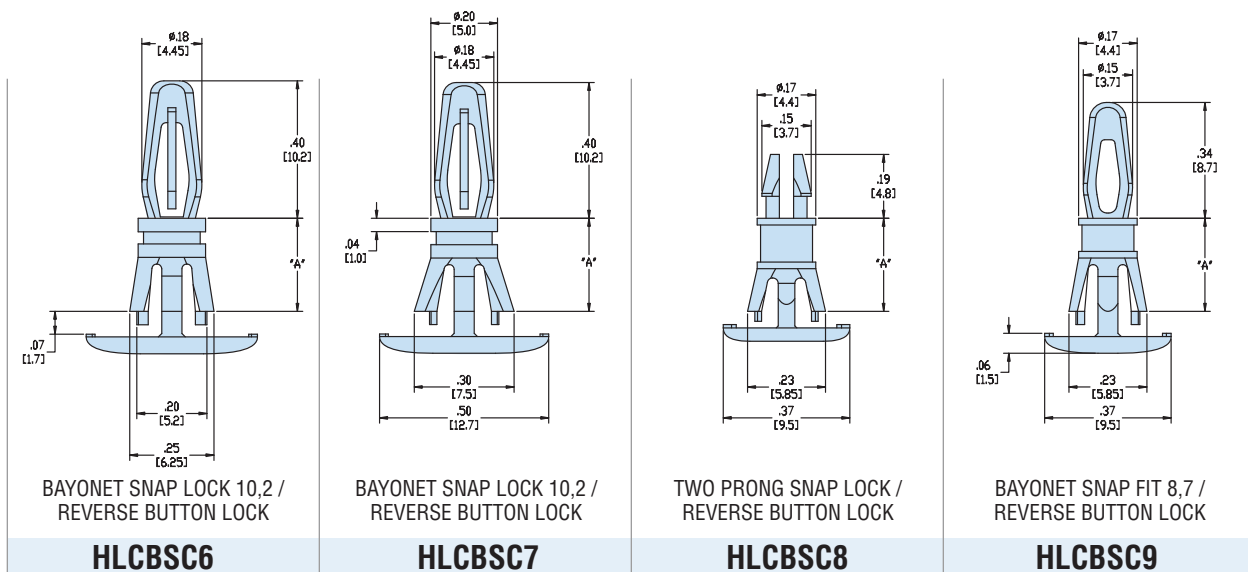

		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB		.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.125	3,2	.062	1,6	.125	3,2
Chassis		.065	1,7	.212	5,4	.065	1,7	.250	6,4	.062	1,6	.187	4,8	.062	1,6	.187	4,8

A		PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION
in.	mm.								
.250	6,4	10387	HLCBSC6-04	10392	HLCBSC7-04	10397	HLCBSC8-04	10405	HLCBSC9-04
.312	7,9					10398	HLCBSC8-05	10406	HLCBSC9-05
.375	9,5	10388	HLCBSC6-06	10393	HLCBSC7-06	10399	HLCBSC8-06	10407	HLCBSC9-06
.437	11,1					10400	HLCBSC8-07	10408	HLCBSC9-07
.500	12,7	10389	HLCBSC6-08	10394	HLCBSC7-08	10401	HLCBSC8-08	10409	HLCBSC9-08
.562	14,3					10402	HLCBSC8-09	10410	HLCBSC9-09
.625	15,9	10390	HLCBSC6-10	10395	HLCBSC7-10	10403	HLCBSC8-10	10411	HLCBSC9-10

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.



Material Nylon 6/6
Flammability Rating 94V-2
Temperature Range .4°F (-18°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10405F](#) [10394F](#) [10392F](#) [10409F](#) [10389F](#) [10406F](#) [10387F](#) [10401F](#) [10410F](#) [10400F](#) [10402F](#) [10393F](#) [10397F](#)
[10403F](#) [10398F](#) [10399F](#) [10407F](#) [10411F](#) [10395F](#) [10388F](#) [10390F](#) [10408F](#)