




Heyco® Nylon PCB Supports - Reverse Locking

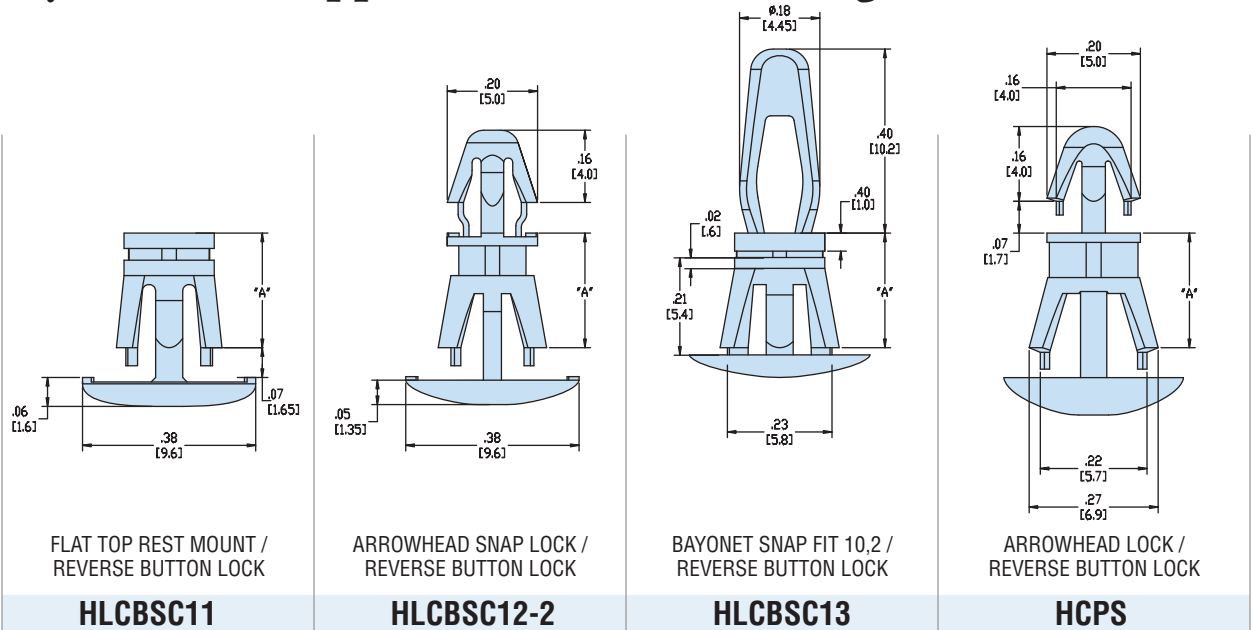

		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB		flat top rest mount				.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
Chassis		.062	1,6	.212	5,4	.078	2,0	.212	5,4	.047	1,2	.236	6,0	.062	1,6	.216	5,5
A		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in.	mm.	Natural*				Natural				Natural				Natural			
.187	4,8	10413	HLCBSC11-06	10420	HLCBSC12-2-06			10426	HLCBSC13-03			10845	HCPS-05				
.250	6,4																
.312	7,9																
.375	9,5																
.488	12,4	10414	HLCBSC11-7.8	10421	HLCBSC12-2-08			10430	HLCBSC13-08			10847	HCPS-08				
.500	12,7	10415	HLCBSC11-08														
.625	15,9	10416	HLCBSC11-10														
.750	19,1	10417	HLCBSC11-12														
.875	22,2	10418	HLCBSC11-14	10424	HLCBSC12-2-14							10850	HCPS-14				
1.000	25,4											10851	HCPS-16				
1.125	28,6											10852	HCPS-18				
1.250	31,8											10853	HCPS-20				
1.375	34,9											10854	HCPS-22				
1.500	38,1											10855	HCPS-24				

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Consult Heyco for HLCBSC11 in V-0 material.

Quick
Specs

Material Nylon 6/6
Flammability Rating 94V-2
Temperature Range .4°F (-18°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10424F](#) [10423F](#) [10421F](#) [10422F](#) [10420F](#)