



Heyco® Nylon PCB Supports - Metric Reverse Locking

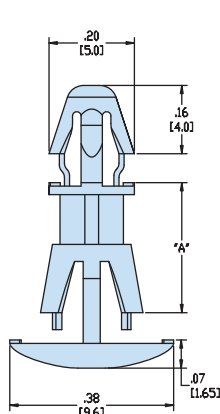

ARROWHEAD SNAP LOCK /
REVERSE BUTTON LOCK

HLCBSC

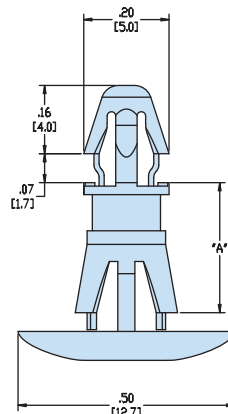

ARROWHEAD SNAP LOCK /
REVERSE BUTTON LOCK

HLCBSC10



	Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	.062	1,6	.157	4,0	.062	1,6	.157	4,0
Chassis	.062	1,6	.212	5,4	.062	1,6	.212	5,4
A mm.	PART NO. Natural		DESCRIPTION		PART NO. Natural		DESCRIPTION	
6,0	10433		HLCBSC-06M					
8,0	10434		HLCBSC-08M		10439	HLCBSC10-08M		
10,0	10435		HLCBSC-10M		10440	HLCBSC10-10M		
12,0	10436		HLCBSC-12M		10441	HLCBSC10-12M		
14,0	10437		HLCBSC-14M		10442	HLCBSC10-14M		

Standard color natural. For special order parts in UL 94V-0 material, add the suffix “F” to Part No.

Material: Nylon 6/6
Flammability Rating: 94V-2
Temperature Range: -40°F (-40°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10439](#) [10437](#) [10435](#) [10436](#) [10434](#) [10433](#) [10442](#) [10440](#) [10441](#)