





Heyco® Nylon PCB Supports - Blind, Key Slot & Rivet Mount

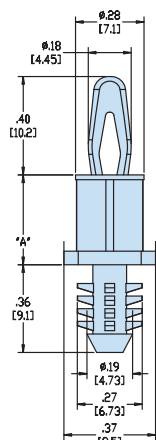


BAYONET SNAP FIT 10,2 /
BLIND FIR TREE

HBS5

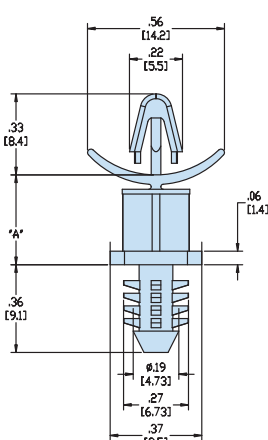


ARROWHEAD SNAP LOCK /
BLIND FIR TREE

HBS6

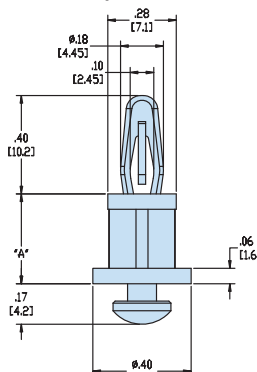

BAYONET SNAP LOCK 10,2 /
KEY SLOT BUTTON

HKSLBN - Key Slot

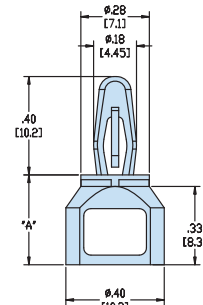


BAYONET SNAP LOCK 10,2 /
RIVET

HRLSP - Rivet

		Minimum Thickness		Mounting Hole Diameter		Minimum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Slot Width		Maximum Thickness		Mounting Hole Diameter	
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB		.062	1,6	.157	4,0	.078	2,0	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
Chassis		.250	6,4	.250	6,4	.250	6,4	.250	6,4	.062	1,6	see diagram		see table		.165	4,2
A		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in.	mm.	Natural				Natural				Natural				Natural			
.125	3,2									10611		HKSLBN-02					
.187	4,8	10587		HBS5-03													
.250	6,4	10588		HBS5-04		10596		HBS6-04		10612		HKSLBN-04					
.375	9,5	10589		HBS5-06		10597		HBS6-06		10613		HKSLBN-06		10603		HRLSP-06	
.437	11,1	10590		HBS5-07										10604		HRLSP-07	
.500	12,7	10591		HBS5-08		10598		HBS6-08		10614		HKSLBN-08		10605		HRLSP-08	
.625	15,9	10592		HBS5-10		10599		HBS6-10						10606		HRLSP-10	
.750	19,1	10593		HBS5-12		10600		HBS6-12						10607		HRLSP-12	
.875	22,2	10594		HBS5-14		10601		HBS6-14						10608		HRLSP-14	
1.000	25,4													10609		HRLSP-16	

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

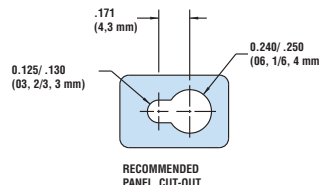

Rivet Table for HRLSP

PART NO.	PANEL THICKNESS	
	in.	mm.
Black		
9058	.03 - .06	0,7 - 1,6
9060	.06 - .11	1,6 - 2,7
9062	.11 - .15	2,7 - 3,7
9064	.15 - .19	3,7 - 4,7
9068	.22 - .26	5,7 - 6,7

Rivet applied from
Chassis side.

Material: Nylon 6/6
Flammability Rating: 94V-2
Temperature Range: .4°F (-18°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10601F](#) [10608F](#) [10607F](#) [10591F](#) [10605F](#) [10603F](#) [10587F](#) [10590F](#) [10600F](#) [10594F](#) [10597F](#) [10588F](#) [10604F](#)
[10598F](#) [10599F](#) [10596F](#) [10593F](#) [10606F](#) [10589F](#) [10592F](#) [10609F](#)