





Heyco® Nylon PCB Supports - Self-Retaining Spacers

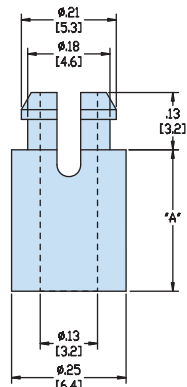


TWO PRONG SNAP LOCK /
#4 or M3 SELF-TAPPING SCREW

HSRS4

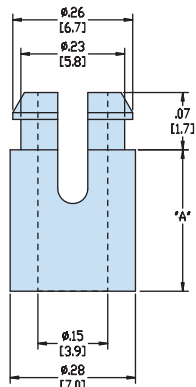

TWO PRONG SNAP LOCK /
#6 or M3 SELF-TAPPING SCREW

HSRS6

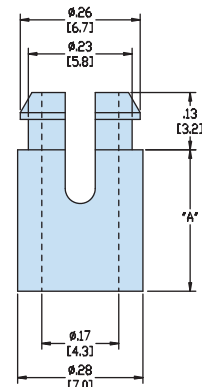

TWO PRONG SNAP LOCK /
#8 or M4 SELF-TAPPING SCREW

HSRS8

		Maximum Thickness †		Mounting Hole Diameter		Maximum Thickness †		Mounting Hole Diameter		Maximum Thickness †		Mounting Hole Diameter	
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB		.062	1,6	.187	4,7	.062	1,6	.232	5,9	.062	1,6	.232	5,9
Chassis		self-tapping			M3	self-tapping			M3	self-tapping			M4
A		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in.	mm.	Natural				Natural				Natural			
.125	3,2	10627		HSRS4-02									
.187	4,8	10628		HSRS4-03									
.250	6,4	10629		HSRS4-04		10639		HSRS6-04		10649		HSRS8-04	
.312	7,9	10630		HSRS4-05		10640		HSRS6-05		10650		HSRS8-05	
.375	9,5	10631		HSRS4-06		10641		HSRS6-06		10651		HSRS8-06	
.437	11,1	10632		HSRS4-07		10642		HSRS6-07		10652		HSRS8-07	
.500	12,7	10633		HSRS4-08		10643		HSRS6-08		10653		HSRS8-08	
.625	15,9	10634		HSRS4-10		10644		HSRS6-10		10654		HSRS8-10	
.750	19,1	10635		HSRS4-12		10645		HSRS6-12		10655		HSRS8-12	
.875	22,2	10636		HSRS4-14		10646		HSRS6-14		10656		HSRS8-14	
1.000	25,4	10637		HSRS4-16		10647		HSRS6-16		10657		HSRS8-16	

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix “F” to Part No.

†Thread depth at Chassis end. For HSRS4, -6 and -8, thread depth = “A” dimension

Material: Nylon 6/6
Flammability Rating: 94V-2
Temperature Range: .4°F (-18°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10644F](#) [10653F](#) [10652F](#) [10656F](#) [10646F](#) [10657F](#) [10639F](#) [10651F](#) [10649F](#) [10641F](#) [10629F](#) [10630F](#) [10636F](#)
[10635F](#) [10633F](#) [10628F](#) [10637F](#) [10650F](#) [10634F](#) [10631F](#) [10647F](#) [10655F](#) [10643F](#) [10654F](#) [10645F](#) [10642F](#)
[10627F](#) [10632F](#) [10640F](#)