




Heyco® Nylon PCB Supports - Screw and Lock

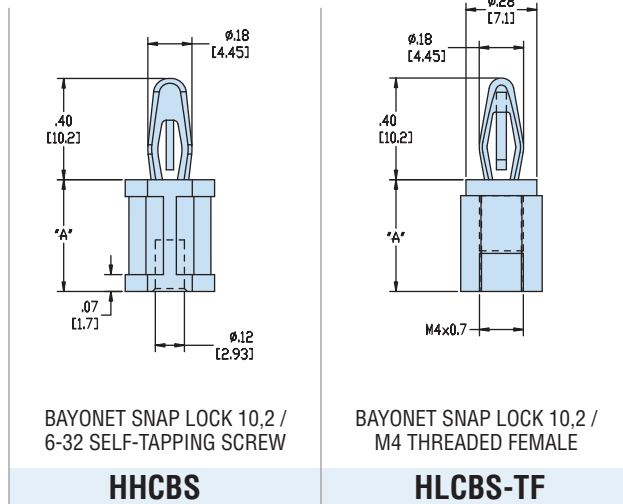

BAYONET SNAP LOCK 10,2 /
6-32 SELF-TAPPING SCREW

BAYONET SNAP LOCK 10,2 /
M4 THREADED FEMALE

HHCBS

HLCBS-TF

	Maximum Thickness*		Mounting Hole Diameter			Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.		in.	mm.	in.	mm.
PCB	.062	1,6	.157	4,0		.062	1,6	.157	4,0
Chassis	.312	7,9	6-32			threaded			M4


A		PART NO. Natural	DESCRIPTION	PART NO. Natural**	DESCRIPTION
in.	mm.				
.250	6,4	10616	HHCBS-04 †		
.375	9,5	10617	HHCBS-06	10829	HLCBS-TF-M4-06
.500	12,7	10618	HHCBS-08	10830	HLCBS-TF-M4-08
.625	15,9	10619	HHCBS-10	10831	HLCBS-TF-M4-10
.750	19,1	10620	HHCBS-12	10832	HLCBS-TF-M4-12
.875	22,2	10621	HHCBS-14	10833	HLCBS-TF-M4-14
1.000	25,4	10622	HHCBS-16	10834	HLCBS-TF-M4-16
1.125	28,6	10623	HHCBS-18		
1.250	31,8	10624	HHCBS-20		
1.406	35,7	10625	HHCBS-22.5		

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Refers to thread depth at chassis which is .312" (7,9 mm)

**Consult Heyco for HLCBS-TF in V-0 material

†Thread depth is .20" (5,2 mm)

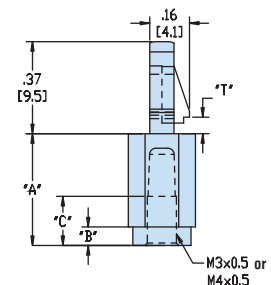

BAYONET SNAP LOCK 9,5 /
METRIC THREADED FEMALE

HTCBS Series

	Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.
PCB	varies		.157	4,0
Chassis	screw*			M3, M4

A		PART NO. Black	DESCRIPTION
mm.	mm.		

HTCBS-M3-6 mm Hex

8,0	1,6	10659	HTCBS-M3-6-8
10,0	1,6	10660	HTCBS-M3-6-10
15,0	1,6	10661	HTCBS-M3-6-15
20,0	1,7	10662	HTCBS-M3-6-20

HTCBS-M3-8 mm Hex

8,0	1,6	10664	HTCBS-M3-8-8
23,0	1,6	10665	HTCBS-M3-8-23

HTCBS-M4-8 mm Hex

10,0	1,6	10667	HTCBS-M4-8-10
12,0	1,7	10668	HTCBS-M4-8-12
15,0	1,6	10669	HTCBS-M4-8-15
30,0	1,6	10670	HTCBS-M4-8-30-16
	1,7	10671	HTCBS-M4-8-30-17
	2,1	10672	HTCBS-M4-8-30-21
35,0	2,1	10673	HTCBS-M4-8-35
70,0	1,6	10674	HTCBS-M4-8-70

Standard color black.

*Shoulder and thread depths vary, consult Heyco.

Quick
Specs

Material	Nylon 6/6
Flammability Rating	94V-2
Temperature Range	.4°F (-18°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10618F](#) [10621F](#) [10617F](#) [10619F](#) [10616F](#) [10620F](#) [10623F](#) [10622F](#) [10624F](#) [10625F](#)