





Heyco® Nylon PCB Supports - Threaded Male

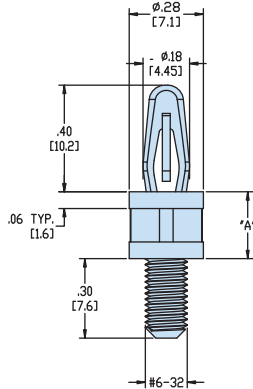


BAYONET SNAP LOCK 10,2 /
6-32 MALE THREAD

HSCBS6

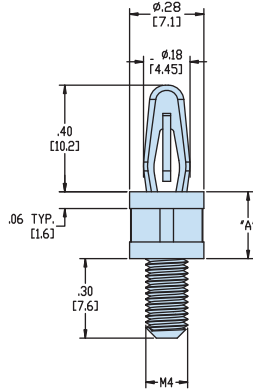


BAYONET SNAP LOCK 10,2 /
M4 MALE THREAD

HSCBS7

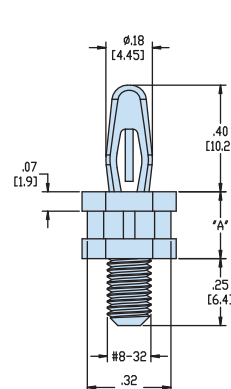

BAYONET SNAP LOCK 10,2 /
8-32 MALE THREAD

HSCBS8

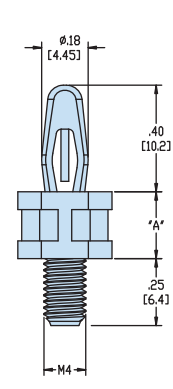

BAYONET SNAP LOCK 10,2 /
M4 MALE THREAD

HSCBS

	Maximum Thread Lg †		Mounting Hole Diameter		Maximum Thread Lg †		Mounting Hole Diameter		Maximum Thread Lg †		Mounting Hole Diameter		Maximum Thread Lg †		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
Chassis	.300	7,6	6-32		.300	7,6	M4		.250	6,4	8-32		.250	6,4	M4	

A	PART NO.	DESCRIPTION	PART NO.	DESCRIPTION	PART NO.	DESCRIPTION	PART NO.	DESCRIPTION
in.	Natural		Natural		Natural		Natural	
.250	10746	HSCBS6-04	10754	HSCBS7-04	10762	HSCBS8-04	10678	HSCBS-04
.375	10747	HSCBS6-06	10755	HSCBS7-06	10763	HSCBS8-06	10679	HSCBS-06
.500	10748	HSCBS6-08	10756	HSCBS7-08	10764	HSCBS8-08	10680	HSCBS-08
.625	10749	HSCBS6-10	10757	HSCBS7-10	10765	HSCBS8-10	10681	HSCBS-10
.750	10750	HSCBS6-12	10758	HSCBS7-12	10766	HSCBS8-12	10682	HSCBS-12
.812							10683	HSCBS-13
.875	10751	HSCBS6-14	10759	HSCBS7-14	10767	HSCBS8-14	10684	HSCBS-14
1.000	10752	HSCBS6-16	10760	HSCBS7-16	10768	HSCBS8-16	10685	HSCBS-16
1.125					10769	HSCBS8-18	10686	HSCBS-18
1.406					10770	HSCBS8-22.5	10687	HSCBS-22.5

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

†Thread length at Chassis

Quick
Specs

Material: Nylon 6/6
Flammability Rating: 94V-2
Temperature Range: .4°F (-18°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10683F](#) [10769F](#) [10757F](#) [10768F](#) [10686F](#) [10682F](#) [10763F](#) [10755F](#) [10754F](#) [10746F](#) [10762F](#) [10760F](#) [10748F](#)
[10749F](#) [10678F](#) [10747F](#) [10758F](#) [10767F](#) [10751F](#) [10764F](#) [10765F](#) [10681F](#) [10752F](#) [10756F](#) [10766F](#) [10759F](#)
[10687F](#) [10684F](#) [10679F](#) [10770F](#) [10750F](#) [10680F](#) [10685F](#)