



Heyco® Nylon PCB Supports - Edge Holding

▼ ALL NEW PRODUCTS! ▼

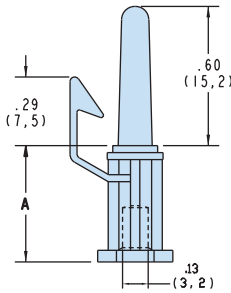


EDGE SNAP LOCK /
#6 SELF-TAPPING SCREW

HTEHCBS

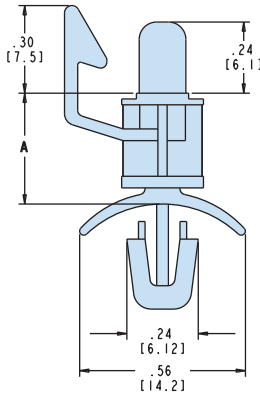


EDGE SNAP LOCK /
ARROWHEAD SNAP LOCK

HEHCBS-7

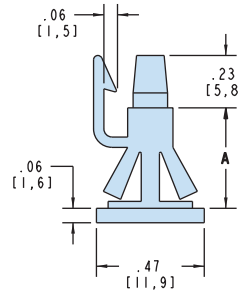

EDGE SNAP LOCK /
REVERSE RECTANGULAR LOCK

HRLEHCBS

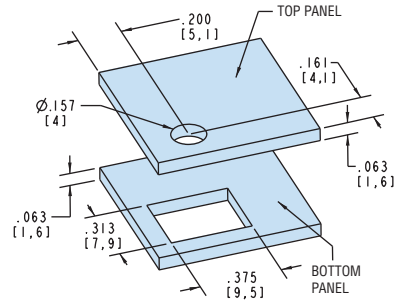

	Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
Chassis	Varies		#6 Screw		.078	2,0	.187	4,8	Varies		#6 Screw	
A	PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in. mm.	Natural*				Natural*				Black			
.250 6,4	10935		HTEHCBS-04		10825		HEHCBS-7-06		10885B 10886B		HRLEHCBS-05 HRLEHCBS-06	
.312 7,9	10936		HTEHCBS-05									
.375 9,5	10937		HTEHCBS-06									
.500 12,7	10939		HTEHCBS-08		10826		HEHCBS-7-14					
.625 15,9	10941		HTEHCBS-10									
.750 19,1	10942		HTEHCBS-12									
.875 22,2	10943		HTEHCBS-14									
1.000 25,4	10944		HTEHCBS-16									

Standard color as shown. *For special order parts in UL 94V-0 material, add the suffix "F" to Part No.

Material
Certifications

Nylon 6/6
Recognized under the Component Program of Underwriters' Laboratories File F197049

Flammability Rating
Temperature Range

94V-2
-40°F (-40°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10941](#) [10942](#) [10936](#) [10935](#) [10944](#) [10943](#) [10939](#) [10937](#) [10886B](#) [10885B](#) [10826](#) [10825](#)