




Heyco® Nylon Hose Clamps


EFFECTIVE CLAMP RANGE				PART NO.			DESCRIPTION	PART DIMENSIONS			
Minimum Diameter		Maximum Diameter		6/6 NYLON		GF* NYLON		A		B	
in.	mm.	in.	mm.	Black	White	Black		in.	mm.	in.	mm.
Regular Style											
.25	6,4	.31	7,9	—	—	2302	HC 250	.13	3,2	.04	1,0
.34	8,7	.41	10,3	2306	2307	2308	HC 344	.21	5,3	.07	1,8
.41	10,3	.47	11,9	2310	2311	2312	HC 406				
.47	11,9	.53	13,5	2314	2315	2316	HC 468				
.53	13,5	.59	15,1	2318	2319	2320	HC 531				
.59	15,1	.66	16,7	2322	2323	2324	HC 593				
.67	17,1	.81	20,6	2326	2327	2328	HC 672				
.75	19,1	.88	22,2	2330	2331	2332	HC 750				
.88	22,2	1.00	25,4	2334	2335	2336	HC 875				
.95	24,1	1.09	26,2	2338	2339	2340	HC 953				
1.03	26,2	1.19	30,2	2342	2343	2344	HC 1031				
1.25	31,8	1.44	36,5	2346	2347	2348	HC 1250	.31	7,9		
1.41	35,7	1.63	41,3	2350	2351	2352	HC 1406	.36	9,1		
1.59	40,4	1.81	46,0	2354	2355	2356	HC 1593				
1.69	42,9	1.91	48,4	2358	2359	2360	HC 1687				
1.88	47,6	2.13	54,0	2362	2363	2364	HC 1875	.40	10,2		
2.13	54,0	2.38	60,3	2366	2367	2368	HC 2.125				
Strap Mate Style											
2.25	57,1	2.88	73,0	-	-	2377	HC 2.25	.44	11,2	.08	2,0
2.75	69,8	3.63	92,1	-	-	2380	HC 2.75				
3.50	88,9	4.25	108,0	-	-	2383	HC 3.5				
4.00	101,6	5.00	127,0	-	-	2386	HC 4.0				

Standard colors 6/6 nylon black and white. Glass filled nylon standard color is black.

*HC 250 features a single tang design in glass-filled nylon only.

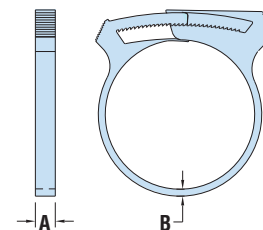

Regular Style

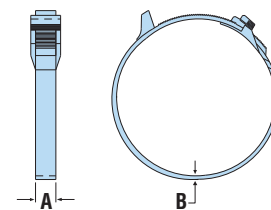

Strap Mate Style

Heyco® Pneumatic Air Tool for Nylon Hose Clamps

For Lockit and Regular Style Hose Clamps only

AIR TOOL PART NO. INCLUDING JAWS	JAW PART NO.*	
	Upper	Lower
0170	0T83	0T84

*Jaw Part No. if purchased separately.



- Allows for a **semi-automated process** which increases speed over manual tools.
- Activated by hand lever reducing stress on the hand and the risk of carpal tunnel syndrome associated with repetitive assembly.
- Maximum Pressure Rating: 125 psi
- Adjustable jaws allow tool to accommodate a wide range of Heyco Hose Clamps.
- Operates only when lever is depressed.
- Tool operates on standard shop air.

Materials	Nylon 6/6 or glass-filled Nylon
Flammability Rating	94V-2 for 6/6 Nylon, 94HB for glass-filled Nylon
Temperature Range	32°F (0°C) to 221°F(105°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[2363](#) [2366](#) [2362](#) [2364](#) [2380](#) [2386](#) [2377](#) [2368](#) [2383](#)