




## HEYClip™ Shorty Side Entry Cable Holders

### Arrowhead Mount

- For Top Entry Shorty Cable Holders, see page 7-53.
- Ideal when space is restricted and side entry is required.

| WIRE CAPACITY                                          |           | PART NO.<br>Natural | DESCRIPTION | PART DIMENSIONS |      |            |     |             |     | MOUNTING HOLE DIA. |     |
|--------------------------------------------------------|-----------|---------------------|-------------|-----------------|------|------------|-----|-------------|-----|--------------------|-----|
| in.                                                    | mm.       |                     |             | A<br>Length     |      | B<br>Width |     | C<br>Height |     |                    |     |
|                                                        |           |                     |             | in.             | mm.  | in.        | mm. | in.         | mm. | in.                | mm. |
| For Panels from .047" (1,2 mm) to .078" (2,0 mm) Thick |           |                     |             |                 |      |            |     |             |     |                    |     |
| .11 x .17                                              | 2,8 x 4,2 | 12130               | CH SE-1117  | .52             | 13,2 | .20        | 5,0 | .19         | 4,7 | .138               | 3,5 |
| .17 x .22                                              | 4,3 x 5,5 | 12131               | CH SE-1722  | .59             | 15,1 | .20        | 5,0 | .26         | 6,7 |                    |     |
| For Panels from .062" (1,6 mm) to .094" (2,4 mm) Thick |           |                     |             |                 |      |            |     |             |     |                    |     |
| .10 x .17                                              | 2,6 x 4,2 | 12133               | CH SE-1017  | .50             | 12,7 | .20        | 5,0 | .21         | 5,3 | .138               | 3,5 |

Standard color natural. Flame retardant UL 94V-0 material available, consult Heyco.

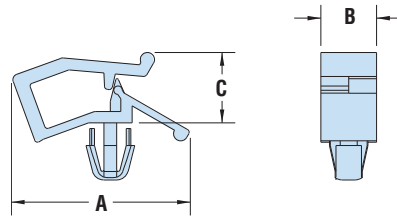


## HEYClip™ Ladder Cable Holders

### Adhesive Back Mount

- Adjustable design secures wire bundles.
- Applies simply to clean dry surface.

| MAXIMUM BUNDLE DIAMETER |      | PART NO.<br>Natural | DESCRIPTION | PART DIMENSIONS |      |            |      |                   |      | MOUNTING HOLE DIA. |     |
|-------------------------|------|---------------------|-------------|-----------------|------|------------|------|-------------------|------|--------------------|-----|
| in.                     | mm.  |                     |             | A<br>Length     |      | B<br>Width |      | C<br>Ladder Width |      | in.                | mm. |
| .47                     | 12,0 | 12360               | CH LAD-047  | .79             | 20,0 | .59        | 15,0 | .20               | 5,0  | .133               | 3,4 |
| .77                     | 19,5 | 12361               | CH LAD-077  |                 |      |            |      |                   |      |                    |     |
| .51                     | 13,0 | 12362               | CH LAD-051  | .98             | 25,0 | .71        | 18,0 | .31               | 8,0  | .138               | 3,5 |
| .67                     | 17,0 | 12363               | CH LAD-067  |                 |      |            |      |                   |      |                    |     |
| .73                     | 18,5 | 12364               | CH LAD-073  |                 |      |            |      |                   |      |                    |     |
| .87                     | 22,0 | 12365               | CH LAD-087  | 1.20            | 30,5 | .83        | 21,0 | .47               | 12,0 |                    |     |
| 1.02                    | 26,0 | 12367               | CH LAD-102  |                 |      |            |      |                   |      |                    |     |

Standard color natural.

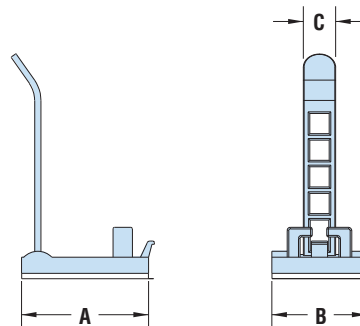

*Quick  
Specs*

|                     |                            |
|---------------------|----------------------------|
| Material            | Nylon 6/6                  |
| Flammability Rating | 94V-2                      |
| Temperature Range   | 32°F (0°C) to 185°F (85°C) |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[8912](#) [8908](#) [8916](#) [8964](#) [8968](#) [8972](#) [8966](#) [8974](#) [8970](#) [8928](#) [8924](#) [8975](#)