





HEYClip™ Shorty Snap Rivets

Two Piece Snap Together Rivets

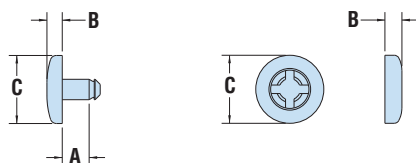


SSRP Series

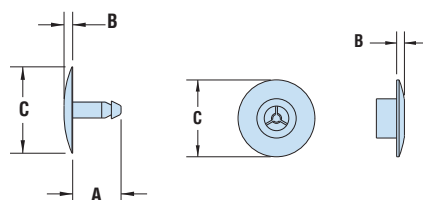


SSRPT Series



- Complete assembly requires two parts. They snap into each other, thus holding flat panels together.

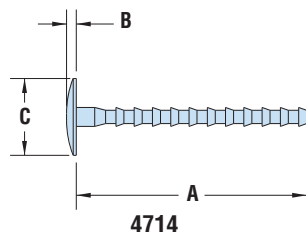

4714

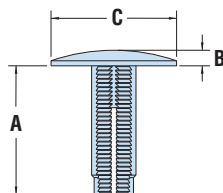

RR Series

WILL FIT THESE PANELS				PART NO.	DESCRIPTION	PART DIMENSIONS						STYLE
MOUNTING HOLE DIA.		ASSEMBLED PANEL THICKNESS				A Length	B Head Height	C Head Diameter				
in.	mm.	in.	mm.									
Natural						in.	mm.	in.	mm.	in.	mm.	

SSRP Series - Pin fits a .125" (3,2 mm) diameter hole

.125	3,2	.030	0,8	4064	SSRP-030	.06	1,6	.09	2,3	.40	10,2	1
		.062	1,6	4065	SSRP-062	.10	2,4					
		.100	2,5	4069	SSRP-100	.13	3,4					
		.125	3,2	4071	SSRP-125	.16	4,0					
		.187	4,8	4073	SSRP-187	.22	5,6					
		.250	6,4	4075	SSRP-250	.28	7,2					

FEMALE CAP for the above parts

				4077	SSRC	n/a		.10	2,5	.40	10,2	2
--	--	--	--	-------------	------	-----	--	-----	-----	-----	------	---

SSRPT Series - Cap fits a .320" (8,1 mm) diameter hole

.320	8,1	.170 - .190	4,3 - 4,8	4715	SSRPT-190	.21	5,3	.06	1,6	.40	10,2	3
		.220 - .240	5,6 - 6,1	4716	SSRPT-220	.26	6,6					
		.320 - .340	8,1 - 8,6	4717	SSRPT-340	.35	8,9					
		.320 - .600	8,1 - 15,2	4718	SSRPT-600	.63	16,0					
		ADJUSTABLE		4714	SSRPT-ADJ	1.50	38,1	.06	1,6	.50	12,7	4

FEMALE CAP for the above parts

				4719	SSRCT	n/a		.06	1,6	.63	15,9	5
--	--	--	--	-------------	-------	-----	--	-----	-----	-----	------	---

Standard color natural.

HEYClip™ Ratchet Rivets

WILL FIT THESE PANELS						PART NO.	DESCRIPTION	PART DIMENSIONS					
MOUNTING HOLE DIA.		ASSEMBLED PANEL THICKNESS						A Length	B Head Height	C Head Diameter			
		Min.		Max.									
in.	mm.	in.	mm.	in.	mm.						Natural		

RR Series

.281	7,1	.235	6,0	.297	7,5	12480	RR 0297-41	.23	5,7	.06	1,6	.41	10,3
		.345	8,8	.500	12,7	12481	RR 0500-41	.34	8,7				
		.500	12,7	.813	20,7	12482	RR 0813-41	.49	12,4				
		.780	19,8	1.375	34,9	12483	RR 1375-41	.77	19,5				
		.235	6,0	.298	7,6	12484	RR 0298-75	.23	5,7				
		.345	8,8	.500	12,7	12485	RR 0500-75	.34	8,7	.09	2,4	.75	19,1
		.500	12,7	.812	20,6	12486	RR 0812-75	.49	12,4				
		.780	19,8	1.375	34,9	12487	RR 1375-75	.77	19,5				

Standard color natural.

Material	Nylon 6/6
Flammability Rating	94 V-2
Temperature Range	32°F (0°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[G3016](#) [G3018](#) [G3017](#)