


**ALL NEW  
PRODUCTS!**




## Heyco® Fan Mounts


| PANEL DIMENSIONS     |         |                    |         | FAN DIMENSIONS     |         |           |            | PART    | DESCRIPTION | MAT'L              | PART DIMENSIONS       |     |     |      |      |      | Style |
|----------------------|---------|--------------------|---------|--------------------|---------|-----------|------------|---------|-------------|--------------------|-----------------------|-----|-----|------|------|------|-------|
| Max. Panel Thickness |         | Mounting Hole Dia. |         | Mounting Hole Dia. |         | Thickness |            |         |             |                    | A                     |     | B   |      | C    |      |       |
| in.                  | mm.     | in.                | mm.     | in.                | mm.     | in.       | mm.        |         |             |                    | in.                   | mm. | in. | mm.  | in.  | mm.  |       |
| FMS - Standard       |         |                    |         |                    |         |           |            |         |             |                    |                       |     |     |      |      |      |       |
| .055                 | 1,4     | .197               | 5,0     | .20                | 5,0     | .08       | 2,0        | 0345    | FMS-1       | EPDM 30            | .06                   | 1,5 | .07 | 1,9  | 1.27 | 32,3 | 1     |
|                      |         |                    |         |                    |         | 0346      | FMS-2      | EPDM 40 |             |                    |                       |     |     |      |      |      |       |
|                      |         |                    |         |                    |         | 0348      | FMS-3      | EPDM 30 |             |                    |                       |     |     |      |      |      |       |
|                      |         |                    |         |                    |         | .12       | 3,1        | 0349    | FMS-4       | EPDM 40            |                       |     |     |      |      |      |       |
| .031                 | 0,8     | .138               | 3,5     | .14                | 3,5     | .79       | 20,0       | 0354    | FMS-5       | Silicone Rubber 40 | .06                   | 1,5 | .73 | 18,5 | 2.20 | 56,0 | 3     |
| .118                 | 3,0     | .169               | 4,3     | .17                | 4,3     | .59       | 15,0       | 0355    | FMS-6       | Silicone Rubber 40 |                       |     |     |      |      |      |       |
| .031                 | 0,8     | .138               | 3,5     | .14                | 3,5     | .98-1.10  | 25,0-28,0  | 0356    | FMS-7       | Silicone Rubber 40 |                       |     |     |      |      |      |       |
|                      |         |                    |         |                    |         |           |            |         |             |                    |                       |     |     |      |      |      |       |
| FMM - Multi          |         |                    |         |                    |         |           |            |         |             |                    |                       |     |     |      |      |      |       |
| .039-.059            | 1,0-1,5 | .177-.189          | 4,5-4,8 | .13-.18            | 3,2-4,5 | .39-2.00  | 10,0-51,0  | 0357    | FMM-1       | Silicone Rubber 40 | see schematic drawing |     |     |      |      |      | 4     |
| FMB - Break-Away     |         |                    |         |                    |         |           |            |         |             |                    |                       |     |     |      |      |      |       |
| .031-.063            | 0,8-1,6 | .177-.197          | 4,5-5,0 | .16-.18            | 4,0-4,5 | .98-2.01  | 25,0-51,0  | 0359    | FMB-1       | Silicone Rubber 40 | see schematic drawing |     |     |      |      |      | 5     |
|                      |         |                    |         | .13-.14            | 3,2-3,5 | up to .40 | up to 10,0 | 0363    | FMB-2       | Silicone Rubber 40 | see schematic drawing |     |     |      |      |      | 6     |
|                      |         |                    |         | .16-.18            | 4,0-4,5 | up to .98 | up to 25,0 |         |             |                    |                       |     |     |      |      |      |       |

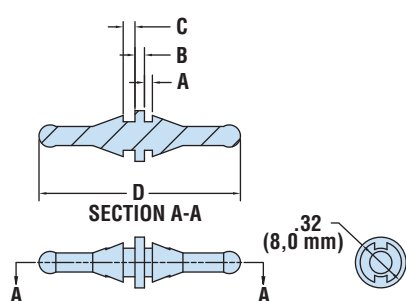


Style 1

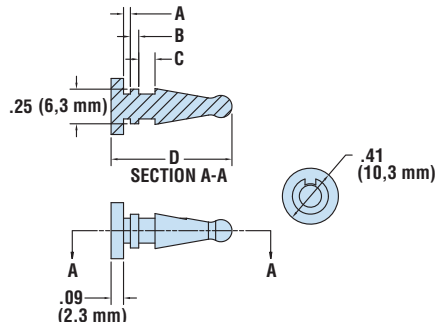


Style 2

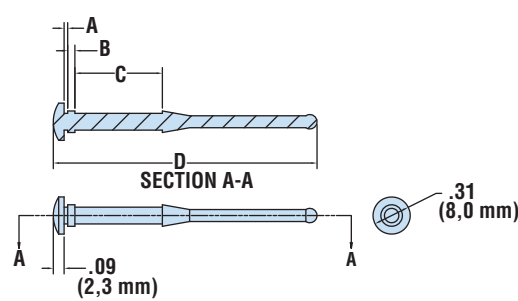


Style 3

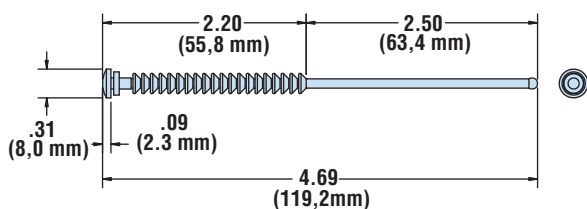

Style 4

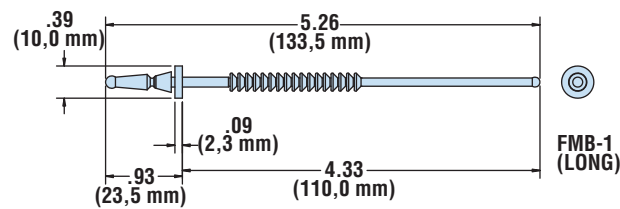

Style 5

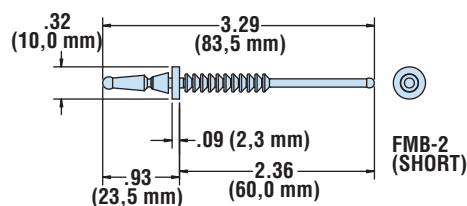

Style 6

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[0348](#) [0355](#) [0363](#) [0354](#) [0357](#) [0346](#) [0345](#) [0356](#) [0359](#)