




- Panels easily open when gently pushed in.
- Easy installation – snaps into hole in panel.
- Enables a single latch to accommodate multiple panel thicknesses.



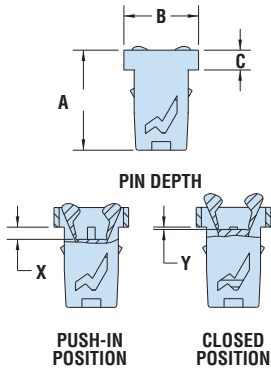


Heyco® Push Latches


ALL NEW
PRODUCTS!

MOUNTING HOLE Dimensions		PANEL THICKNESS		PART NO. Black	DESCRIPTION	Mating Pin	PIN DEPTH				PART DIMENSIONS					
							X Push-in		Y Closed		A Length		B Arm Spread		C Head Height	
in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
.315 x .276	8.0 X 7.0	.08	2.0	14309	DPL-100A	1	.071	1,80	.014	0,35	.59	15,0	.43	11,0	.11	2,9
				14312	DPL-150F	2	.077	1,95	.020	0,50						
				14313	DPL-700F	2	.073	1,85	.020	0,50	.58	14,8	.43	11,0	.11	2,9
				14314	DPL-400P	3	.059	1,50	.016	0,40	.58	14,8	.43	11,0	.12	3,1

Standard color black

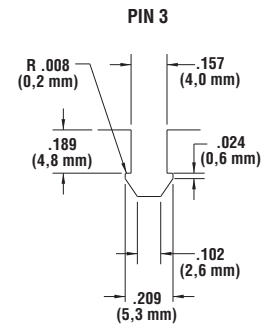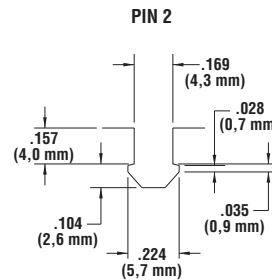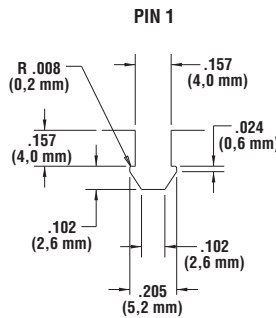

- Designed for fast and easy installation and removal - simply push to fasten and pull to release.
- Ideal for frequent maintenance work.
- Typical applications include metal enclosures, telecom equipment, appliances and electrical equipment.

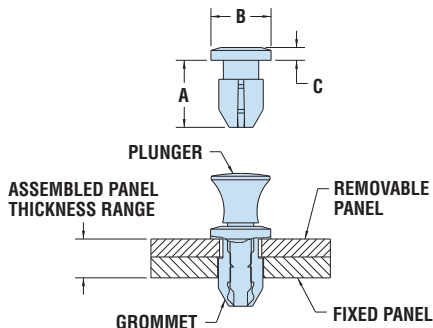

Heyco® Snap Latch Rivets

Grommet

STANDARD
PACK
1,000/BAG

FIXED PANEL HOLE DIAMETER		REMOVABLE PANEL THICKNESS		PART NO.		DESCRIPTION		MATING PLUNGER		PART DIMENSIONS					
				Black	White			Black	White	A Body Length		B Head Diameter		C Head Height	
in.	mm.	in.	mm.							in.	mm.	in.	mm.	in.	mm.
.253	6.4	.043	1.1	12283	12284	HSLG-1M	12261	12262	.31	8.0					
		.063	1.6	12285	12286	HSLG-2M	12263	12264	.33	8.5					
		.098	2.5	12287	12288	HSLG-3M	12265	12266	.37	9.5					
		.161	4.1	12289	12290	HSLG-4M	12267	12268	.43	11.0					

Standard colors black and white.


Plunger

REMOVABLE PANEL HOLE DIAMETER		ASSEMBLED PANEL THICKNESS RANGE				PART NO.		DESCRIPTION	MATING GROMMET		
		Minimum		Maximum		Black	White		Black	White	
in.	mm.	in.	mm.	in.	mm.						
.237	6.0	.059	1.5	.146	3.7	12261	12262	HSLPB-1M	12283	12284	
		.079	2.0	.165	4.2	12263	12264	HSLPB-2M	12285	12286	
		.118	3.0	.205	5.2	12265	12266	HSLPB-3M	12287	12288	
		.181	4.6	.272	6.9	12267	12268	HSLPB-4M	12289	12290	


Standard colors black and white.

Material Nylon 6/6
Flammability Rating 94V-2
Temperature Range 32°F (0°C) to 185°F (85°C)


Quick
Specs

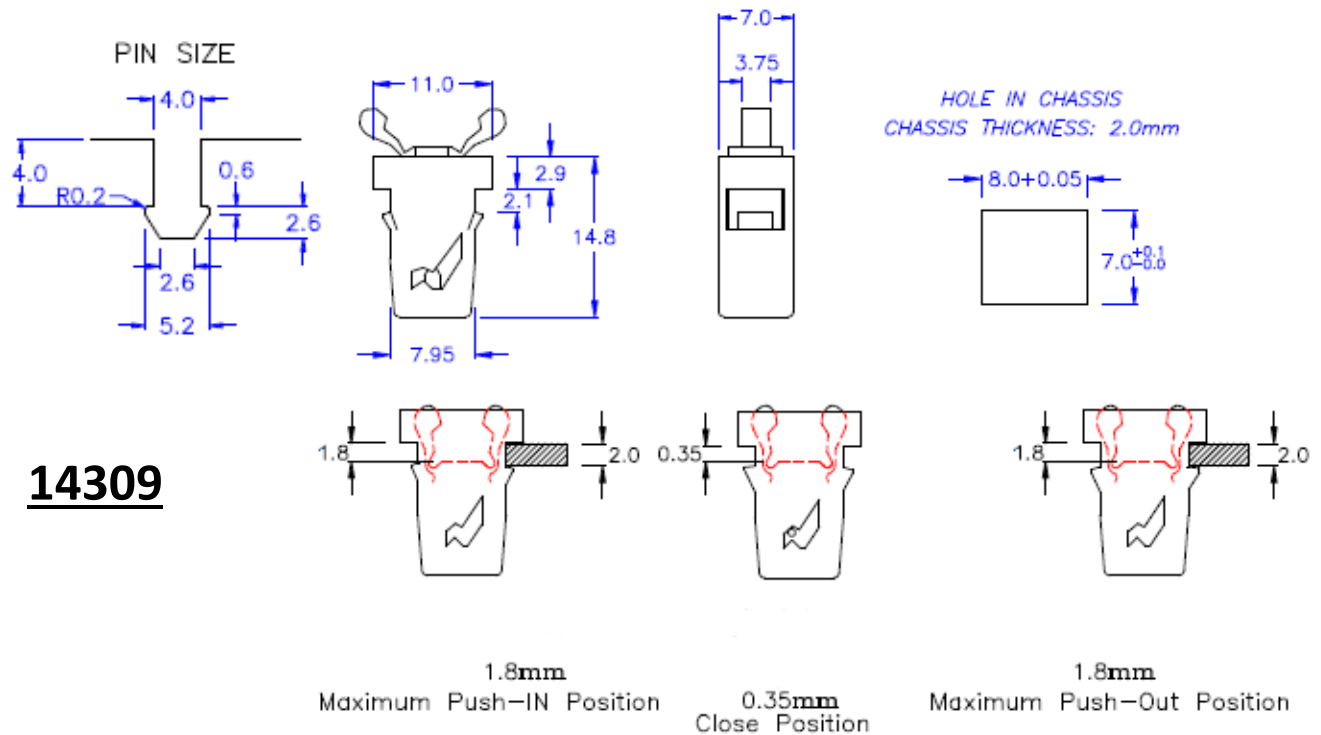


- A-** Door latch is opened by pushing-in 1.45mm distance (which is the 1.8mm distance from the bottom of matching clip to the top surface of platform)
- B-** The distance between bottom of matching clip to the top surface of platform should be in 0.35mm in closed position

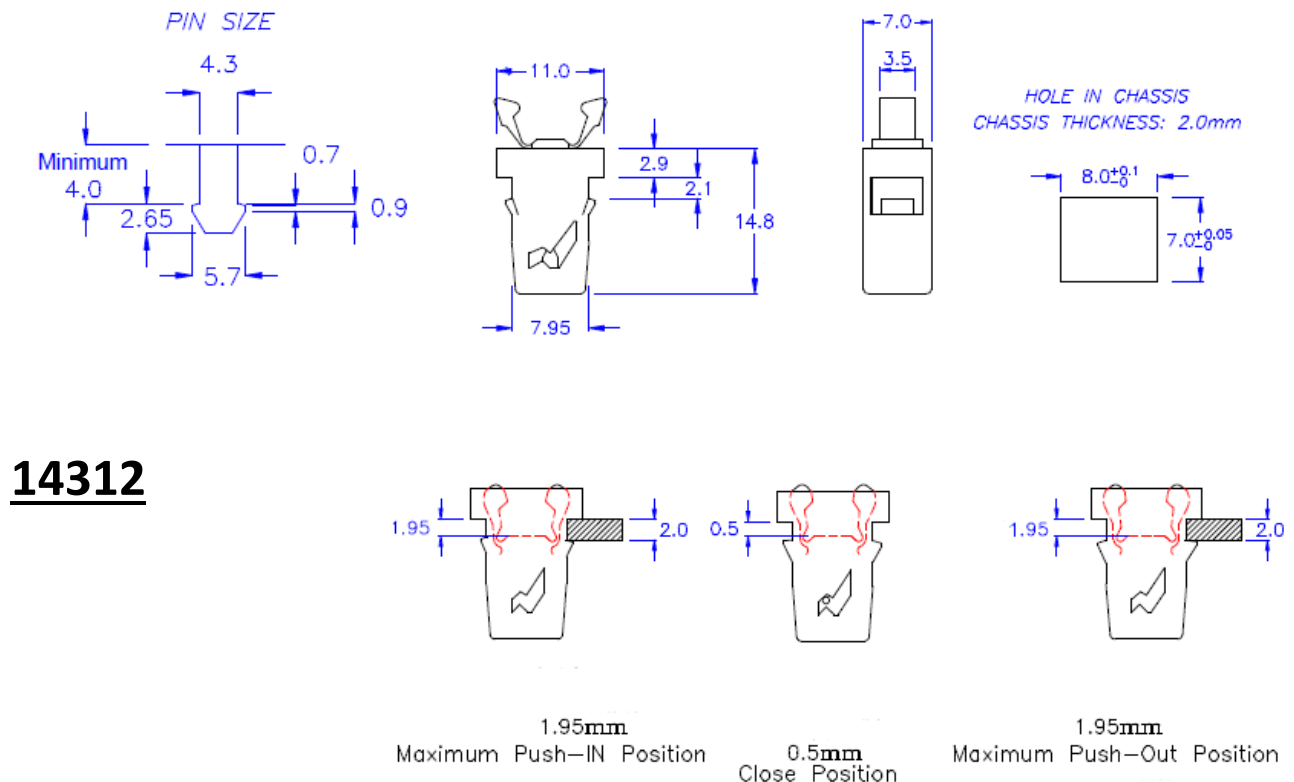


- A-** Door latch is opened by pushing-in 1.45mm distance (which is the 1.8mm distance from the bottom of matching clip to the top surface of platform)
- B-** The distance between bottom of matching clip to the top surface of platform should be in 0.5mm in closed position

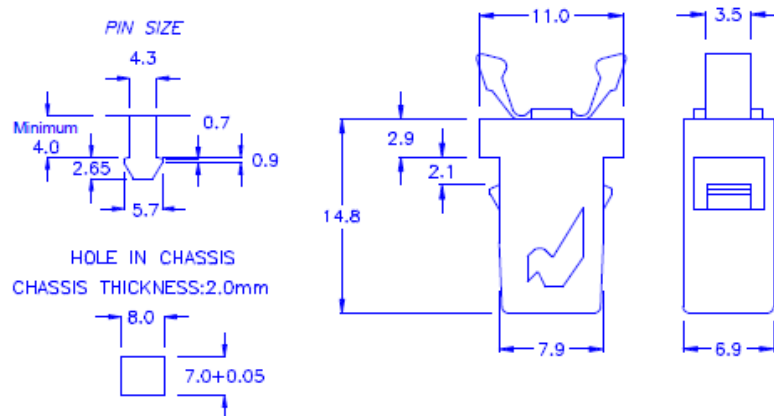


14313

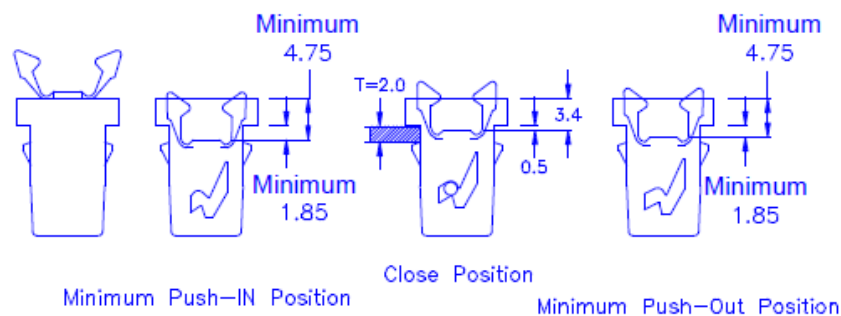

- A- Door latch is opened by pushing-in 1.35mm distance (which is the 1.8mm distance from the bottom of matching clip to the top surface of platform)
- B- The distance between bottom of matching clip to the top surface of platform should be in 0.5mm in closed position

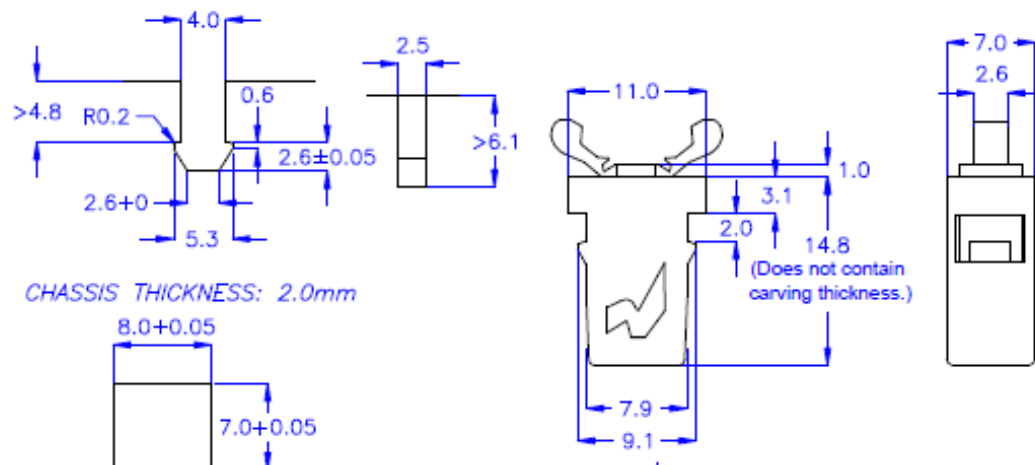

14314

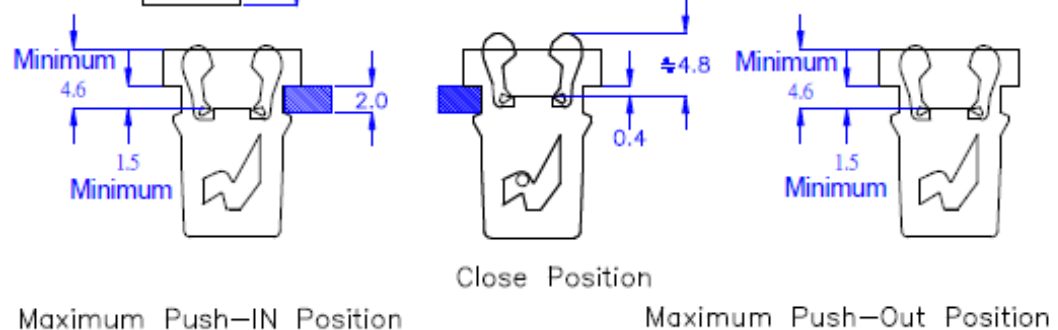

- A- Door latch is opened by pushing-in 1.1mm distance (which is the 1.8mm distance from the bottom of matching clip to the top surface of platform)
- B- The distance between bottom of matching clip to the top surface of platform should be in 0.4mm in closed position

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[14313](#) [14312](#) [14314](#) [14309](#)