




- Push mount design allows for fast installation.
- Releasable and reusable wire clip.
- Bayonet design allows from .02" (0,5 mm) panel thickness to .15" (3,8 mm).
- Bayonet snap locks into a .250" (6,3 mm) hole and will hold a 25 pound continuous load or a 50 pound impact load.
- Multiple sizes available for bundles from .19" (4,7 mm) to 1.00" (25,4 mm).




Arrowhead Mount Instructions



Simply insert base of clip into .250" diameter hole.

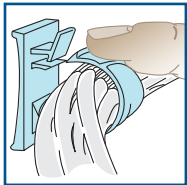

HEYClip opens easily for access to bundle.

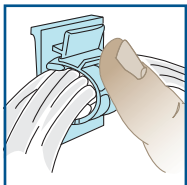



Unique lock/release feature operates easily and locks securely. When closed, HEYClip will not open until tab is released.

Quick Specs

HEYClip™ Locking Releasable Wire Clips - Arrowhead Mount


MAXIMUM BUNDLE DIAMETER		PART NO.		DESCRIPTION	FOOTPRINT		OVERALL HEIGHT C		CLAMP WIDTH D		MOUNTING HOLE DIA.	
in.	mm.	Gray	Black		A x B		in.	mm.	in.	mm.	in.	mm.
PMWC Series For Panels .02" (0,5 mm) to .08" (2,0 mm) thick												
.19	4,7	3845	3870	PMWC 187-20	.54 x 1.01	13,7 x 25,7	.39	9,9	.38	9,7	.250	6,4
.25	6,4	3846	3871	PMWC 250-20	.58 x 1.01	14,7 x 25,7	.45	11,4	.41	10,4		
.38	9,5	3847	3872	PMWC 375-20	.65 x 1.01	16,5 x 25,7	.53	13,5	.50	12,7		
.50	12,7	3848	3906	PMWC 500-20	.75 x 1.20	19,1 x 30,5	.73	18,5	.59	15,0		
.75	19,1	3849	3908	PMWC 750-20	.88 x 1.38	22,4 x 35,1	.99	25,1	.67	17,0		
1.00	25,4	3853	3909	PMWC 1000-20	1.37 x 1.88	34,8 x 47,8	1.35	34,3	.99	25,1		
For Panels .09" (2,3 mm) to .15" (3,8 mm) thick												
.19	4,7	3880	3910	PMWC 187-90	.54 x 1.01	13,7 x 25,7	.39	9,9	.38	9,7	.250	6,4
.25	6,4	3881	3912	PMWC 250-90	.58 x 1.01	14,7 x 25,7	.45	11,4	.41	10,4		
.38	9,5	3882	3913	PMWC 375-90	.65 x 1.01	16,5 x 25,7	.53	13,5	.50	12,7		
.50	12,7	3883	3914	PMWC 500-90	.75 x 1.20	19,1 x 30,5	.73	18,5	.59	15,0		
.75	19,1	3884	3915	PMWC 750-90	.88 x 1.38	22,4 x 35,1	.99	25,1	.67	17,0		
1.00	25,4	3885	3916	PMWC 1000-90	1.37 x 1.88	34,8 x 47,8	1.35	34,3	.99	25,1		

Standard color gray or black.

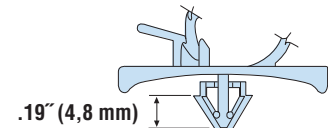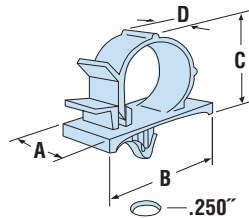

Release tab provides easy opening without forcing.

 Barbed locking element ensures reliable retention.



Quick lock/release allows fast lock-up and easy access to wire bundle.

Unique design of push mount permits fast installation and provides high pull-out resistance.

Material	Nylon 6/6
Flammability Rating	94V-2
Temperature Range	32°F (0°C) to 185°F (85°C) - Gray 32°F (0°C) to 221°F (105°C) - Black

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3846](#) [3351](#) [3359](#) [3349](#) [3350](#) [3361](#) [3360](#) [3663](#) [3931](#) [3668B](#) [3666](#) [3668](#) [3666B](#) [3932](#) [3915](#) [3663B](#)