



Heyco® Custom Turn-2-Lock Cord and Plug Sets

Female Configurations for 125 & 277 V, 15 & 20 Amp Applications

UL Recognized for Use in the U.S. and Canada Under File E217650

- Consult Heyco for special lengths, applied Terminations and Strain Reliefs, and **other custom configurations not shown**. Turn-2-Lock can be supplied with a Strain Relief, Metallic or Non-Metallic Cordgrip, and/or a Ring or other Terminal(s) already attached, to **save time and reduce cost** in your assembly process.
- Popular 125, 250, 277, 347, and 480 Volt; with 15, 20 and 30 Amp NEMA Configurations are available.
- We offer 12” to 15+ feet Turn-2-Lock Whips in both Male and Female NEMA configurations.
- **Applications:** For use in highbay and lowbay lighting; display cases; and commercial cooking, laundry, construction, and other specialty equipment where the possibility of the male and female ends of the plug becoming easily disconnected is not an option.
- Standard colors are Black and White. Consult Heyco for custom colors.

DESCRIPTION Volts-Amps	Type	WIRE			PART NO.	ROJ B in.	Strip Length C in.	Ring Terminal Part No. **	Strain Relief Part No. ***	
		Gauge AWG-Cond	Color	Length A* in.					D in.	

NEMA L5-15R, 125 Volts, 15 Amps, 12 Gauge

FT2L 125V-15A	SJTW	12-3	Black	24.0 36.0	S7610AI S7610	2.5	1/2	8145	-	-
			White	36.0	S7611	2.5	1/2	8145		
			Black	48.0 49.5	S7610QQ S7610CA	5 2.5	1/2 3/8	8145 -		
				60.0 72.0	S7610NN S7610AH	2.5	1/2	8145		
FT2L 125V-15A	STOW	12-3	Black	36.0	S7612	2.5	1/2	8145	-	-
				54.0	S7612AQ	15				
				60.0	S7612NN	2.5				
				66.0	S7612WW	6				
				72.0	S7612BR	2.5	5/8	-		
				84.0	S7612SS	2.5	1/2	8145		
96.0 120.0	S7612BK S7612AE	2.5	5/8	-						



NEMA L5-20R, 125 Volts, 20 Amps, 12 Gauge

FT2L 125V-20A	SJTW	12-3	Black	12.0	S7743BM	5	1/2	-	1865	6
				24.0	S7743BH	3.5	1/2	-	1865	4.5
				36.0	S7743	2.5	1/2	8145	-	-
				51.5	S7743AS	3.5	1/2	-	1865	4.5
FT2L 125V-20A	STOW	12-3	Black	72.0	S7743AW	5	1/2	-	-	-
				84.0	S7743TT	15				
				26.0	S7750BJ	4				
				36.0	S7750	2.5	1/2	8145		
				36.0	S7750ZZ	6	1/2	8145		
				60.0	S7750B	5	1/2	-		
66.0	S7750WW	6	1/2	8145						
84.0	S7750TT	15	1/2	-						

NEMA L7-15R, 277 Volts, 15 Amps, 12 Gauge

FT2L 277V-15A	SJTW	12-3	Black	36.0	S7733	2.5	1/2	8145	-	-
			White	36.0	S7734					

* Consult Heyco for custom lengths, applied Ring Terminals and applied Strain Relief devices.
 ** For additional Heyco Terminals see pages 8-15 thru 8-20.
 *** For additional Heyco Liquid Tight and Strain Relief Devices, see Sections 3 & 4.

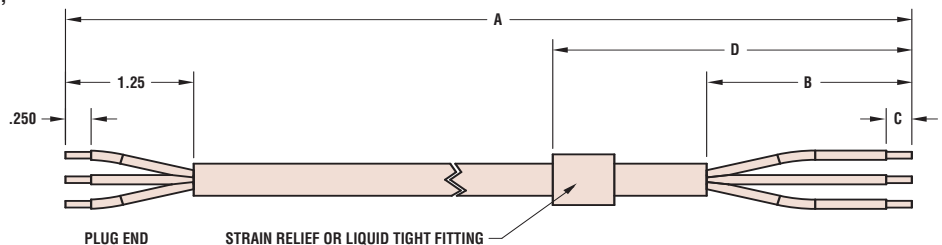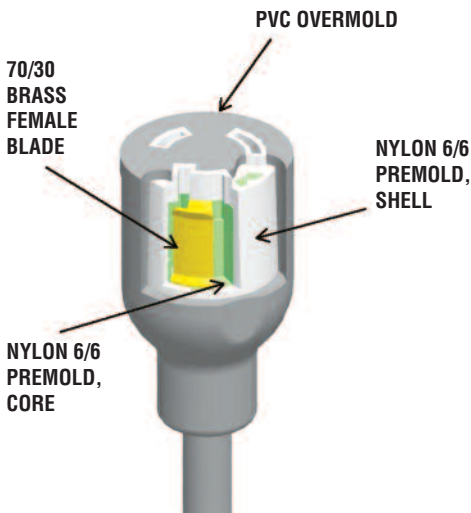

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[2949](#)