

Heyco® Quick Connect Terminals

See pages 8-8 & 8-9 for mating Quick Connect Male Tabs.

For Heyco Applicators, see page 8-59


Flag Terminals




Stock Gauge in.	Insulation Dia. in.	PART DATA			PART NO.	FEED	PART DIMENSIONS		
		Mating Tab Size in.	AWG Range	Material			W in.	L in.	D in.
Flag Insulation Support Terminals									
.016	.110/.160	.250 x .032	18-14	Brass	7950	Traverse	.300	.48	.24
				Tin-Pl	7951				
				Tin-Pl	7953*				
Flag Terminals									
.010	-	.110 x .020	24-18	Brass Tin-Pl	7910 7911	Traverse	.148	.31	.15

* Left-handed Flag.

- Quick Connects allow you to easily choose the right terminals for your application.
- **Flag Insulation Support Terminals** provide **strain relief** as well as **support** for insertion into the housing, allowing the terminal to withstand shock and vibration.
- Can be applied with your existing equipment or with Heyco Applicators.
- These applicators offer reliable connections semi-automatically and by integration into automated termination.
- Field Tested.
- Available in brass and tin-plated brass.
- .016" and .010" gauge material.
- Available in strip form only.
- DFARS Compliant

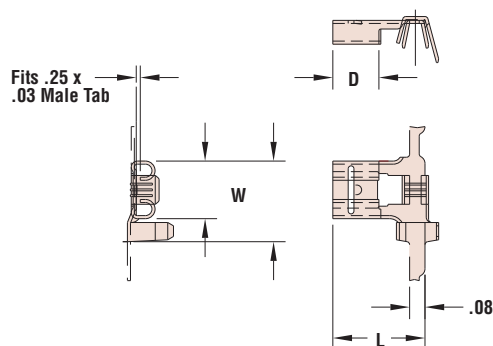

Flag Insulation Support Terminals

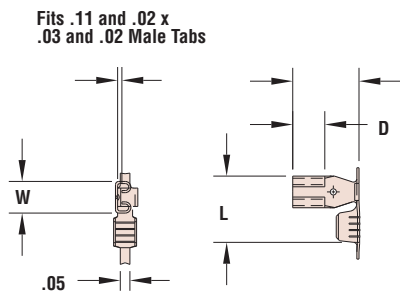

Flag Terminals

Materials	Alloy 260 Brass (70% Cu, 30% Zn. Higher Cu content resists dezincification)
	Tin-Pl = Brass, Tin plated before or after stamping
Certifications	<ul style="list-style-type: none"> UL Listed under Underwriters' Laboratories File E137778 CSA Certified by the Canadian Standards Association File 97795

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[7910](#) [7950](#) [7951](#) [7911](#) [7953](#)