

Heyco® Polyurethane Adhesive-Back Bumpers




	PART DIMENSIONS				PART NO.		DESCRIPTION	Pieces per Sheet
	A Diameter		B Height		Clear	Black		
	in.	mm.	in.	mm.				
HBA Series - Hemi								
	.25	6,4	.06	1,6	N040	N140	HBA 250-06	578
NEW!	.31	7,9	.09	2,3	N027	N127	HBA 312-09	450
NEW!	.34	8,6			NSD027	-	HBA 312-09-SD	
					N007	N107	HBA 335-09	
					NSD007	-	HBA 335-09-SD	
NEW!	.38	9,7	.15	3,8	N012	N112	HBA 375-15	200
					NSD012	-	HBA 375-15-SD	288
NEW!	.38	9,7	.21	5,3	N022	N122	HBA 375-21	300
NEW!					NSD022	-	HBA 375-21-SD	
NEW!	.39	9,9	.12	3,0	N010	N110	HBA 394-12	288
NEW!					NSD010	-	HBA 394-12-SD	
	.44	11,2	.20	5,1	N002	N102	HBA 440-20	242
					NSD002	-	HBA 440-20-SD	
	.62	15,7	.31	7,9	N015	N115	HBA 620-31	128
	.70	17,8	.38	9,7	N008	N108	HBA 700-38	98
	.75	19,1	.08	1,9	N039	N139	HBA 750-08	84
CBA Series - Cylinder								
NEW!	.38	9,7	.13	3,2	N034	N134	CBA 370-13	300
			.19	4,8	NSD034	-	CBA 375-13-SD	
	.50	12,7	.06	1,5	N035	N135	CBA 370-19	200
NEW!			.14	3,6	N005	N105	CBA 500-06	200
					N001	N101	CBA 500-14	
					NSD001	-	CBA 500-14-SD	
		.25	6,4	N006	N106	CBA 500-25		
	.65	16,5	.40	10,2	N011	N111	CBA 650-40	128
NEW!	.75	19,1	.16	4,1	N044	N144	CBA 750-16	98
	.78	19,8	.20	5,1	N041	N141	CBA 780-20	84
	.81	20,6	.12	3,0	N024	N124	CBA 810-12	72
NEW!	1.23	31,2	.10	2,5	N072	N172	CBA 1230-10	32
TCBA Series - Tapered Cylinder								
NEW!	.38	9,7	.18	4,6	NSD067	-	TCBA 375-18-SD	288
NEW!	.72	18,2	.56	14,2	N037	N137	TCBA 720-56	1
CDBA Series - Pocket								
NEW!	.50	12,7	.14	3,6	N018	N118	CDBA 500-14	200
					NSD018	-	CDBA 500-14-SD	
	.88	22,4	.40	10,2	N017	N117	CDBA 880-40	72
	1.81	46,0	.60	15,2	N030	N130	CDBA 1810-60	1
RCDBA Series - Reverse Cylindrical Depression								
NEW!	.50	12,7	.20	5,1	NSD058	-	RCDBA 500-20-SD	200
TBA Series - Square or Tapered								
	.40	10,2	.10	2,5	N020	N120	TBA 4040-10	242
	.50	12,7	.12	3,0	N009	N109	TBA 5050-12	200
			.23	5,8	N03R	N13R	TBA 5050-23	
NEW!	.78	19,8	.25	6,4	N029	N129	TBA 7878-25	98
NEW!			.38	9,7	N004	N104	TBA 7878-38	1
	.81	20,6	.30	7,6	N019	N119	TBA 8181-30	98
NEW!	1.00	25,4	.18	4,6	N036	N136	TBA 100100-18	5
RPBA Series - Round Pyramid								
NEW!	.50	12,7	.15	3,8	NSD033	-	RPBA 500-15-SD	200

Standard colors clear and black. For white, gray or brown consult Heyco.

NSD refers to soft durometer Polyurethane (Shore A 45-55) and will not be available in Black.

Material	Polyurethane
Certifications	Recognized under the Component Program of Underwriters' Laboratories File E196663
Flammability Rating	HB
Temperature Range	0°F (-18°C) to 180°F (82°C)

- Quick and easy installation—simply peel off backing and press into place. With no holes to drill, and no screws or rivets needed, adhesive backed bumpers will save you time and money.
- Bumpers can be attached to a wide variety of surfaces; aluminum, ceramic, formica, glass, painted surfaces, polyethylene, polypropylene, vinyl, and steel.
- Adhesive backed bumpers are nonmarking, nonstaining, skid, and scratch resistant.
- Surface must be clean, dry, and free of grease, oil, and other common solvents to obtain maximum adhesion. Clean surfaces with low strength solvents such as Isopropyl Alcohol or Heptane.
- Bumpers have a rubber-based pressure sensitive adhesive with an end use temperature of 0°F (-18°C) to 180°F (82°C).

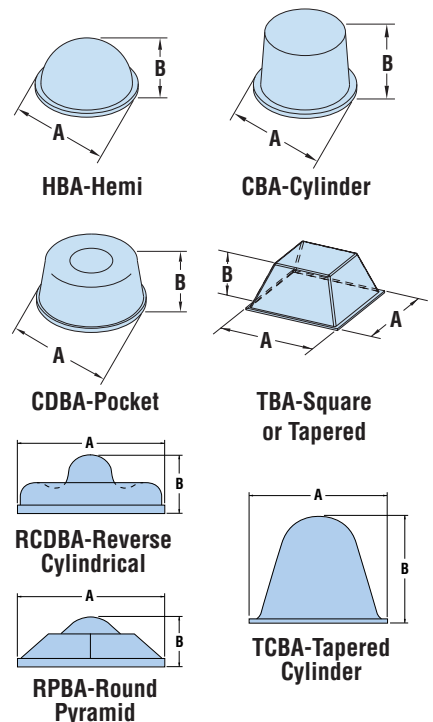

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Heyco:

[N006](#) [N107](#) [N117](#) [N135](#) [N124](#) [N101](#) [N106](#) [N130](#) [N105](#) [N008](#) [N007](#) [G2314](#) [G2313](#) [G2312](#) [N027](#) [N109](#) [N139](#)
[N015](#) [N018](#) [N002](#) [N017](#) [N127](#) [N115](#) [N041](#) [N112](#) [N141](#) [N118](#) [N030](#) [N108](#) [N140](#) [N024](#) [N011](#) [N012](#) [N009](#)
[N035](#) [N111](#) [N019](#) [N102](#) [N001](#) [N005](#) [N040](#) [N119](#) [N039](#) [N120](#) [N03R](#) [N13R](#) [N034](#) [N020](#) [N134](#) [N129](#) [NSD002](#)
[N044](#) [NSD027](#) [N072](#) [N022](#) [NSD001](#) [NSD018](#) [N122](#) [NSD010](#) [N029](#) [NSD007](#) [NSD034](#) [NSD033](#) [NSD022](#)
[NSD067](#) [NSD012](#) [NSD058](#) [N172](#) [N004](#) [N010](#) [N036](#) [N037](#) [N104](#) [N110](#) [N136](#) [N137](#) [N144](#)