



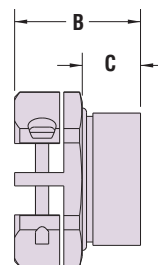

## Heyco® Brass Clamping Strain Reliefs

- Extra pull-out resistance
- For Heyco Liquid Tight Clamping Cordgrips, see page 3-45.
- Locknuts not included. For metal locknut specifications or to order locknuts separately, see page 3-48.

CABLE DIAMETER RANGE				PART NO.	THREAD SIZE	PART DIMENSIONS							
Minimum		Maximum				A Clearance Hole Dia.		B Max. O.A. Length		C Thread Length		D Wrenching Flat Size	
in.	mm.	in.	mm.			in.	mm.	in.	mm.	in.	mm.	in.	mm.
PG Hubs													
.157	4,0	.315	8,0	<b>14875</b>	PG7	.492	12,5	.59	15,0	.24	6,0	.67	17
.236	6,0	.394	10,0	<b>14876</b>	PG9	.598	15,2	.67	17,0	.24	6,0	.79	20
.236	6,0	.472	12,0	<b>14877</b>	PG11	.732	18,6	.67	17,0	.24	6,0	.87	22
.276	7,0	.591	15,0	<b>14878</b>	PG13	.827	21,0	.71	18,0	.28	7,0	.94	24
.354	9,0	.669	17,0	<b>14879</b>	PG16	.886	22,5	.75	19,0	.28	7,0	1.06	27
.472	12,0	.866	22,0	<b>14880</b>	PG21	1.114	28,3	.87	22,0	.31	8,0	1.38	35
.709	18,0	1.181	30,0	<b>14881</b>	PG29	1.469	37,3	.91	23,0	.31	8,0	1.65	42
.945	24,0	1.417	36,0	<b>14882</b>	PG36	1.874	47,6	1.10	28,0	.39	10,0	2.17	55
Metric Hubs													
.197	5,0	.315	8,0	<b>14884</b>	M12 x 1,5	.472	12,0	.79	20,0	.39	10,0	.63	16
.236	6,0	.413	10,5	<b>14885</b>	M16 x 1,5	.630	16,0	.83	21,0	.39	10,0	.75	19
.315	8,0	.591	15,0	<b>14886</b>	M20 x 1,5	.787	20,0	.87	22,0	.39	10,0	.94	24
.492	12,5	.807	20,5	<b>14887</b>	M25 x 1,5	.984	25,0	.94	24,0	.43	11,0	1.18	30
.669	17,0	1.004	25,5	<b>14888</b>	M32 x 1,5	1.260	32,0	1.10	28,0	.51	13,0	1.42	36
.945	24,0	1.299	33,0	<b>14889</b>	M40 x 1,5	1.575	40,0	1.18	30,0	.51	13,0	1.81	46

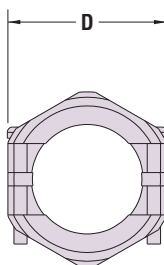

*Quick  
Specs*

Material  
Temperature Rating  
IP Rating

Nickel-Plated Brass body with Stainless Steel screws  
-58°F (-50°C) to 572°F (300°C)  
IP 20

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[14882](#) [14880](#) [14881](#) [14878](#) [14884](#) [14889](#) [14888](#) [14877](#) [14875](#) [14879](#) [14885](#) [14886](#) [14887](#) [14876](#)