




HEYClip™ Cable Holders - Adhesive Back Mount


WIRE CAPACITY		PART NO.			DESCRIPTION	OVERALL HEIGHT C		FOOTPRINT		STYLE
		Rubber	Acrylic	VHB		A x B				
in.	mm.		Natural			in.	mm.	in.	mm.	
CH RA Series										
.17 x .12	4,4 x 3,0	4271	—	—	CH RA-72	.31	7,9	.37 x .37	9,4 x 9,4	4
.18 x .04	4,6 x 1,0	—	4212A	4212V	CH RA-65	.26	6,5	.37 x .37	9,4 x 9,4	1
.18 x .11	4,6 x 2,8	—	4213A	4213V	CH RA-83	.33	8,3			
.25 x .13	6,4 x 3,2	4214	4214A	4214V	CH RA-102	.40	10,2	.50 x .50	12,7 x 12,7	
.31 x .16	7,9 x 4,1	4215	4215A	4215V	CH RA-119	.47	11,9			
.35 x .24	8,9 x 6,1	4216	4216A	4216V	CH RA-141	.56	14,1			
.35 x .31	8,9 x 7,9	—	4217A	4217V	CH RA-157	.62	15,7	.76 x .74	19,3 x 18,8	2
.45 x .38	11,4 x 9,5	3603	3603A	3603V	CH RA-122	.47	12,0			
x .75	x 19,0	3608	3608A	3608V	CH RA-172	.68	17,2			
		3613	3613A	3613V	CH RA-267	1.05	26,7			
.29 x .25	7,4 x 6,4	3614	—	—	CH RA-121	.48	12,1	.50 x 1.00	12,7 x 25,4	3

Standard color natural. Flame retardant UL 94V-0 material available, consult Heyco.


Style 1

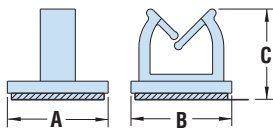


Style 2

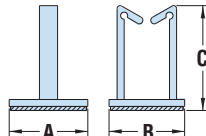

Style 3

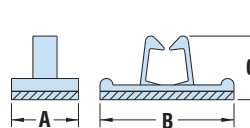

Style 4

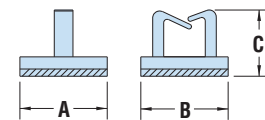

HEYClip™ Cable Holders - Blind Head Mount

For .250" (6,4 mm) Minimum Thickness Panels


WIRE CAPACITY		PART NO.	DESCRIPTION	OVERALL HEIGHT C		FOOTPRINT A x B		MOUNTING HOLE DIA.		
in.	mm.			in.	mm.	in.	mm.	in.	mm.	
Top Entry - Regular Gate										
.44	x .19	x 4,8	4202	CH RB-13	.51	13,0	.22 x .61	5,6 x 15,5	.312	7,9
	x .38	x 9,7	4203	CH RB-18	.71	18,0				
	x .74	x 18,8	4204	CH RB-27	1.06	26,9				
	x 1.05	x 26,7	4205	CH RB-35	1.40	35,6				
Top Entry - Latch Gate										
.44	x .14	x 3,6	4206	CH LB-13	.51	13,0	.22 x .61	5,6 x 15,5	.312	7,9
	x .33	x 8,4	4207	CH LB-18	.71	18,0				
	x .69	x 17,5	4208	CH LB-27	1.06	27,0				
	x 1.00	x 25,4	4209	CH LB-35	1.38	35,0				
Side Entry - Regular Gate*										
.11	x .33	x 8,3	4220	CH RB-13-90	.20	5,1	.37 x .50	9,5 x 12,7	.157	4,0
	x .49	x 12,5	4221	CH RB-17-90	.20	5,1	.37 x .67	9,5 x 17,0		

Standard color natural. Flame retardant UL 94V-0 material available, consult Heyco. *For Panel thickness up to .161" (4,1 mm)

Material	Nylon 6/6	Adhesives*
Flammability Rating	94V-2	Rubber Adhesive 50°F (10°C) to 155°F (68°C)
Temperature Range	Nylon: 32°F (0°C) to 185°F (85°C)	Acrylic Adhesive 10°F (-12°C) to 180°F (82°C)
		VHB Adhesive -40°F (-40°C) to 194°F (90°C)


*Low temperature reflects minimum application temperature for adhesives

- Gather and route cables.
- Part Description Key: CH RB-X, where X = Overall Height (mm).

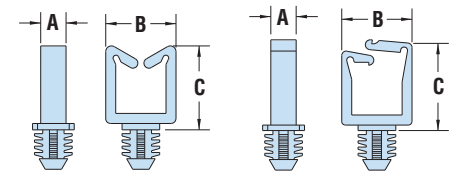

Top Entry Regular Gate

Top Entry Latch Gate

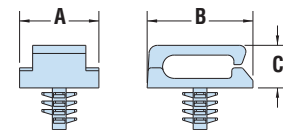

Side Entry Regular Gate

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3603A](#) [3603V](#) [3608A](#) [3608V](#) [3613V](#) [4214A](#) [4217V](#) [4214V](#) [4215A](#) [4215V](#) [4216A](#) [4216V](#) [4217A](#) [4212A](#) [4212V](#)
[4213A](#) [4213V](#) [3613-P](#)