





- Self-adjusting Arrowhead Mount protrudes approximately .22" (5,6 mm). (CHSO only)
- Part Description Key: CH SO-X, where X = Overall Height (mm).
- Self-adjusting Arrowhead Mount protrudes approximately .20" (5,1 mm).

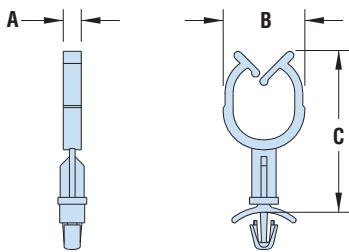

CH SO Series

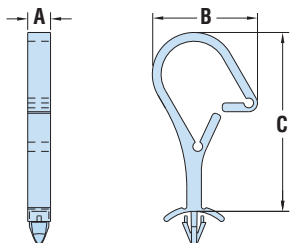

CH RJ Series

HEYClip™ Standoff Cable Holders - Arrowhead Mount

WIRE CAPACITY		PART NO.	DESCRIPTION	HEIGHT ABOVE PANEL C		FOOTPRINT A x B		MOUNTING HOLE DIA.	
in.	mm.			in.	mm.	in.	mm.	in.	mm.

CH SO Series For Panels up to .063" (1,6 mm) thick

.54 x .54	13,6 x 13,6	3349	CH SO-6	1.00	25,5	16 x .71	4,0 x 18,0	.187	4,8
		3350	CH SO-8	1.08	27,5				
		3351	CH SO-10	1.16	29,5				
		3359	CH SO-12	1.24	31,5				
		3360	CH SO-14	1.32	33,5				
		3361	CH SO-16	1.40	35,5				
		3369	CH SO-18	1.48	37,5				
		3370	CH SO-20	1.56	39,5				
		3371	CH SO-22	1.63	41,5				
		3385	CH SO-24	1.71	43,5				
		3386	CH SO-26	1.79	45,5				
		3387	CH SO-28	1.87	47,5				

CH RJ Series For Panels .09" (2,3 mm) thick

.62	15,7	3598	CH RJ-625	1.70	42,9	.22 x 1.00	5,6 x 25,4	.187	4,8
-----	------	------	-----------	------	------	------------	------------	------	-----

Standard color natural. Flame retardant UL 94V-0 material available, consult Heyco.

HEYClip™ Round Cable Holders

BUNDLE DIAMETER		PART NO.		DESCRIPTION	OVERALL HEIGHT C		FOOTPRINT A x B		MOUNTING HOLE		STYLE
in.	mm.	Natural	Black		in.	mm.	in.	mm.	in.	mm.	

Arrowhead Mount - For Panels from .030" (0,8 mm) to .060" (1,5 mm) thick

.45	11,4	3663	3663B	CHCS 4	.57	14,5	.18 x .57	4,5 x 14,5	.12	3,1	1
.62	15,9	3666	3666B	CHCS 10	.97	24,6	.30 x 1.03	7,5 x 26,2	.25	6,4	2

Arrowhead Mount - For Panels from .058" (1,5 mm) to .064" (2,5 mm) thick

1.00	25,4	3668*	3668B*	CHCS 16	1.34	34,1	.38 x 1.25	9,5 x 31,7	.25	6,4	3
------	------	-------	--------	---------	------	------	------------	------------	-----	-----	---

Slotted with Adhesive Back Mount


.62	15,9	3931	-	CHCS 10A	.95	24,1	1.00 x 1.00	25,4 x 25,4	.25	6,4	4
-----	------	------	---	----------	-----	------	-------------	-------------	-----	-----	---

Slotted for Screw Mount


.62	15,9	3932	-	CHCS 10B	.92	23,3	1.00 x 1.00	25,4 x 25,4	.25	6,4	4
-----	------	------	---	----------	-----	------	-------------	-------------	-----	-----	---

Standard color natural. Flame retardant UL 94V-0 material available, consult Heyco.


*Designed to fit square mounting hole

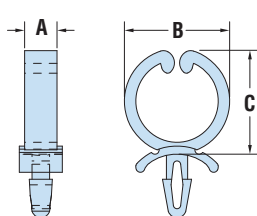


Style 1

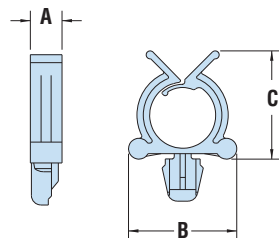

Style 2

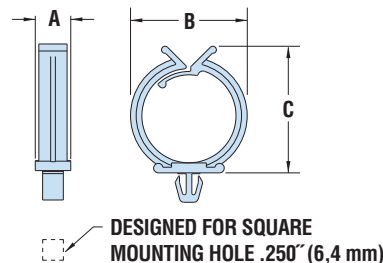

Style 3

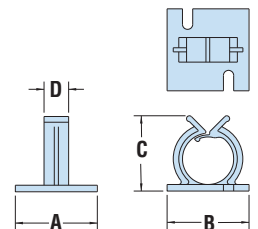

Style 4

Quick
Specs

Material	Nylon 6/6
Flammability Rating	94V-2
Temperature Range	32°F (0°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3370](#) [3385](#) [3386](#) [3391](#) [3395](#) [3397](#) [3369](#) [3371](#) [3387](#) [3666-P](#) [3668-P](#) [3663-P](#) [3663B-P](#) [3932-P](#) [3666B-P](#)
[3668B-P](#)