


**ALL NEW
PRODUCTS!**

HEYClip™ Shorty Side Entry Cable Holders

Arrowhead Mount


- For Top Entry Shorty Cable Holders, see page 7-55.
- Ideal when space is restricted and side entry is required.

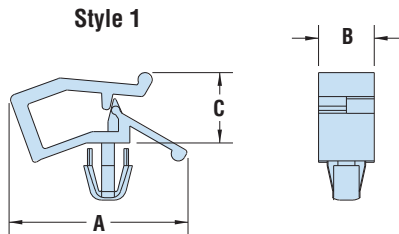

WIRE CAPACITY		PART NO. Natural	DESCRIPTION	PART DIMENSIONS						MOUNTING HOLE DIA.		STYLE
in.	mm.			A Length		B Width		C Height				
				in.	mm.	in.	mm.	in.	mm.	in.	mm.	
For Panels from .047" (1,2 mm) to .078" (2,0 mm) Thick												
.11 x .17	2,8 x 4,2	12130	CH SE-1117	.52	13,2	.20	5,0	.19	4,7	.138	3,5	1
.17 x .22	4,3 x 5,5	12131	CH SE-1722	.59	15,1	.20	5,0	.26	6,7			
For Panels from .062" (1,6 mm) to .094" (2,4 mm) Thick												
.10 x .17	2,6 x 4,2	12133	CH SE-1017	.50	12,7	.20	5,0	.21	5,3	.138	3,5	1
For Panels from .024" (0,6 mm) to .118" (3,0 mm) Thick												
.236 x .472	6,0 x 12,0	11980*	CH SE-12	.795	20,2	.394	10,0	.618	15,7	.265	6,73	2

Standard color natural. Flame retardant UL 94V-0 material available, consult Heyco.


*Standard color black.

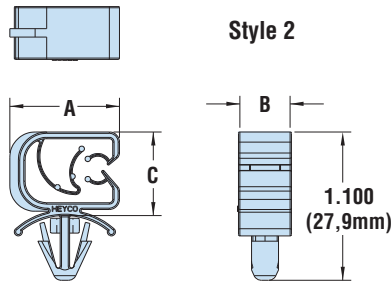

HEYClip™ Ladder Cable Holders

Adhesive Back Mount

- Adjustable design secures wire bundles.
- Applies simply to clean dry surface.

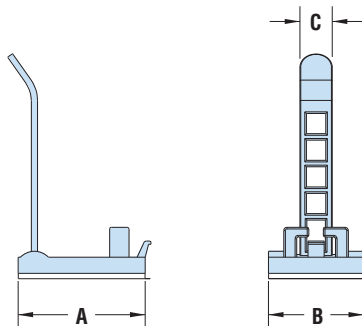

MAXIMUM BUNDLE DIAMETER		PART NO. Natural	DESCRIPTION	PART DIMENSIONS						MOUNTING HOLE DIA.	
in.	mm.			A Length		B Width		C Ladder Width		in.	mm.
.47	12,0	12360	CH LAD-047	.79	20,0	.59	15,0	.20	5,0	.133	3,4
.77	19,5	12361	CH LAD-077								
.51	13,0	12362	CH LAD-051							.138	3,5
.67	17,0	12363	CH LAD-067	.98	25,0	.71	18,0	.31	8,0		
.73	18,5	12364	CH LAD-073								
.87	22,0	12365	CH LAD-087	1.20	30,5	.83	21,0	.47	12,0		
1.02	26,0	12367	CH LAD-102								

Standard color natural.

*Quick
Specs*

Material	Nylon 6/6
Flammability Rating	94V-2
Temperature Range	32°F (0°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[12130](#) [12131](#) [12133](#)