



Heyco® Double D Hole Plugs

For Mounting Holes with Flats

 
Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)

PANEL DIMENSIONS				PART NO.		DESCRIPTION	PART DIMENSIONS			
D Mounting Hole Dia.		C To Prevent Rotation		Black	White		A Head Diameter		B Overall Height	
in.	mm.	in.	mm.				in.	mm.	in.	mm.
.375	9,5	.345	8,8	2617	2618	DP 375*	.47	11,9	.41	10,3
.437	11,1	.390	9,9	2488	2489	DD 437-390	.53	13,5		
.500	12,7	.445	11,3	2491	2492	DD 500-445	.55	14,7		
.562	14,3	.530	13,5	2494	2495	DD 562-530	.66	16,7		
.625	15,9	.550	14,0	2497	2498	DD 625-550	.73	18,5		
.750	19,1	.625	15,9	2503	2504	DD 750-625	.92	23,4		
.875	22,2	.770	19,5	2509	2510	DD 875-770	1.02	25,8	.45	11,5
				2511	-	DD 875-770-9**	.94	23,8		
1.109	28,2	1.000	25,4	2717	2718	DD 1109-1000	1.22	30,9	.48	12,1
2.000	50,8	1.875	47,6	2959	2963	DD 2000-1875	2.17	55,1		



Standard colors black and white. Consult Heyco for other colors.

*On installation, DP 375 Locking Fingers must be aligned with Mounting Hole Flats.


**Smaller than standard Head Diameter, for clearance situations.





DD Series

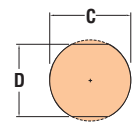 


MOUNTING HOLE

 

RP Series

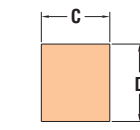 

MOUNTING HOLE

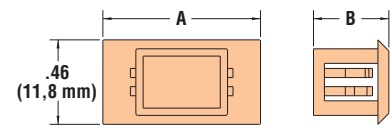

3299, 3388, 3389

Heyco® Rectangular Blanking & Connector Port Plugs

Multiple Locking Steps for Various Panel Thicknesses

PANEL DIMENSIONS						PART NO.	DESCRIPTION	PART DIMENSIONS			
Mounting Hole								A Head Dimensions	B Overall Height		
Maximum Thickness		C Length		D Width							Black
in.	mm.	in.	mm.	in.	mm.			in.	mm.	in.	mm.
Rectangular Blanking Plugs											
.03	0,64	.96	24,5	.96	24,5	13910	RP 245-245	1.06 x 1.06	26,9 x 26,9	.30	7,6
						13911	RB 245-245*	1.05 x 1.05	26,7 x 26,7		
.04	1,0	.27	6,9	.29	7,4	2512	RP 69-74	.37 x .37	9,4 x 9,4	.33	8,4
.10	2,5	.45	11,5	.51	13,9	1890	RP 115-130	.58 x .58	14,7 x 14,7	.40	10,2
.13	3,2	.94	23,8	1.65	42,0	2513	RP 239-419	2.17 x 1.38	55,1 x 35,0	.46	11,7
.16	4,0	.69	17,5	.69	17,5	1892	RP 175-175	.83 x .83	21,1 x 21,1	.47	11,9
Connector Port Plugs											
.14	3,5	.37	9,5	.51	13,0	3299	RP 95-130-1	.63	16,0	.41	10,5
						3388	RP 95-130	.87	22,0		
				1.02	26,0	3389	RP 95-260	1.38	35,0		

Standard color black.

*Bushing version of the above plug.

Material	Nylon 6/6
Certifications	UL Recognized under the Component Program of Underwriter Laboratories File E51579 (DD only)
Flammability Rating	94V-2
Temperature Range	-40°F (-40°C) to 221°F (105°C)

Quick Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[2513](#)