




HEYClip™ Drive Fasteners

WILL FIT THESE PANELS						PART NO.						DESCRIPTION	PART DIMENSIONS					
MOUNTING HOLE DIA.		ASSEMBLED PANEL THICKNESS				Acetal		Nylon V-2		Nylon V-0			A Length		B Head Height		C Head Diameter	
		Min.		Max.		Black	Natural	Black	Natural	Black	Natural		in.	mm.	in.	mm.	in.	mm.
in.	mm.	in.	mm.	in.	mm.													
.125	3,2	.04	1,0	.18	4,5	9201	9202	9710	9711	9710F	9711F	DF 125-039	.51	13,0	.06	1,5	.31	8,0
.154	3,9	.04	1,0	.20	5,0	9203	9204	9712	9713	9712F	9713F	DF 154-039	.55	14,0	.06	1,6	.35	9,0
.185	4,7	.04	1,0	.22	5,5	9205	9206	9714	9715	9714F	9715F	DF 185-039	.59	15,0	.07	1,7	.39	10,0
						9126	9127	9716	9717	9716F	9717F	DF 185-039-1	.59	15,0	.11	2,9	.43	11,0
.217	5,5	.24	6,0	.35	9,0	9209	9210	9718	9719	9718F	9719F	DF 217-236	.71	18,0	.08	2,0	.47	12,0
.250	6,4	.06	1,5	.26	6,5	9128	9129	9722	9723	9722F	9723F	DF 250-059	.67	17,0	.08	2,0	.47	12,0
.307	7,8	.06	1,5	.28	7,0	9207	9208	9720	9721	9720F	9721F	DF 307-059	.75	19,0	.09	2,2	.55	14,0

Standard colors black and natural.

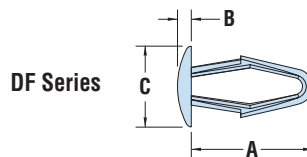

- Heyco Drive Fasteners help secure and fasten components and/or panels to a wide variety of materials such as wood, metal, particle board, plastic and rubber.
- Hollow body design increases flexibility, for easy installation.
- Part Description Key: DF XXX-YYY where XXX = Mounting Hole Diameter (inches) and YYY = minimum Panel Thickness (inches).


HEYClip™ Mounting Buttons

WILL FIT THESE PANELS						PART NO.	DESCRIPTION	PART DIMENSIONS						
MOUNTING HOLE DIA.		ASSEMBLED PANEL THICKNESS						Natural	A Length		B Head Height		C Head Length	
in.	mm.	in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.
.156	4,0	.031	0,8	.100	2,4	4251	HMP 156-031	.24	6,1	.19	4,8	.38	9,5	
		.094	2,4	.157	4,0	4252	HMP 156-094	.30	7,7					
		.189	4,8	.220	5,6	4253	HMP 156-189	.40	10,1					
		.220	5,6	.312	7,1	4254	HMP 156-220	.43	10,9					
		.312	7,9	.375	9,5	4255	HMP 156-312	.52	13,2					
		.375	9,5	.437	11,1	4256	HMP 156-375	.58	14,8					
		.437	11,1	.500	12,7	4257	HMP 156-437	.65	16,4					
		.500	12,7	.563	14,3	4258	HMP 156-500	.71	18,0					
		.563	14,3	.625	15,9	4259	HMP 156-563	.77	19,6					
.187	4,7	.031	0,8	.100	2,4	14251	HMP 187-031	.24	6,1	.19	4,8	.48	12,3	
		.094	2,4	.157	4,0	14252	HMP 187-094	.30	7,7					
		.189	4,8	.220	5,6	14253	HMP 187-189	.40	10,1					
		.220	5,6	.312	7,1	14254	HMP 187-220	.43	10,9					
		.312	7,9	.375	9,5	14255	HMP 187-312	.52	13,2					
		.375	9,5	.437	11,1	14256	HMP 187-375	.58	14,8					
		.437	11,1	.500	12,7	14257	HMP 187-437	.65	16,4					
		.500	12,7	.563	14,3	14258	HMP 187-500	.71	18,0					
		.563	14,3	.625	15,9	14259	HMP 187-563	.77	19,6					

Standard color natural.



- An easy and economical solution to mating objects together.
- The mounting arrowhead locks securely in place yet allows for removal from underside of board.
- Available for .156" (4,0 mm) and .187" (4,7 mm) mounting holes for panel thicknesses from .031" (0,8 mm) to .625" (15,9 mm)

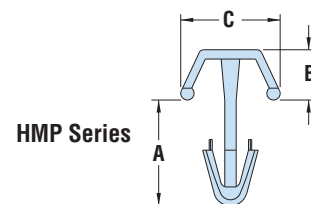

NEW!

	DF	DF		HMP
Material	Acetal (POM)	Nylon 6/6	Material	Nylon 6/6
Flammability Rating	94-HB	UL94 V-0 *OR* UL94 V-2	Flammability Rating	94V-2
Temperature Range	-4°F (-18°C) to 220°F (104°C)	-40°F (-40°C) TO 185°F (85°C)	Temperature Range	32°F (0°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[9207](#) [9210](#) [9202](#) [9203](#) [9206](#) [9208](#) [9209](#) [9201](#) [9127](#) [9129](#) [9128](#) [9126](#) [9204](#) [9205](#) [9710](#) [9710F](#) [9711](#) [9711F](#)
[9712](#) [9712F](#) [9722](#) [9722F](#) [9723](#) [9723F](#) [9719](#) [9719F](#) [9720](#) [9720F](#) [9721](#) [9721F](#) [9716](#) [9716F](#) [9717](#) [9717F](#) [9718](#)
[9718F](#) [9713](#) [9713F](#) [9714](#) [9714F](#) [9715](#) [9715F](#)